



INTERIOR HOOK COLLECTION

# Stainless Steel

Choose from our selection of beautiful stainless steel hooks; with a wide variety of coat, latch, swing, wire, and specialty hooks we are sure we will have the hook you need. Ideal for outdoor application and exposure to the elements.

Please refer to our *General Catalog* for our complete selection.



COAT HOOKS



LATCH HOOKS



SWING HOOKS



WIRE HOOKS



SPECIALTY HOOKS



# Undermount Hooks

Discrete, safe and durable. Our undermount hooks combine highly functional pieces with everything else you expect from a hook.



5HJU-60M  
304 Stainless Steel  
W61 x H69 x D69 (mm)



HK-CH35  
Aluminum Alloy  
W60 x H42.4 x D79 (mm)



HJ (20,30,50)  
304 Stainless Steel  
20 W28 x H27 x D17 (mm)  
30 W32.5 x H33 x D17 (mm)  
50 W43.5 x H47 x D22 (mm)




RF-50  
304 Stainless Steel  
W50 x H39 x R38 (mm)




UC (048,055)  
304 Stainless Steel  
048 W40 x H55 x D29.9 (mm)  
055 W40 x H62 x D30.8 (mm)

## Premium Materials

From the shine of the stainless steel to the warmth of leather, or the soft-touch of silicon; we're committed to the finest materials available with aesthetics and functionality in mind.

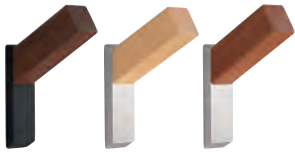

 **PREMIUM WOOD**  
PXB-WM-5-111  
Base: Zinc Alloy, Steel  
W22 x H96 x D64.5 (mm)



**LEATHER CHIC**  
PXB-LE05-111  
Silicone Rubber, Zinc Alloy  
W45 x H45.5 x D66 (mm)



## Select Metals

Unique look and style, with chrome and gold plating, matte black and stainless steel finishes; our metal hooks are sure to deliver elegance to any environment.



**PXB-QL05-111**  
Zinc Alloy  
W48 x H51 x D63 (mm)



**HK-QC18 & HK-QC24**  
Zinc Alloy  
18 W43.5 x H45.6 x D53.9 (mm)  
24 W45 x H61.3 x D75 (mm)



## Sleek Design

Classic look, aesthetics and functionality are achieved in the Urbanmetal and Nordic hooks. Design coupled with great materials bring luxury to any room.



**URBANMETAL**  
PXB-UM05-101  
Aluminum Alloy  
W47 x H69.6 x D39 (mm)



**URBANMETAL QUEST**  
PXB-UM05101-Q1  
Aluminum Alloy, Brass  
W47 x H69.6 x D39 (mm)



**NORDIC RUBBER**  
PXB-GN05-101  
Silicone Rubber, Zinc Alloy  
W25 x H75 x D48 (mm)



**AGED CAST**  
PXB-AC05-111  
Brass  
W36 x H52.5 x D58 (mm)



**AGED BASE**  
PXB-AB05-101,111  
Brass  
101: W17 x H42 x D39 (mm)  
111: W23.5 x H58 x D54 (mm)



**AGED SCREW**  
PXB-AS05  
Brass  
W51 x H45.2 x D58.6 (mm)

## Aged Metals

Our aged hooks hold a rustic style coupled with functionality. Great to compliment any room with a raw yet elegant element.





## Latch Hooks

Made from 316 stainless steel and with up to 132 lbs of load capacity, our latch hooks can withstand the elements while looking amazing.



EN-R80  
316 Stainless Steel  
W16 x H80 x D31.8 (mm)



EN-K (84-120)  
316 Stainless Steel  
84 W16 x H84 x D38 (mm)  
120 W22 x H120 x D54 (mm)



EN-R100F  
316 Stainless Steel  
W20 x H100 x D60 (mm)



EN-R80-K  
316 Stainless Steel  
W21.5 x H89.7 x D40.5 (mm)



## Recessed Hooks

With capacity of up to 44 lbs our recessed hooks are an ideal solution for safety, style and functionality.

Please refer to our *General Catalog* for our complete selection.



NF-R64  
Zink Alloy  
R64 x D17.5 (mm)



NF-60D  
Aluminum  
W24 x H60 x D24 (mm)



NF-47D  
Polycarbonate  
W23.9 x H54.4 x D17.4 (mm)

## Colorful Environments

Our Gomu Ranger hooks are a beautiful and safe addition to your home environments.



GOMU RANGER  
DOUBLE  
PXB-GR05-211  
Silicone Rubber,  
304 Stainless Steel  
W15 x H75.4 x D63.1 (mm)



GOMU RANGER  
SINGLE  
PXB-GR05-111  
Silicone Rubber,  
304 Stainless Steel  
W15 x H45 x D50.5 (mm)



# DESIGN WITHOUT COMPROMISE

## CONCEALED SCREW

Unnoticeable screws for clean designs.



## ELABORATE DESIGN

0.2mm-round corners allow for an exquisite shape.

## CAREFULLY SOURCED MATERIALS

From the shine of the stainless steel to the warmth of leather, or the soft-touch of silicon; we're committed to the finest materials available.



## HIGH LOAD CAPACITY

High-strength materials inside the hooks provide the high load capacity.



## Sugatsune America, Inc.

18101 Savarona Way

Carson, CA 90746

Phone: 310-329-6373

Toll Free: 800-562-5267

Fax: 310-329-0819

E-mail: [sales@sugatsune.com](mailto:sales@sugatsune.com)

## Chicago Showroom

121 West Wacker Drive #1007

Chicago, IL 60601

Phone: 312-461-1081

Fax: 312-461-1082

## Canada Office

3775 Boulevard du Tricentenaire

Montreal, Quebec H1B 5W3

Phone: 514-312-5267

Fax: 514-399-0538

E-mail: [support@sugatsune.ca](mailto:support@sugatsune.ca)

[www.sugatsune.com](http://www.sugatsune.com)

[www.sugatsune.ca](http://www.sugatsune.ca) (for Canada)

