

SPACE SHOULDN'T
DICTATE STYLE



www.sugatsune.com

Sugatsune America, Inc.

18101 Savarona Way
Carson, CA 90746

Phone: 310-329-6373

Toll Free: 800-562-5267

Fax: 310-329-0819

E-mail: sales@sugatsune.com

Chicago Showroom / Sales Office:

121 West Wacker Drive #1007

Chicago, IL 60601

Phone: 312-461-1081

Fax: 312-461-1082

Canada Offices

3775 Boulevard du Tricentenaire

Montreal, Quebec H1B 5W3

Phone: 514-312-5267

Fax: 514-399-0538

www.sugatsune.com

www.sugatsune.ca (for Canada)



LIT-LINX-MINI-2020

SUGATSUNE




LIN-X Series

Sugatsune LIN-X Series

Features


- Easy Installation with 4-Way Adjustability
- Space-Saving with Lateral Movement
- Full Access to Corner Cabinets
- Soft, Self-Closing Movement
- No Track or Rails Needed
- Allows Door and Cabinets to Stop Freely

Configurations

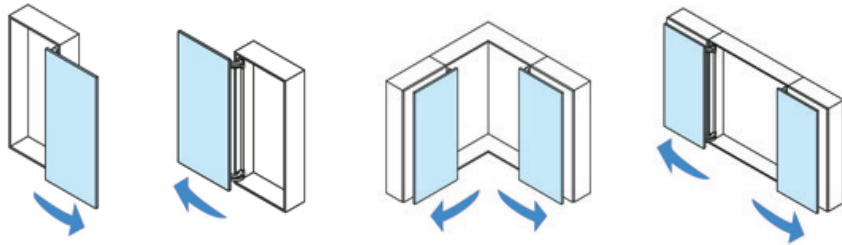


Movement

Standard Opening Movement

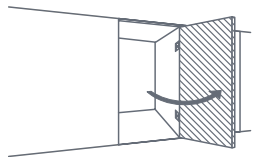

VS

Lateral Opening Movement

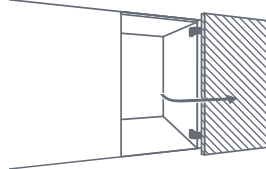

Which System Works Best for You?

For Cabinets

LIN-X450

Door Width: 15-3/4" ~ 19-11/16" (400~500 mm)
Door Height: Max. 94-1/2" (2400 mm)
Door Thickness: 5/8" ~ 15/16" (15~24 mm)
Door Weight: Max. 37.5 lbs (17kg) / Door

LIN-X600

Door Width: 21-5/8" ~ 25-9/16" (550~650 mm)
Door Height: Max. 94-1/2" (2400 mm)
Door Thickness: 5/8" ~ 15/16" (15~24 mm)
Door Weight: Max. 52.8 lbs (24kg) / Door

For Doors

LIN-X800/LIN-X800H

Door Width: 29-17/32" ~ 33 7/16" (750~850 mm)
Door Height: Max. 94-1/2" (2400 mm)/117-5/16" (2980 mm)
Door Thickness: 15/16" ~ 1-9/16" (24~40 mm)
Door Weight: Max. 88 lbs (40 kg) / Door

LIN-X1000

Door Width: 29-17/32" ~ 43-5/16" (750~1100 mm)
Door Height: Max. 117-21/64" (2980 mm)
Door Thickness: 15/16" ~ 1-37/64" (24~40 mm)
Door Weight: Max. 198 lbs (90 kg) / Door



Innovative,
Space-Saving,
& Unique
Applications