

ADJUSTABLE SOFT-DOWN STAY



NSD-10





- For DOWNWARD-OPENING FLAP DOOR with piano, butt or drop Hinges.
- NSD-10 is designed to hold door in closed position.
- Torque Calculation :
Torque = Door Height x 1/2 x Door Weight
Per Piece : 20~70 kg·cm (19~60 lbs·inch)
Per Pair : 40~140 kg·cm (38~120 lbs·inch)

Material	Finish
Zinc Alloy, Steel	Bright Nickel



PAT

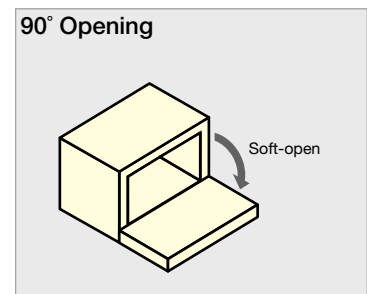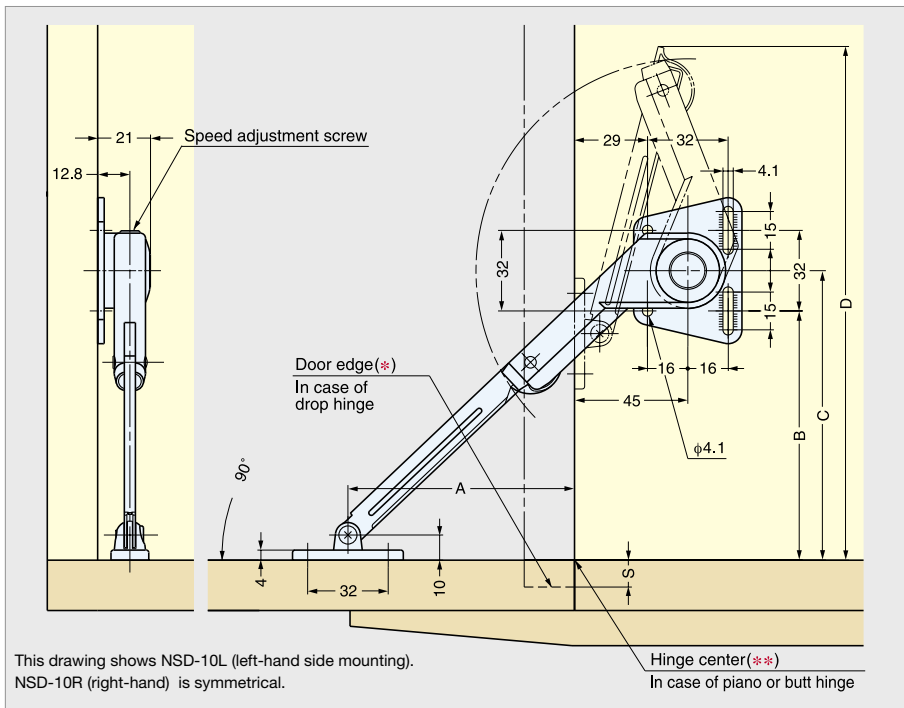

The distance for A, B, C is measured from "door edge (*)" and "top surface of bottom board" when drop hinges are used, and from "hinge center (**)" and "top surface of bottom board" when piano or butt hinges are used.

Hinge Type	A	B	C	D
Drop Hinge	97(3-13/16")	106 (4-11/64") -S	122 (4-51/64") -S	211 (8-5/16") -S
Piano / Butt Hinge	90(3-35/64")	99 (3-57/64")	115 (4-17/32")	204 (8-1/32")

Note: "S" dimension is the overlay distance for drop hinge(s).

Item No.	Weight (g)	Box (pcs)	Carton (pcs)
NSD-10R	210	20	80
NSD-10L	210	20	80