

HEAVY DUTY SOFT-DOWN STAY




HDS-10




- For DOWNWARD-OPENING FLAP DOOR with piano, butt or drop hinges.
- HDS-10 is designed to hold door in closed and opened position.
- Used in pairs
- Torque Calculation :
 $Torque = Door\ Height \times 1/2 \times Door\ Weight$
 K-Type (Light Duty) : 140~200 kg-cm (121~173 lbs-inch) / pair
 M-Type (Medium Duty) : 200~250 kg-cm (173~216 lbs-inch) / pair
 H-Type (Heavy Duty) : 250~300 kg-cm (216~260 lbs-inch) / pair

With Piano / Butt Hinge

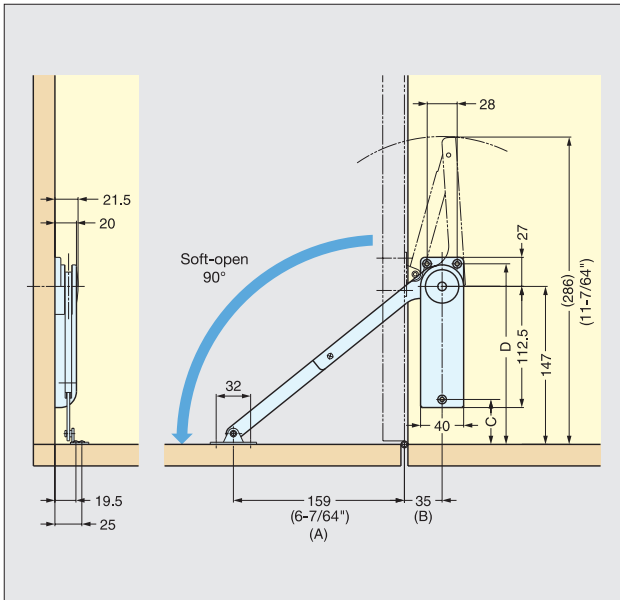

With Drop Hinge (SDH-001)

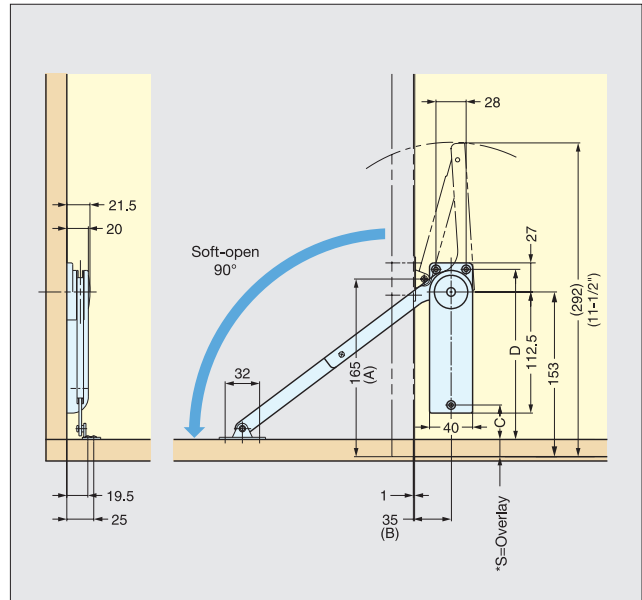

*S=Overlay coverage in case of drop hinge

Item No.		Type	Torque (kg-cm/pair)	Weight (g)	Box (pcs)	Carton (pcs)
Left	Right					
HDS-10KL	HDS-10KR	Light Duty	140~200	290	40	200
HDS-10ML	HDS-10MR	Medium Duty	200~250	290		
HDS-10HL	HDS-10HR	Heavy Duty	250~300	310		

Hinge Type	A	B	C	D
Drop Hinge	165	35	48-S	174-S
Piano / Butt Hinge	159		42	168
Material		Finish/Color		
Steel		Nickel		
Plastic		Black, White		