



## FULL EXTENSION SLIDE

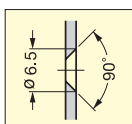

# AR3

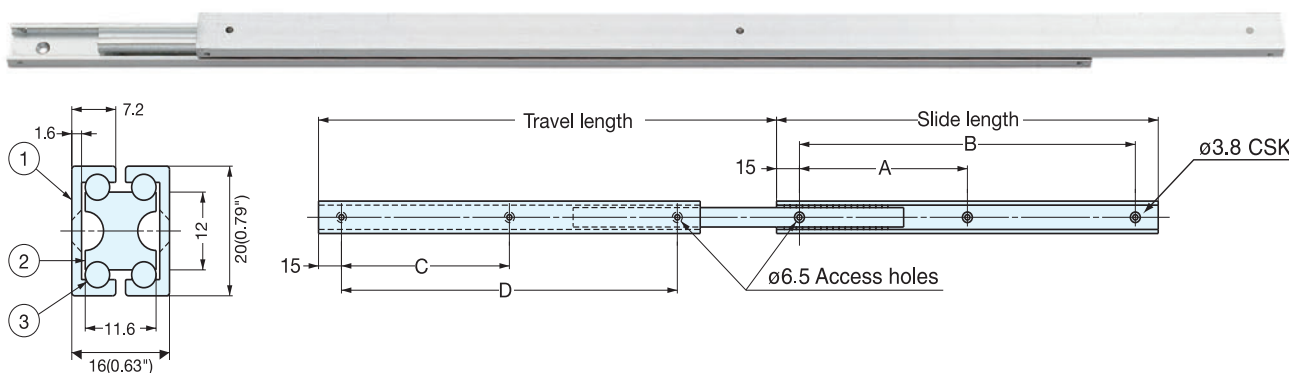

Hole Dimension (Outer Rail)

- Full extension
- Positive stop
- Non-handed

25.4mm=1"



No.	Part	Material	Finish
①	Outer Rail	Aluminum	White Anodized
②	Inner Rail		
③	Balls	Steel	-

Item No.	Slide Length	Travel Length	A	B	C	D	Load Rating (kg/pair)	Weight (g)	Box (pcs)
AR3-100	100 ( 3-15/16" )	100 ( 3-15/16" )	-	70	-	70	14.5 (32 lbs)	63	30
AR3-200	200 ( 7-7/8" )	223 ( 8-25/32" )	85	170	85	170	14.5 (32 lbs)	128	
AR3-300	300 ( 11-13/16" )	345 ( 13-19/32" )	135	270	135	270	14 (31 lbs)	194	
AR3-400	400 ( 15-3/4" )	460 ( 18-7/64" )	185	370	135	370	13 (29 lbs)	260	20
AR3-500	500 ( 19-11/16" )	576 ( 22-43/64" )	235	470	235	470	12 (27 lbs)	325	

## 3/4 EXTENSION SLIDE



## AR2

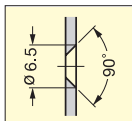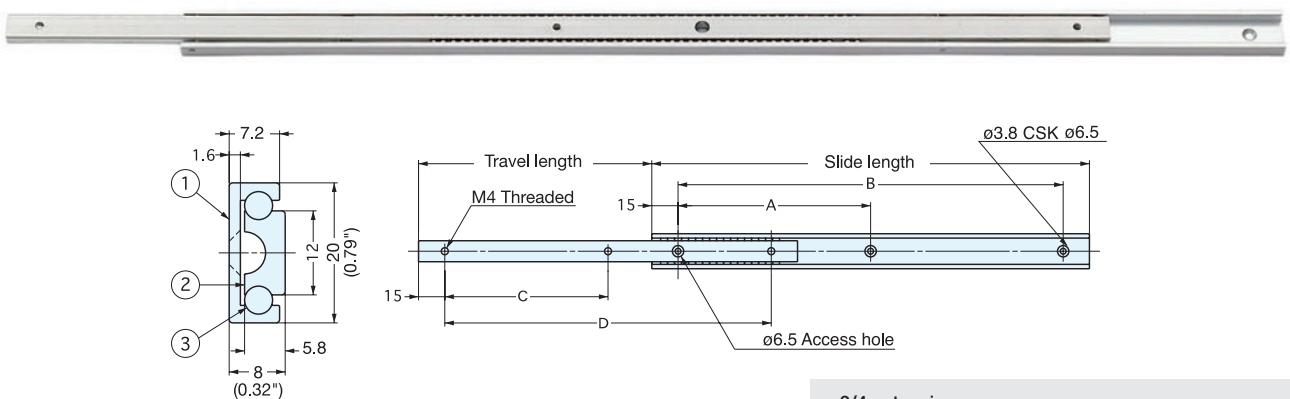

Hole Dimension (Outer Rail)

- 3/4 extension
- Positive stop
- Non-handed

25.4mm=1"

No.	Part	Material	Finish
①	Outer Rail	Aluminum	White Anodized
②	Inner Rail		
③	Balls	Steel	-

Item No.	Slide Length	Travel Length	A	B	C	D	Load Rating (kg/pair)	Weight (g)	Box (pcs)
AR2-100	100 ( 3-15/16" )	60 ( 2-23/64" )	-	70	-	70	18 (40 lbs)	31	50
AR2-200	200 ( 7-7/8" )	120 ( 4-23/32" )	85	170	85	170	18 (40 lbs)	63	
AR2-300	300 ( 11-13/16" )	180 ( 7-5/64" )	135	270	135	270	16.5 (36 lbs)	76	
AR2-400	400 ( 15-3/4" )	240 ( 9-29/64" )	185	370	135	370	15 (35 lbs)	129	
AR2-500	500 ( 19-11/16" )	300 ( 11-13/16" )	235	470	235	470	13 (30 lbs)	161	