
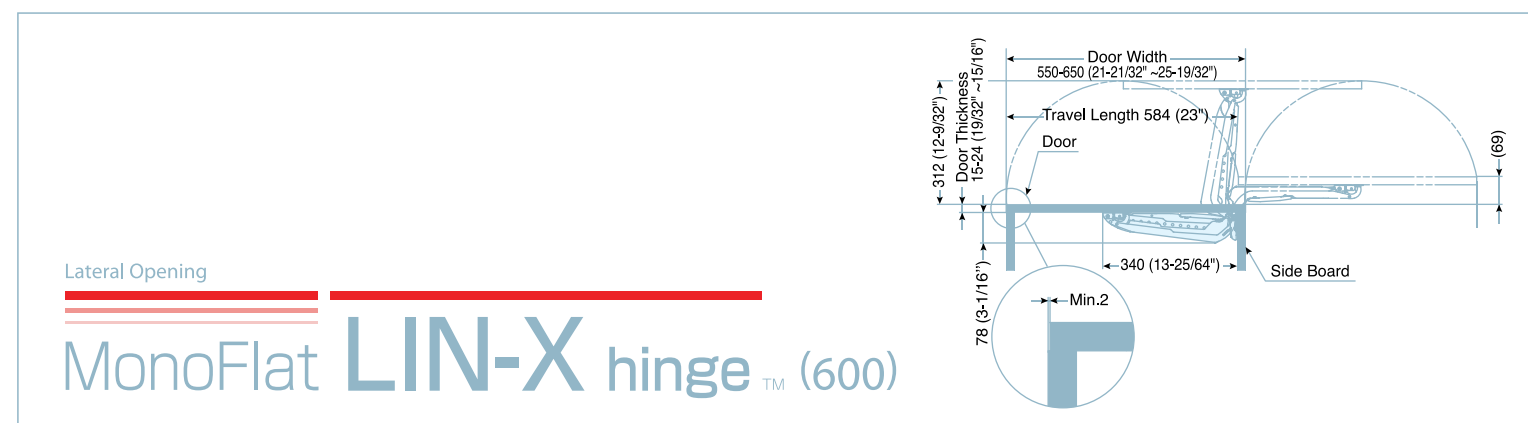
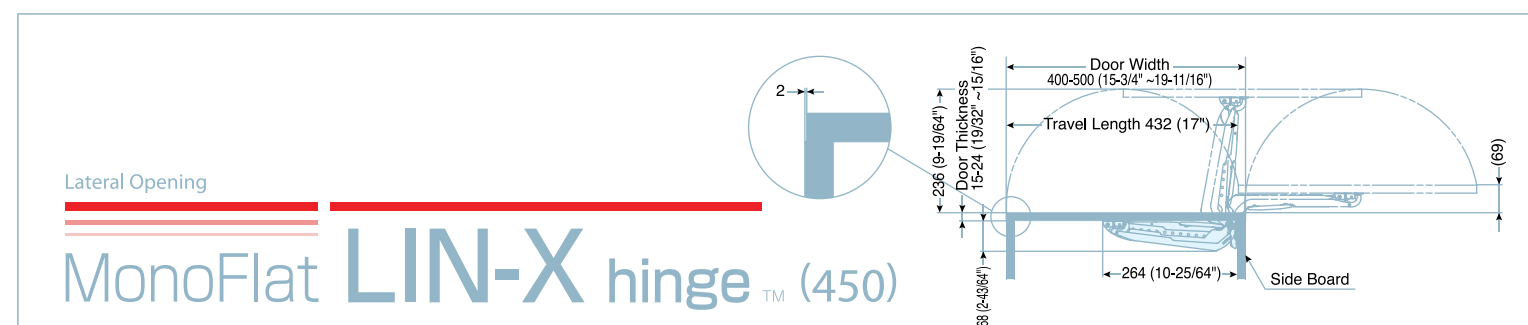
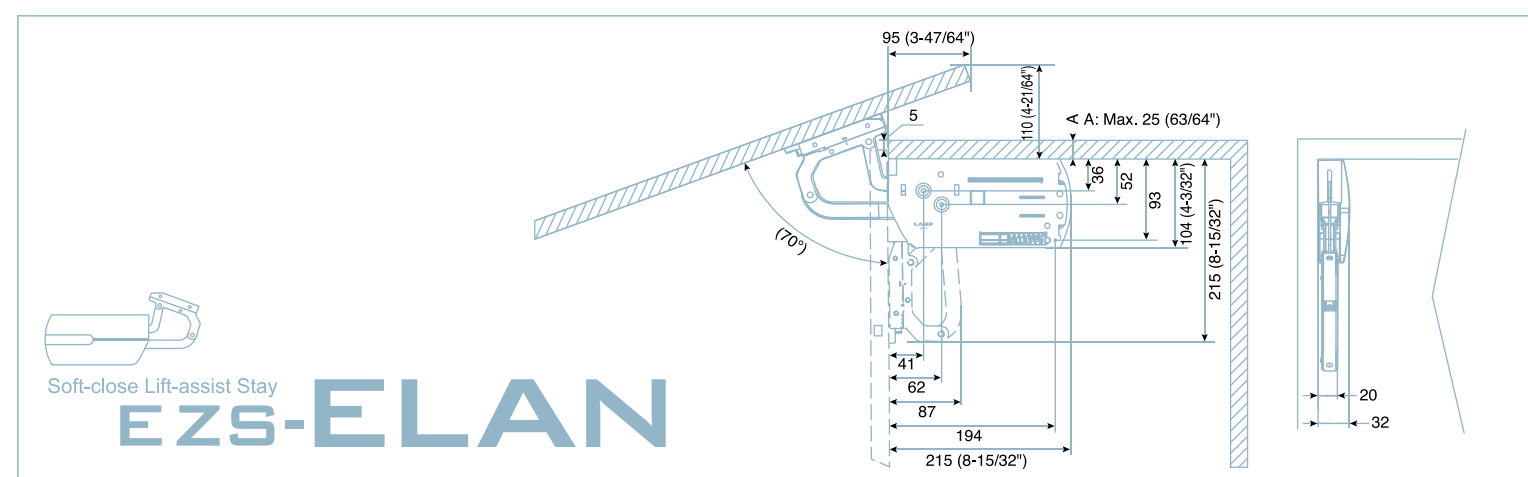


PRODUCT SIZE INFORMATION

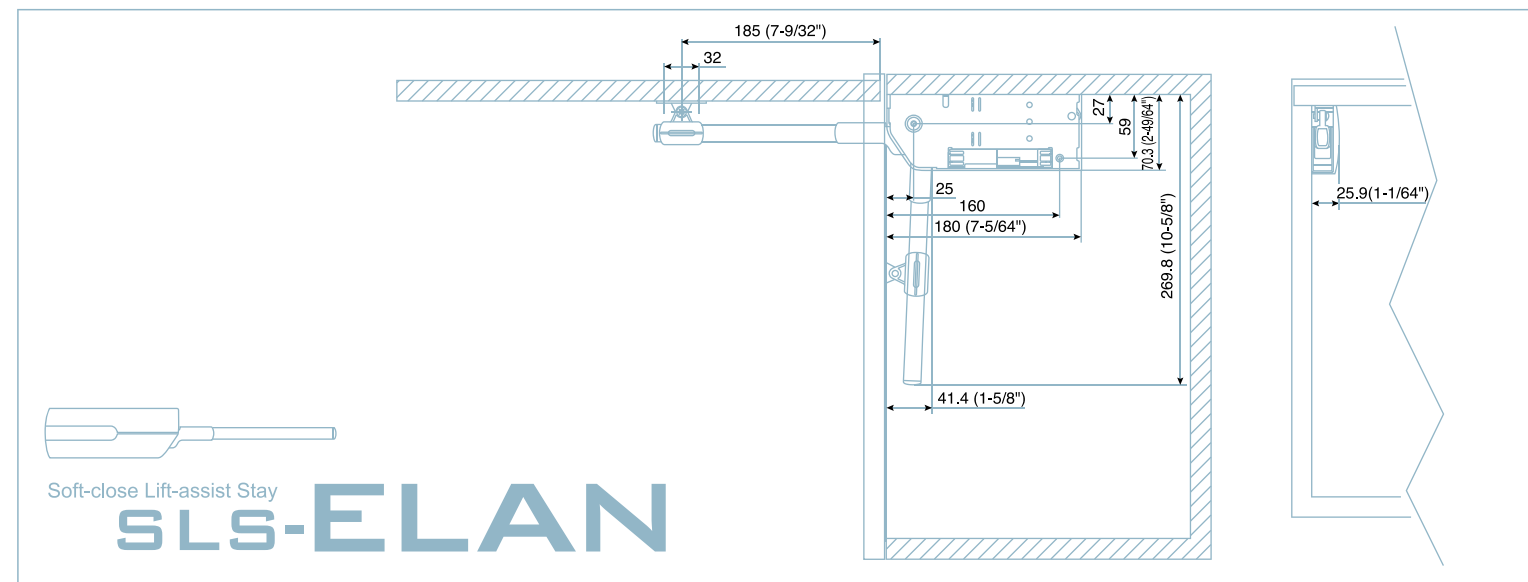

**SUGATSUNE**

**INNOVATIVE DOOR SYSTEMS**

Lateral Opening Hinge







Soft-close Lift-assist Stay

Soft-close Lift-assist Stay


# SLS-ELAN



## INSTALLATION

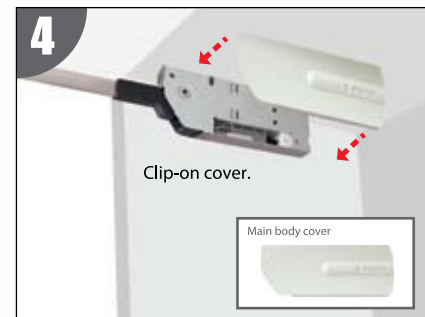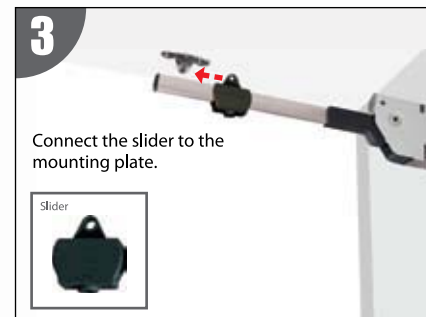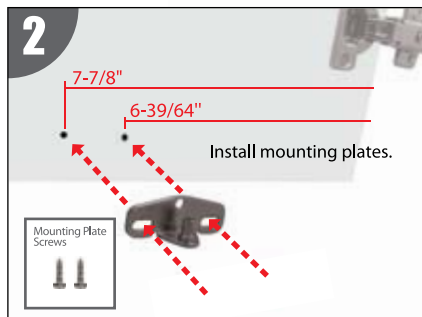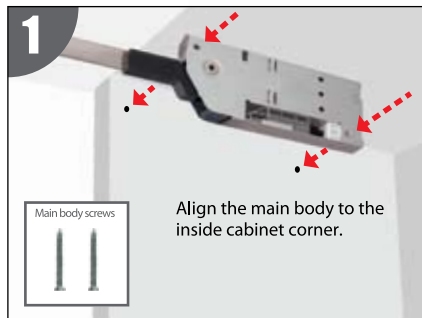

**FINISH**

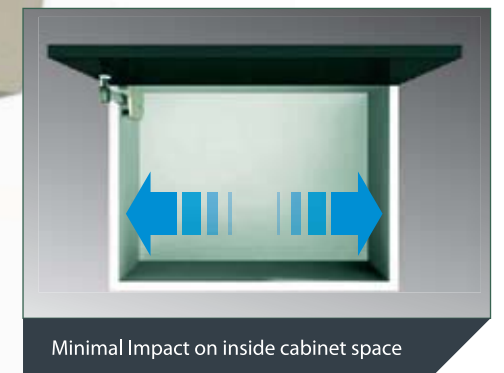

## FEATURES

Multi Function Stay for Upward-opening flap doors.

3 functions on 1 stay - Lift-assist / Free stop / Soft close.

Easy Installation


Simply align the body to the inside cabinet corner and attach using only 2 screws.

Slim design allows maximum space inside cabinet.

Application flexibility

Lift mechanism supports a variety of door (s) sizes in single or pair configuration.

## DOOR SIZE RANGES


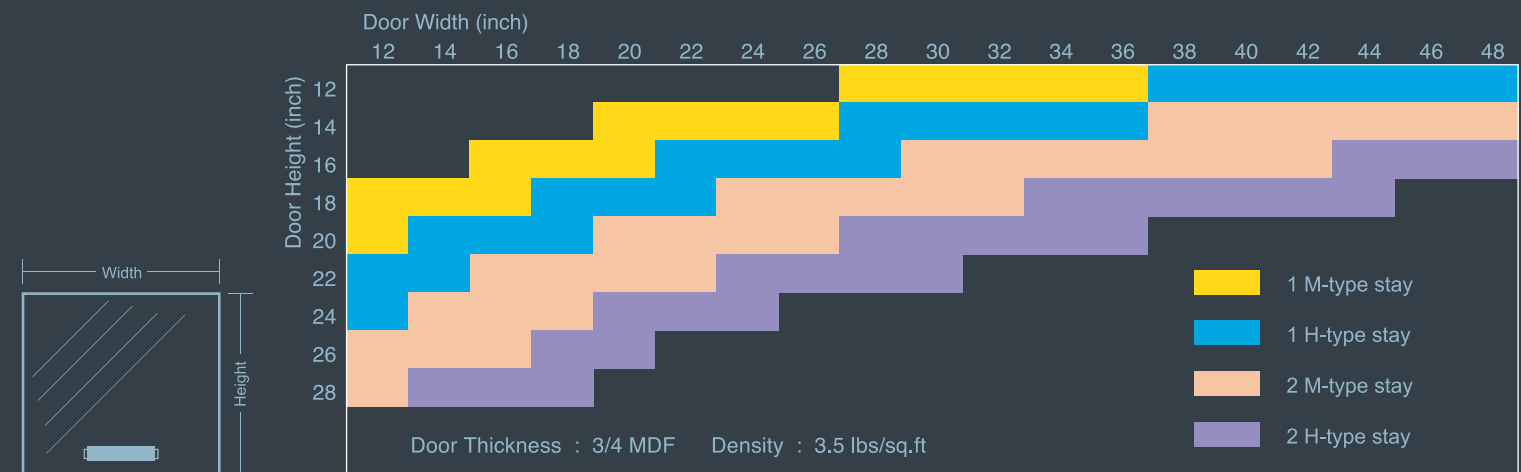


Soft-close Lift-assist Stay

# EZS-ELAN



## INSTALLATION

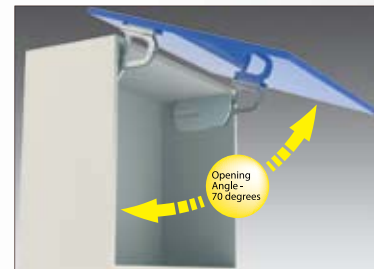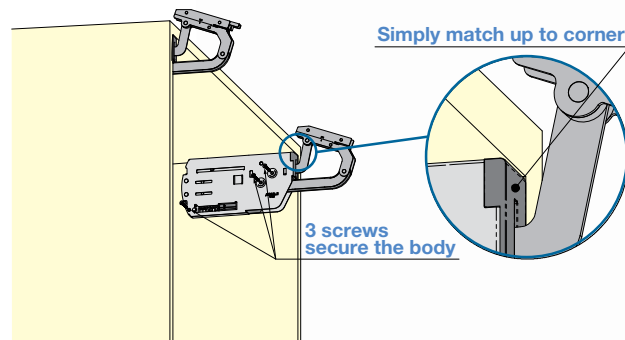


## SPECIFICATIONS


Door Width	23-1/2" ~ 47-1/4"
Door Height	19-43/64" ~ 29-17/32"
Door Weight	11 ~ 27.5lbs
Horizontal adjustability	± 3/64"
Vertical adjustability	± 5/64"

## FEATURES

- Multi Function Stay for Upward-opening flap doors  
3 function on 1 stay (Free stop / Lift assist / Soft close)
- Easy Installation  
Simply align and attach the body to the inside cabinet corner
- Minimal range of motion above the cabinet (4-21/64")
- No connecting bar or hinges are required
- Application flexibility  
Lift mechanism supports a variety of door (s) sizes
- Slim design allows maximum space inside cabinet

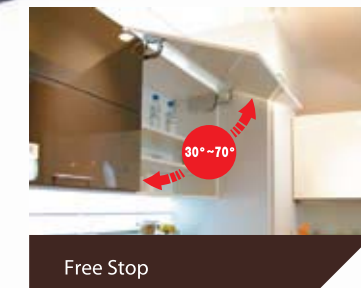


## DOOR SIZES RANGES

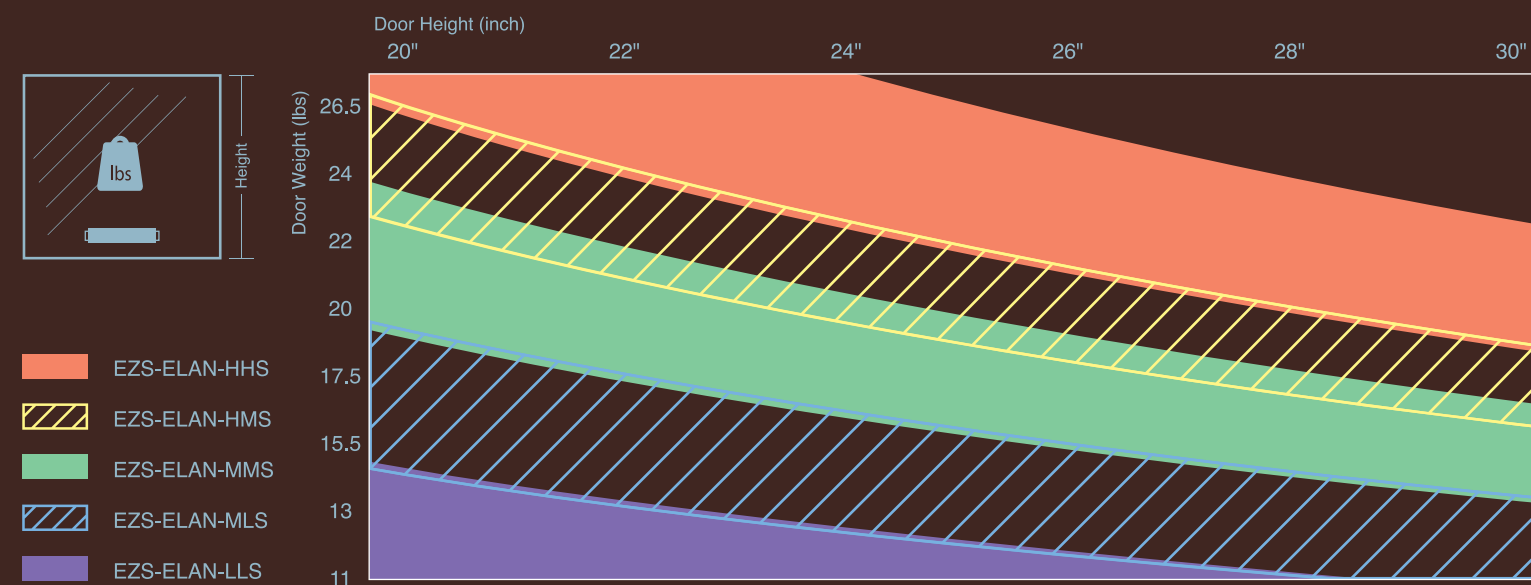





Lateral Opening

# MonoFlat LIN-X hinge™

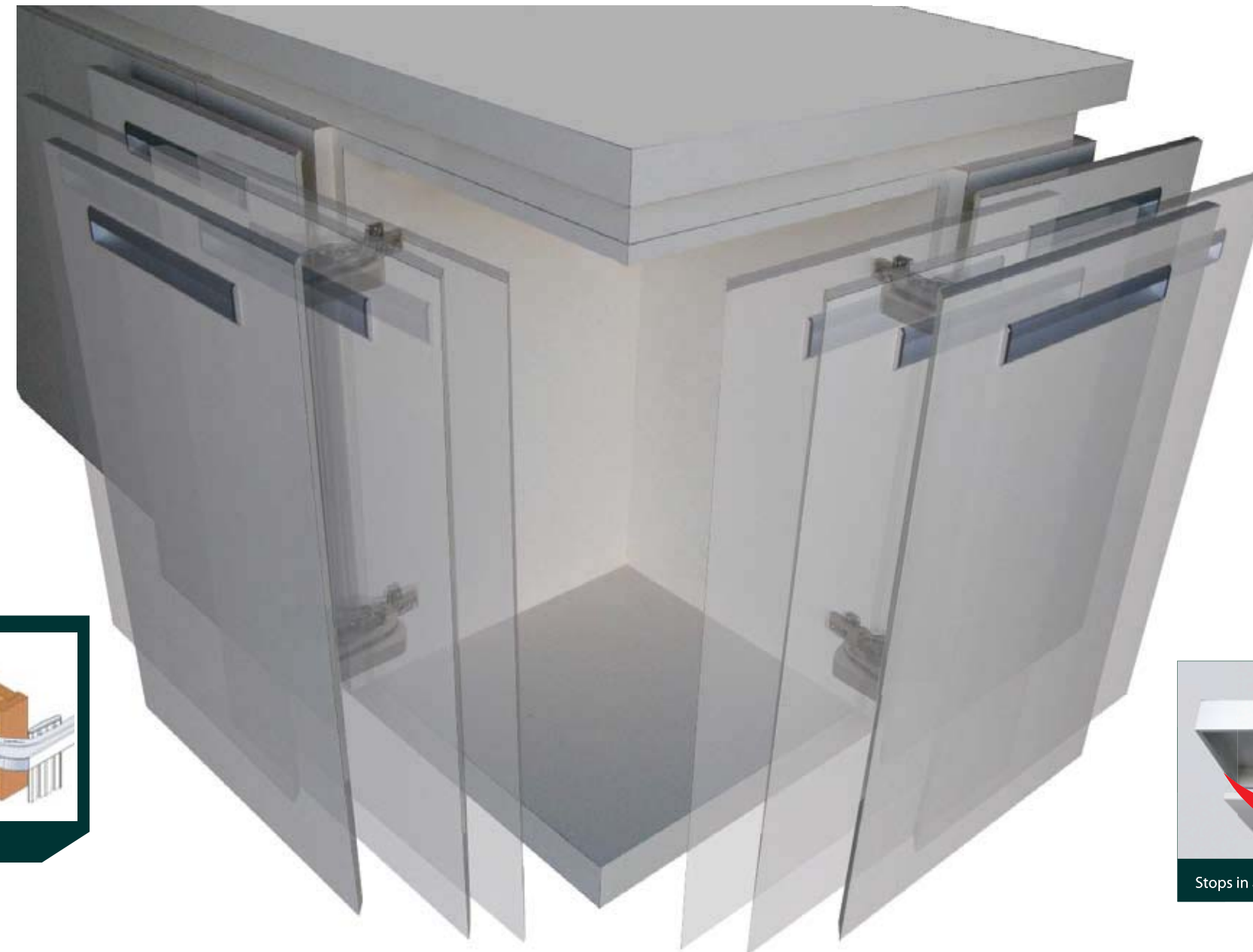

## INSTALLATION

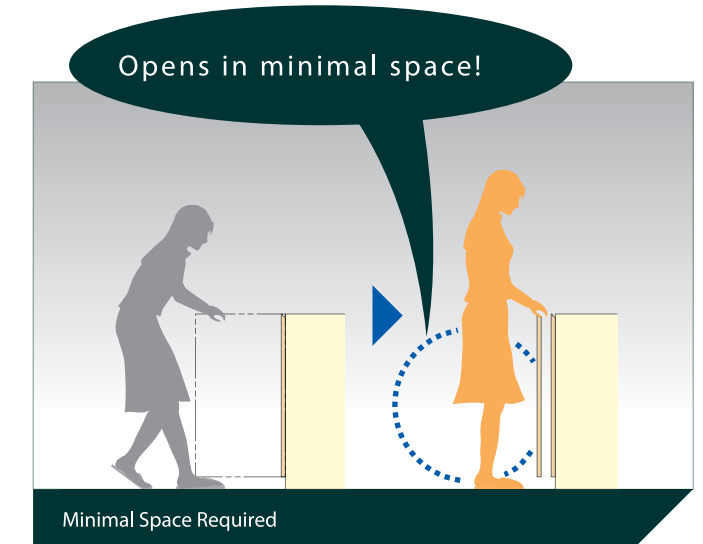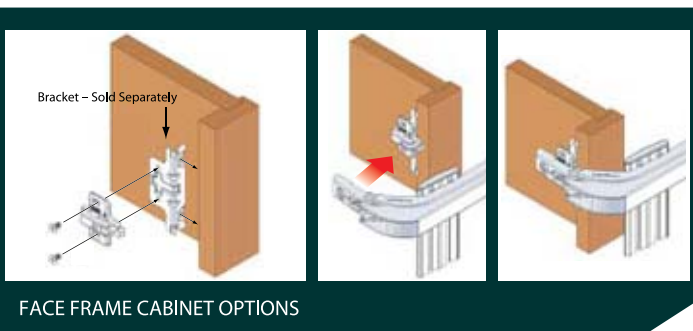

## FEATURES

- Lateral Opening      Allows doors to swing out laterally in small radius, ideal for tight front space applications
- Easy Installation      Snap-In installation on 32 pitch mounting plate
- Free Stop / Soft Closing
- Door can be pulled open from any position
- Maximum Space Availability
- Fully Adjustability
- Space Saving

## APPLICABLE DOOR SIZE

	LIN-X450			LIN-X600	
	Standard	Custom Set		Standard	Custom Set
Door Width	15-3/4" ~ 19-11/16"		Door Width	21-21/32" ~ 25-19/32"	
Door Height	23-5/8" ~ 35-7/16"	23-5/8" ~ 94-1/2"	Door Height	23-5/8" ~ 35-7/16"	23-5/8" ~ 94-1/2"
Door Thickness	19/32" ~ 61/64"		Door Thickness	19/32" ~ 61/64"	
Door Weight	Max. 15.4 lbs	Max. 37.4 lbs	Door Weight	Max. 19.8 lbs	Max. 52.8 lbs