

Yes, it is
Stainless Steel
& it Closes Softy



SUGATSUNE

 SPECIALTY HINGES: Stainless Steel

sugatsune.com




STAINLESS STEEL CONCEALED SOFT-CLOSE HINGE




- Full stainless steel fabrication (excluding damper unit) allows the hinge to be used in outdoor environments.
- Successfully completed 500 hrs. of ISO9227 salt spray testing.
- Overlay: 9/16" ~ 3/4" (15 ~ 19mm).
- Door Thickness: 9/16" ~ 13/16" (15 ~ 20mm).
- 3-Way Adjustable (overlay, depth, vertical).
- Self-closing version helps to firmly close door.
- Soft-close version prevents the door from slamming shut.
- Durable, successfully passed 30,000 cycle test.
- Easily clips on and off the mounting plate. (sold separately).

Item No.	Feature	Door Thickness	Weight (g)	Carton (pcs)
180SUS-D46-19T	Soft Close Damper	9/16" ~ 13/16" (15 ~ 20mm)	60	200
180SUS-C46-19T	Self-Close			


Material	Finish
304 Stainless Steel	Polished

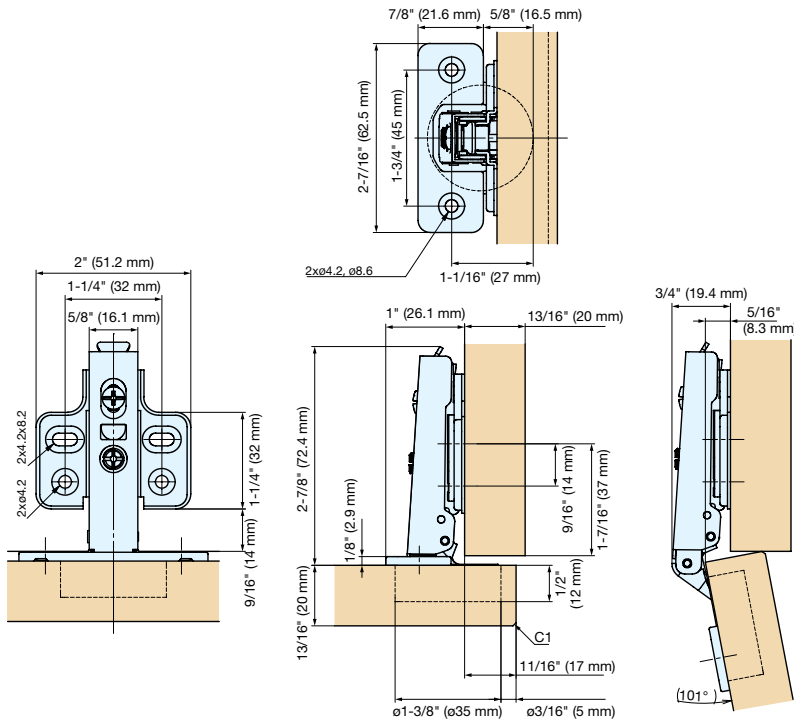


Locus Chart

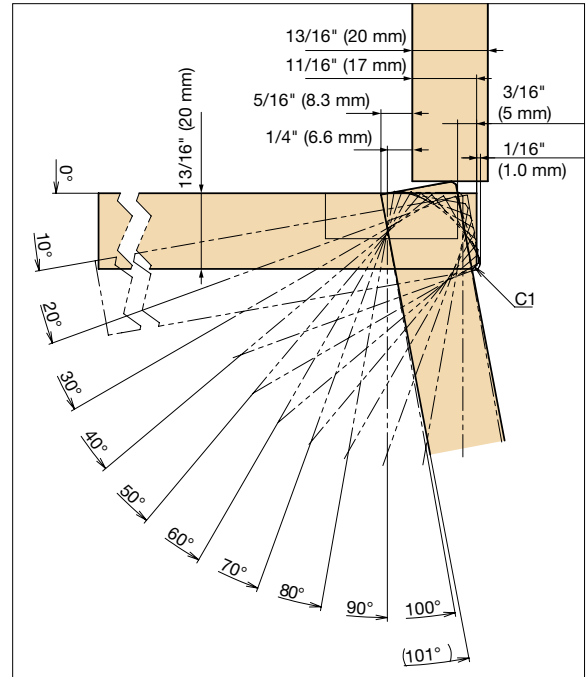

Recommended Hinge Quantity

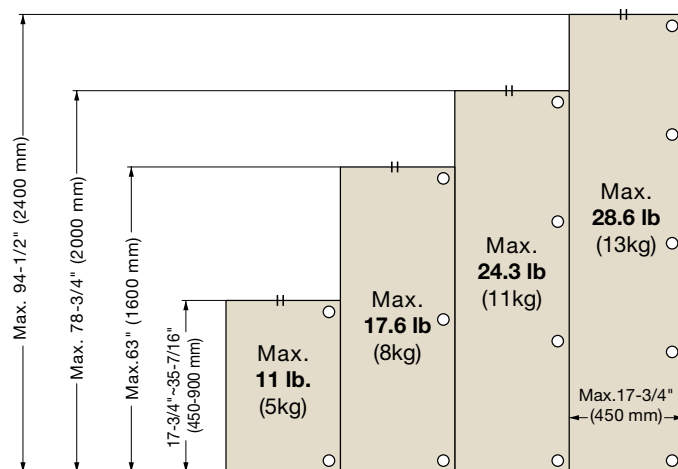

Bore Dimensions

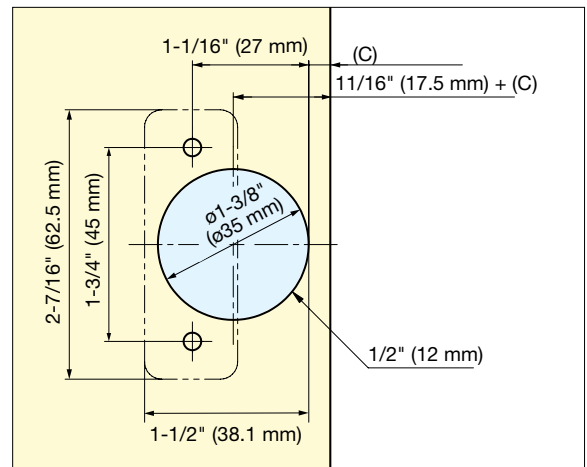


STAINLESS STEEL MOUNTING PLATE



- Full STAINLESS STEEL fabrication
- To be used with 180SUS-C46-19T and 180SUS-D46-19T

Item No.	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
180SUS-P6T	79	60	200	304 Stainless Steel	Polished

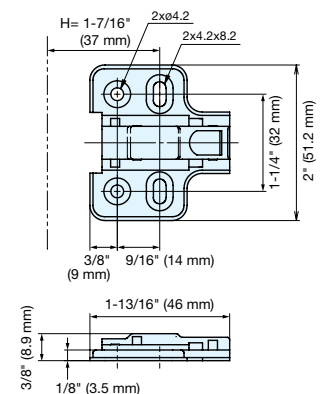

OTHER CONCEALED CUP HINGES

304B SERIES Stainless Steel



Available in Free swinging and Self-closing. Polished finish. Materials: 304 Stainless Steel. The Series is NSF Approved Component



304B-46/19
19 mm overlay
Opening angles: 100°



304B-46/14
14 mm overlay
Opening angles: 100°



304B-46/9
9 mm overlay
Opening angles: 100°



Mounting Plates for 304B Series Hinge
304B-P3A, 304-P4A/32, 304B-P4A/32-3W

J95 SERIES Heavy Duty



Heavy Duty, can hold up to 55 lbs/2 hinges 88 lbs/3 hinges.

Available in Free swinging and Self-closing, Nickel and Black finishes. Materials: Zinc Alloy and Steel.



J95-24/25T
25 mm overlay
Opening angles: 95°



J95-24/25T
16 mm overlay
Opening angles: 95°



J95-24/25T
Inset
Opening angles: 95°



J95ZC, J95SC
Plate and Hinge Covers
in gray, black and chrome



**HG-J95FP,
GH-J95FP-Q1**
Glass face plates available

OLYMPIA SERIES with 5 Speed Adjustable Soft-Close



Available in soft close (5 levels), Free swinging, Self-closing and Self-opening.



Olympia 360-D26-19T
19 mm overlay
Opening angles: 105° or 85°. (Thick door hinge available with 26 mm overlay H360-26-26T)



Olympia 360-D26-14T
14 mm overlay
Opening angles: 105° or 85°. (Thick door hinge available with 16 mm overlay H360-26-16T)



Olympia 360-D26-9T
9 mm overlay
Opening angles: 105° or 85°.



Olympia 360-26-0T
Inset
Opening angle: 93°. (Thick door hinge available H360-26-0T)



ACCESSORIES
Covers, Spacers, stoppers and brackets available.

LIT-180SUS-2024



We understand that your craftsmanship is important to you, our concealed cup hinges are designed and manufactured to the highest standards to bring your designs to life. From stainless steel, soft-closing to heavy duty hinges that can hold up to 88 lbs doors, Sugatsune specializes in hardware that will enhance and elevate your spaces.

Visit [sugatsune.com](https://www.sugatsune.com) for more information on more than 6,000 high quality products.

[sugatsune.com](https://www.sugatsune.com)



1.800.562.5267