


EDGE PULL



SN

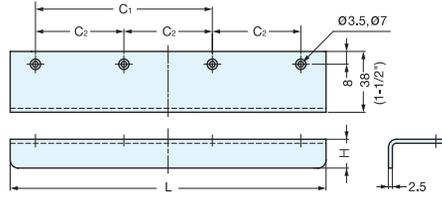

Available in 3 finishes. Please specify finish when ordering.


Material	Finish
304 Stainless Steel	Mirror (M)
	Satin (S)
	Black (BL)

Item No.			L	C ₁	C ₂	H	Holes	Weight (g)	Box (pcs)	Carton (pcs)
SN-50/M*	SN-50/S*	SN-50/BL	50 (1-31/32")	30 (1-3/16")	-	18 (11/16")	2	47	40	400
SN-70/M*	SN-70/S*	SN-70/BL	70 (2-3/4")	46 (1-13/16")	-			65	30	300
SN-95/M*	SN-95/S*	SN-95/BL	95 (3-47/64")	65 (2-9/16")	-		90	20	200	
SN-120/M*	SN-120/S*	-	120 (4-23/32")	90 (3-35/64")	45		112			
SN-150/M*	SN-150/S*	-	150 (5-29/32")	114 (4-31/64")	57		147	15	150	
SN-200/M	SN-200/S	-	200 (7-7/8")	112 (4-13/32")	56		200			
SN-300/M	SN-300/S	-	300 (11-13/16")	180 (7-3/32")	90		300	10	40	

* NSF Component

EDGE PULL

SNB

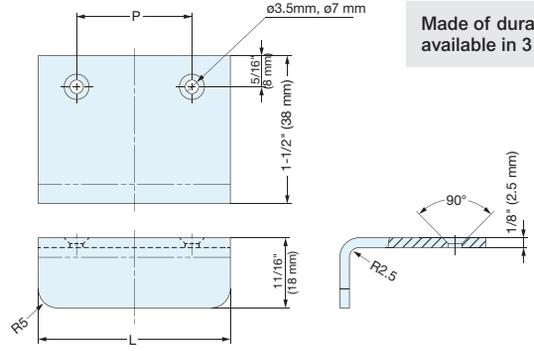



Made of durable brass available in 3 finishes

Item No.			L	P	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
SNB-50/BB	SNB-50/SB	SNB-50/AB	50 (1-31/32")	30 (1-3/16")	50	20	200	Brass	Bright Brass (BB)
SNB-70/BB	SNB-70/SB	SNB-70/AB	70 (2-3/4")	46 (1-13/16")	70	20	100		Satin Brass (SB)
SNB-95/BB	SNB-95/SB	SNB-95/AB	95 (3-47/64")	65 (2-9/16")	95	20	100		Antique Brass (AB)

EDGE PULL



SND

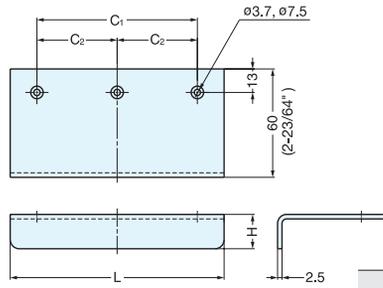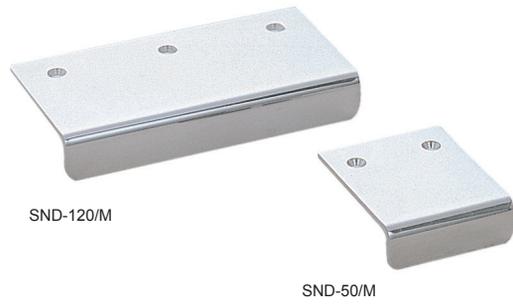

Material	Finish
304 Stainless Steel	Mirror

Item No.	L	C ₁	C ₂	H	Weight (g)	Box (pcs)	Carton (pcs)
SND-50/M*	50 (1-31/32")	30 (1-3/16")	-	17 (43/64")	67	10	200
SND-70/M*	70 (2-3/4")	46 (1-13/16")	-	18 (45/64")	95		
SND-95/M*	95 (3-47/64")	65 (2-9/16")	-	19 (3/4")	130		
SND-120/M	120 (4-23/32")	90 (3-35/64")	45		166	5	50
SND-150/M	150 (5-29/32")	114 (4-31/64")	57		208		

* NSF Component