


# DOOR HANDLE

STAINLESS  
304  
STEEL

## DSI-4400

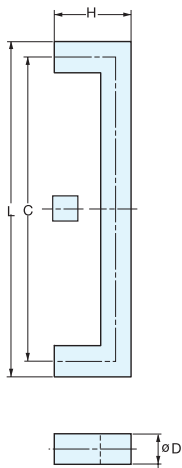

- For use with DSI mounting kits (sold separately, See P.10).
- Please specify Interior/Exterior type when ordering:
  - Posts for Exterior handles are threaded to accept screws.
  - Posts for Interior handles have set screws for DSI mounting kits.
- Similar style to KPH series cabinet handles. (P.45)


Material	Finish
304 Stainless Steel	Satin

Item No.		D	L	C	H	Weight (kg)		Box (pcs)	Carton (pcs)
Interior	Exterior					Interior	Exterior		
DSI-4400-15-15I	DSI-4400-15-15E	15	165 ( 6-1/2" )	150 ( 5-29/32" )	55 (2-3/16")	0.41 (0.9 lbs)	0.42 (0.9 lbs)	1	10
DSI-4400-15-20I	DSI-4400-15-20E		215 ( 8-1/2" )	200 ( 7-7/8" )		0.48 (1.1 lbs)	0.50 (1.1 lbs)		
DSI-4400-15-30I	DSI-4400-15-30E		315 ( 12-3/8" )	300 (11-13/16")		0.67 (1.5 lbs)	0.68 (1.5 lbs)		
DSI-4400-20-20I	DSI-4400-20-20E	20	220 ( 8-11/16" )	200 ( 7-7/8" )	65 (2-9/16")	0.18 (0.4 lbs)	0.23 (0.5 lbs)		
DSI-4400-20-25I	DSI-4400-20-25E		270 ( 10-5/8" )	250 ( 9-27/32" )		0.22 (0.5 lbs)	0.24 (0.5 lbs)		
DSI-4400-20-30I	DSI-4400-20-30E		320 ( 12-5/8" )	300 (11-13/16")		0.26 (0.6 lbs)	0.26 (0.6 lbs)		
DSI-4400-30-25I	DSI-4400-30-25E	30	280 ( 11" )	250 ( 9-27/32" )	90 (3-9/16")	0.56 (1.2 lbs)	0.59 (1.3 lbs)		
DSI-4400-30-30I	DSI-4400-30-30E		330 ( 12" )	300 (11-13/16")		0.51 (1.1 lbs)	0.50 (1.1 lbs)		
DSI-4400-30-35I	DSI-4400-30-35E		380 (14-15/16")	350 (13-25/32")		0.71 (1.6 lbs)	0.57 (1.3 lbs)		
DSI-4400-30-60I	DSI-4400-30-60E		630 (24-13/16")	600 ( 23-5/8" )		1.09 (2.4 lbs)	1.09 (2.4 lbs)		

# DOOR HANDLE

STAINLESS  
304  
STEEL

## DSI-1630

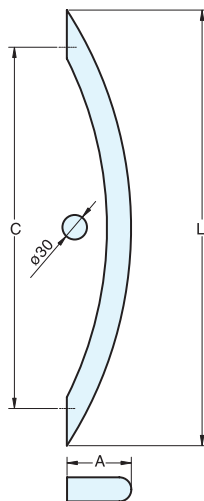

- For use with DSI mounting kits (sold separately, See P.10).
- Please specify Interior/Exterior type when ordering:
  - Posts for Exterior handles are threaded to accept screws.
  - Posts for Interior handles have set screws for DSI mounting kits.
- Similar style to 30 series cabinet handles. (P.38)



Material	Finish
304 Stainless Steel	Satin

Item No.		L	C	A	Weight (kg)	Box (pcs)	Carton (pcs)
Interior	Exterior						
DSI-1630-30-25I	DSI-1630-30-25E	314 ( 12-3/8" )	250 ( 9-7/8" )	66 ( 2-19/32" )	0.8 (1.8 lbs)	1	10
DSI-1630-30-35I	DSI-1630-30-35E	430 (16-15/16")	350 ( 13-3/4" )	74 ( 2-29/32" )	1.2 (2.7 lbs)		
DSI-1630-30-45I	DSI-1630-30-45E	542 ( 21-5/16" )	450 ( 17-3/4" )	80 ( 3-5/32" )	1.5 (3.3 lbs)		
DSI-1630-30-60I	DSI-1630-30-60E	721 ( 28-3/8" )	600 ( 23-5/8" )	79 ( 3-7/64" )	1.8 (4.0 lbs)		