


3-WAY ADJUSTABLE CONCEALED HINGE

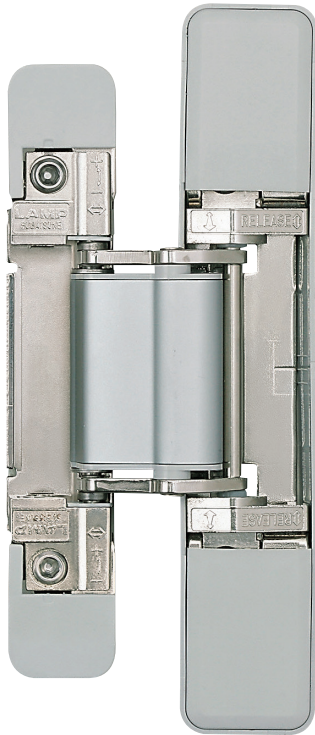

HES3D-V135LGR-2





HES3D-V135LGR-2

- 3-WAY adjustment function allows vertical, horizontal, and depth adjustment after hinge installed.
- Easy installation and adjustment.
- Successfully passed 300,000 open/close private cycle tests.
- Supplied with steel button head screw.
- Door weight: Max. 40 kg (88 lbs)/2 pcs, 55 kg (122 lbs)/3 pcs
- Door Thickness: Min. 30 mm (1-3/16")
- Max. Door Size: H 2400 mm × W 900 mm (H 94-1/2" × W 35-7/16")


Item No.	Finish/Color
HES3D-V135LGR-2	Light Gray

Item No.	Weight (g)	Box (pcs)	Carton (pcs)
HES3D-V135LGR-2	400	2	24

No.	Part Name	Material	Finish/Color
①	Body	Steel	Nickel
②	Base Frame	Polyacetal	Light Gray
③	Arm	Aluminum	Anodized
④	Pin	Steel	Nickel
⑤	Cover	Polyacetal	Light Gray
⑥	Block	Zinc Alloy	Nickel

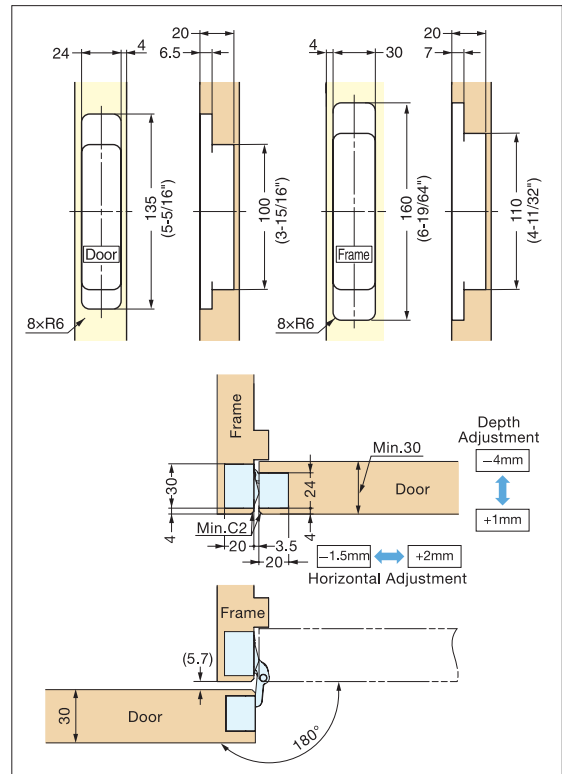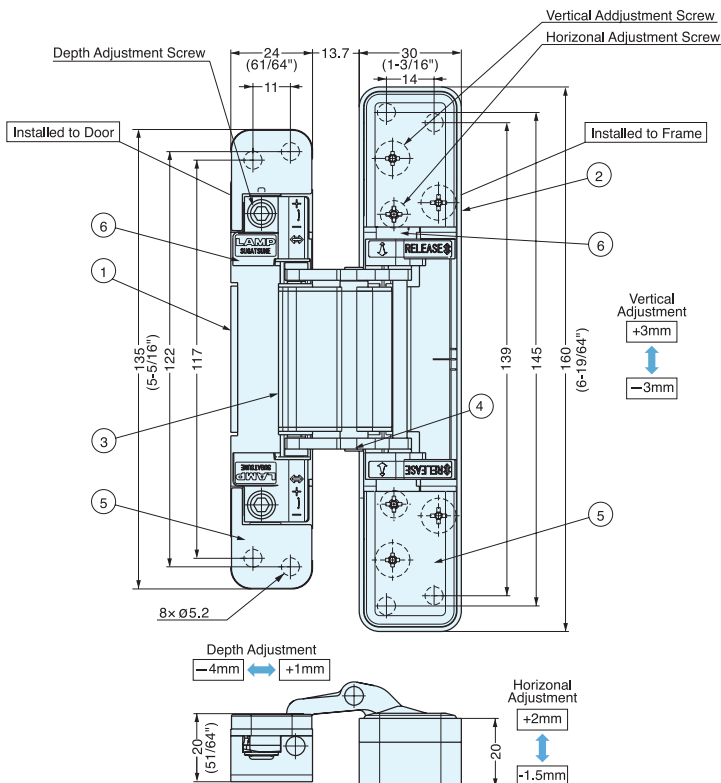

Bore Dimensions

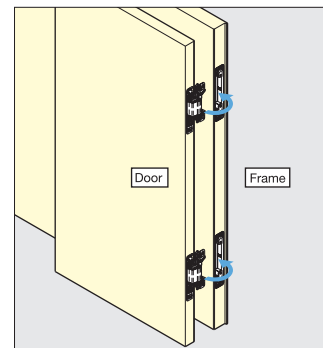

Installation