

Zwei L Lift-Off Hinge




ZL-1701

HINGES




Zwei L LIFT-OFF HINGES



ZL-1701-10

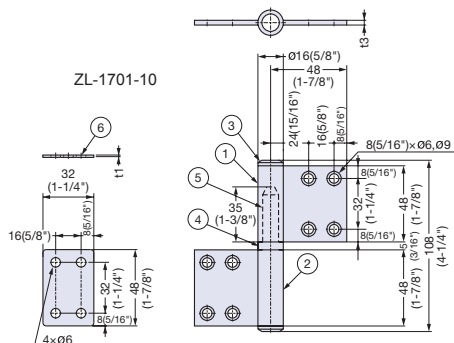

ZL-1701-12

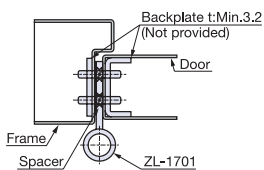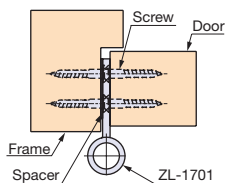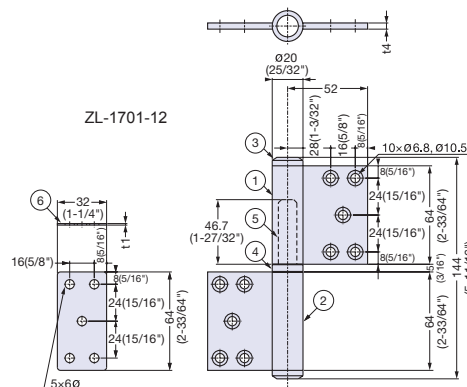

No.	Part Name	Material	Finish/Color
①	Door Side Hinge Plate	316 Stainless Steel	Zwei L
②	Frame Side Hinge Plate		
③	Head Cap		Satin
④	Washer		
⑤	Pin		
⑥	Spacer		

ZL-1701-10: Supplied with stainless steel wood screws (4.1 × 38) and stainless steel screws (M5 × 16, ø8 Head)

ZL-1701-12: Supplied with stainless steel wood screws (4.8 × 38) and stainless steel screws (M5 × 16, ø9 Head)

Item No.	Load Capacity (kg)	Weight (g)	Box (pcs)
ZL-1701-10	40(88 lbs)/2pcs	380	8
ZL-1701-12	50(110 lbs)/2pcs	430	



HEAVY DUTY CLEAN ROOM LIFT-OFF HINGE




HG-CV127



HG-CV127/R

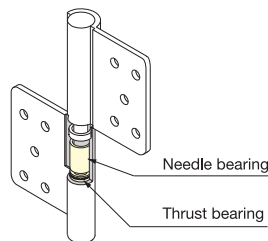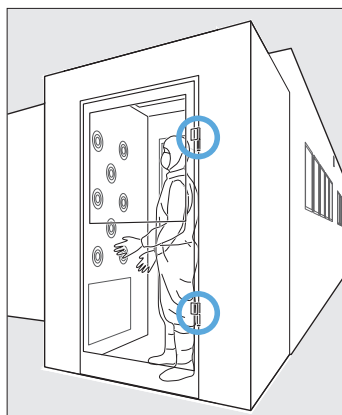

- No metal-to-metal contact.
- Special bearings minimize particles.
- Successfully passed 200,000 open cycle test at the following door size.
 - Door Weight: MAX. 100 kg/pair (220 lbs/pair)
 - Door Height: MAX. 2,000 mm (78-3/4")
 - Door Width: MAX. 900 mm (35-7/16")

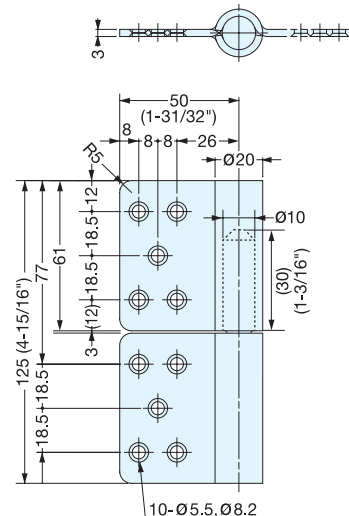

Item No.	Weight (g)	Box (pcs)	Carton (pcs)
HG-CV127/L	388	5	50
HG-CV127/R			

Material	Finish
304 Stainless Steel	Satin/Polished