


# OVERLAY DOOR ANGLE HINGE






## AHA-24

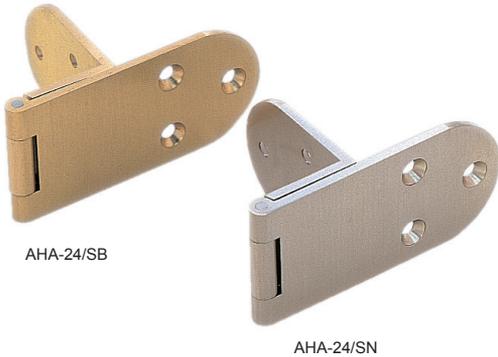

AHA-24/SB

AHA-24/SN

- Recommended Door Specifications:  
 Thickness: Recess Mount-27 mm (1-1/16"); Surface Mount-24.5 mm (1")  
 Width: Max. 450 mm (17-3/4")  
 Height: Max. 700 mm (27-9/16")  
 Weight: Max. 2.6 kg (5.7 lbs) per pair

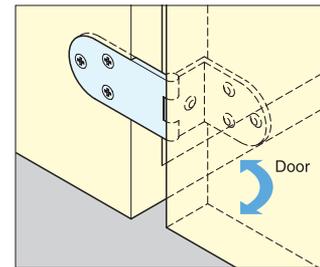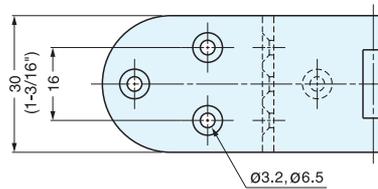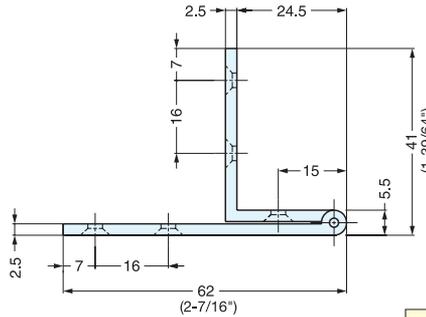

Item No.		Weight (g)	Box (pcs)	Carton (pcs)
AHA-24/SB	AHA-24/SN	70	50	200

Material	Finish
Brass	Satin Brass (SB) Satin Nickel (SN)

# OVERLAY DOOR ANGLE HINGE






## AHB-18



AHB-18/SB

AHB-18/SN

- Recommended Door Specifications:  
 Thickness: Recess Mount-21 mm (13/16"); Surface Mount-18 mm (11/16")  
 Width: Max. 450 mm (17-3/4")  
 Height: Max. 700 mm (27-9/16")  
 Weight: Max. 2.6 kg (5.7 lbs) per pair

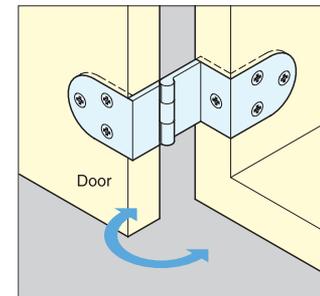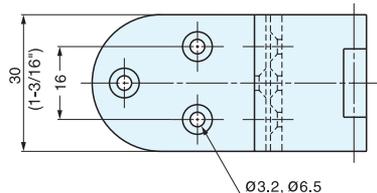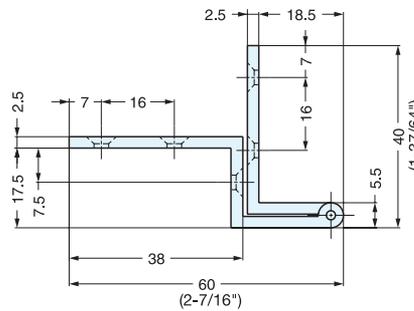

Item No.		Weight (g)	Box (pcs)	Carton (pcs)
AHB-18/SB	AHB-18/SN	76	50	200

Material	Finish
Brass	Satin Brass (SB) Satin Nickel (SN)