



ROTARY DAMPER




URD8-3



- 360 degree rotary damper.
- Cylindrical shape for concealed application.
- For inset applications.

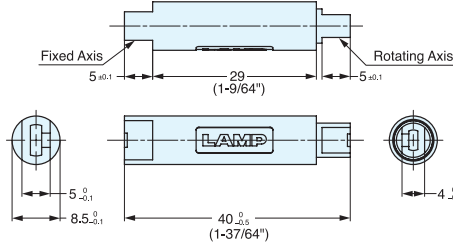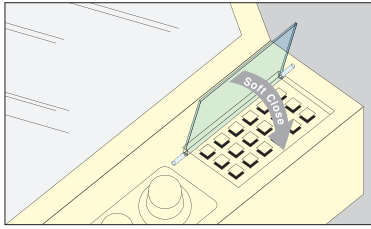

Cut-Out Dimension


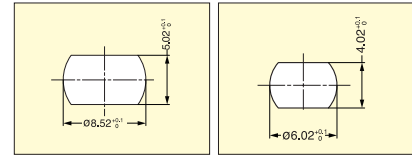


Item No.	Material	Finish	Torque per piece (kgf·cm)	Weight (g)
URD8-3	Polyacetal	Plain	0.22~0.39 (0.19~0.26 lbs·in)	2.5



MICRO DETENT HINGE




MPH

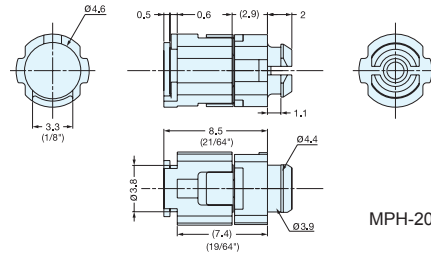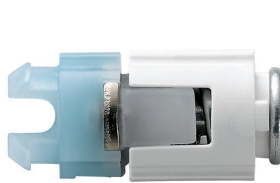

MPH-20-5

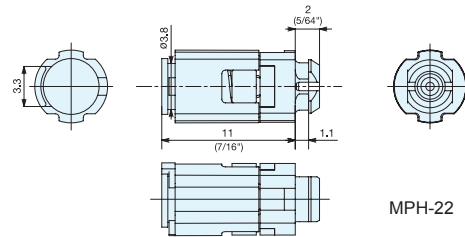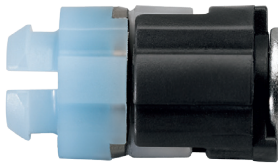

MPH-22

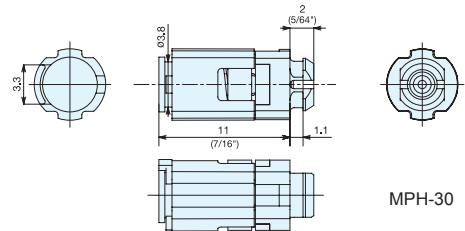

MPH-30

Item No.	Weight (g)	Carton (pcs)	Part Name	Material	Finish
MPH-20-5	0.46 (0.02 oz)	4000	Body	Polyacetal	Grey
MPH-22	0.62 (0.02 oz)		Spindle	Steel	Yellow Zinc Chromate
MPH-30	1.01 (0.04 oz)				