

SOFT-CLOSE HINGE



HG-JHW / HG-JHWG

HINGES


SOFT-CLOSE HINGES




- Soft-Close damper keeps lid from slamming shut.
- Surface mount type.
- Two different damper direction available for various application.
- Operating temperature: 0~40°C (32~104°F)
- Operating angle: 115°/Dead angle 5°

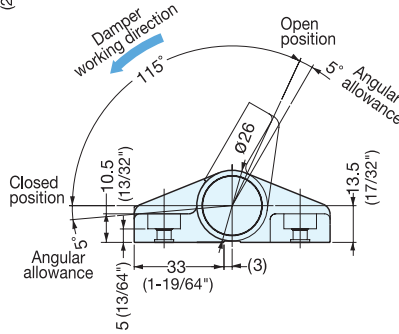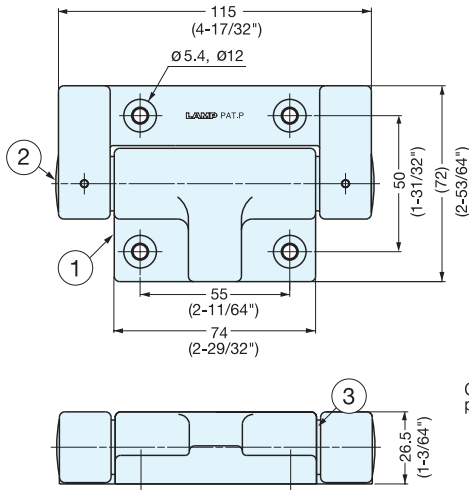


HG-JHW

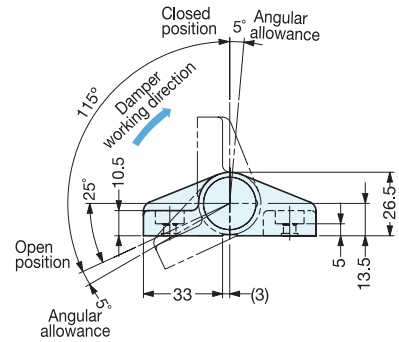

HG-JHWG

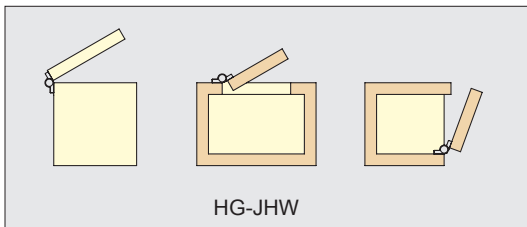

Installation

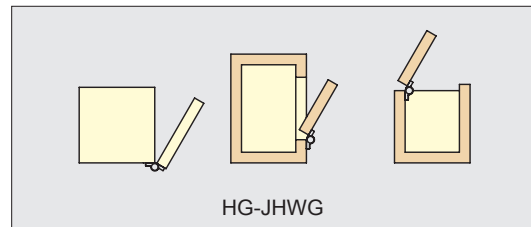

HG-JHW

HG-JHWG

| Item No. | Torque per pair (kgf·cm) | Weight (g) | Box (pcs) | Carton (pcs) |
|-----------|---------------------------|------------|-----------|--------------|
| HG-JHW50 | 61~102 (53~88 lbs·in) | 200 | 4 | 64 |
| HG-JHW70 | 102~143 (88~124 lbs·in) | | | |
| HG-JHWG50 | 61~102 (53~88 lbs·in) | | | |
| HG-JHWG70 | 102~143 (88~124 lbs·in) | | | |

| No. | Part Name | Material | Color |
|-----|-----------|------------------------|-----------|
| ① | Bracket | PBT Plastic/Zinc Alloy | Dark Grey |
| ② | Cap | Polypropylene | |
| ③ | Damper | 304 Stainless Steel | Plain |

* Sold per piece.