

GLASS HINGE (INSET)

GS-GH5

HINGES

GLASS SHOWCASE HARDWARE



Chrome (CR)

24K Gold Plated (GP)




Black (BL)

Parts Included


- Hinge for inset glass door for glass showcase.
- Can be used together with glass bracket GS-GB5 (below) and lock GS-GL5.
- Temporary holding feature allows for easy installation of the door by one person.
- Sideways adjustment (± 2.5 mm) possible after installation of the door.
- Gap below door is adjustable from 3 mm to 5 mm with washers.
- Sold in pairs.

Installation drawings

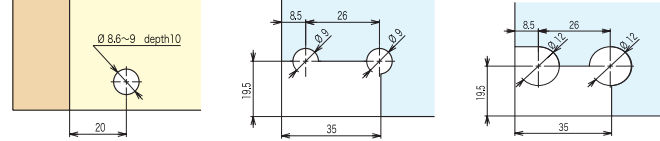

Top and bottom panel

Door

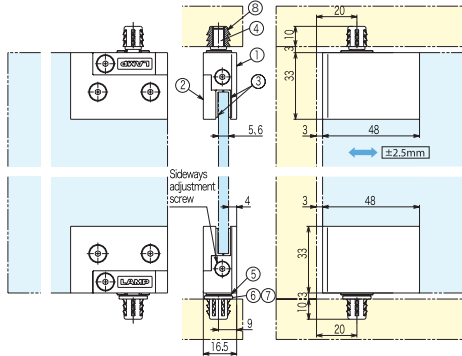

No.	Part Name	Material	Finish
①	Body	Zinc Alloy	Chrome, Black, 24K Gold Plated
②	Back Plate		
③	Gasket	Chloroprene Rubber	Black
④	Axis	Stainless Steel	Plain
⑤	Plastic Washer	Polyamide	Black
⑥	Washer (t: 1.5)	304 Stainless Steel	Plain
⑦	Washer (t: 3.5)	Brass	Nickel
⑧	Insert	Zinc Alloy	-

Item Name	Door Width	Door Height	Door Weight	Glass Thickness	Finish
GS-GH5-CR	Max. 17-3/4" (450 mm)	Max. 23-5/8" (600 mm)	11 lbs/2 pcs (5 kg/2 pcs)	Min. 3/16", 1/4" (5, 6 mm)	Chrome
GS-GH5-GP					Gold Plated
GS-GH5-BL					Black

SURFACE MOUNTING BRACKET




GS-GH5-MU




- Specially designed for use with the GS-GH5 glass hinge.
- Can be simply installed with screws without recessing.
- Comes with a spacer which can increase the gap below doors from 1/8 to 3/16" (3 to 5 mm).
- Sold as a set: two brackets and one spacer.


Bracket

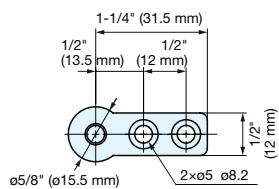


Spacer

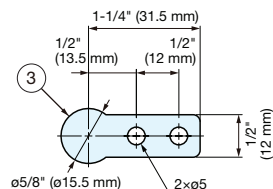


Installation

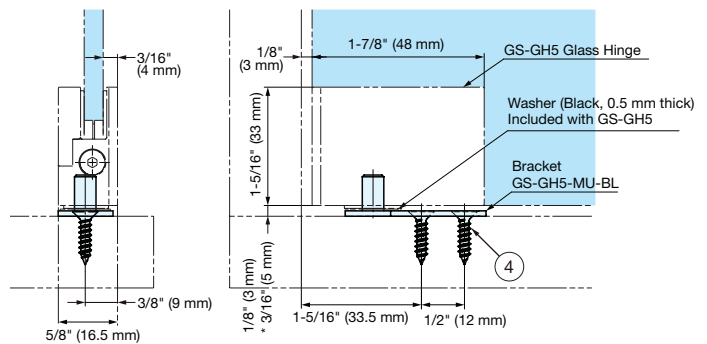

* Indicates the dimensions when the spacer is attached.

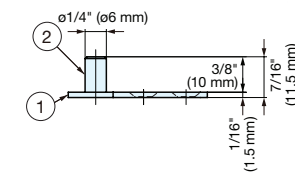

Bracket and Spacer

 

Item No.	Box (pcs)	Carton (pcs)
GS-GH5-MU-BL	40	360

No.	Part Name	Material	Finish
①	Strike Plate	430 Stainless Steel	Enamel Black
②	Shaft	303 Stainless Steel	Plain
③	Spacer	POM	Black
④	Included Screw	Stainless Steel	Enamel Black