

HEAVY DUTY SOFT-DOWN STAY



HDS-10


LID SUPPORTS

HEAVY DUTY SOFT-DOWN STAYS




- For DOWNWARD-OPENING FLAP DOOR used with piano, butt or drop hinges (SDH-001, SDH-P, P.238).
- HDS-10 is designed to hold door in closed and opened position.
- Used in pairs
- Torque Calculation:
Torque = Door Height × 1/2 × Door Weight
- K-Type (Light Duty):
140~200 kg·cm (121~173 lbs·inch)/pair
- M-Type (Medium Duty):
200~250 kg·cm (173~216 lbs·inch)/pair
- H-Type (Heavy Duty):
250~300 kg·cm (216~260 lbs·inch)/pair

With Piano/Butt Hinge

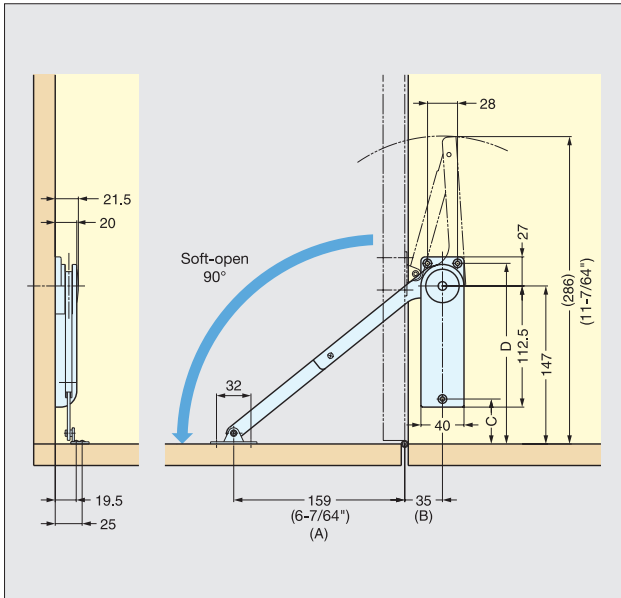

With Drop Hinge (SDH-001)

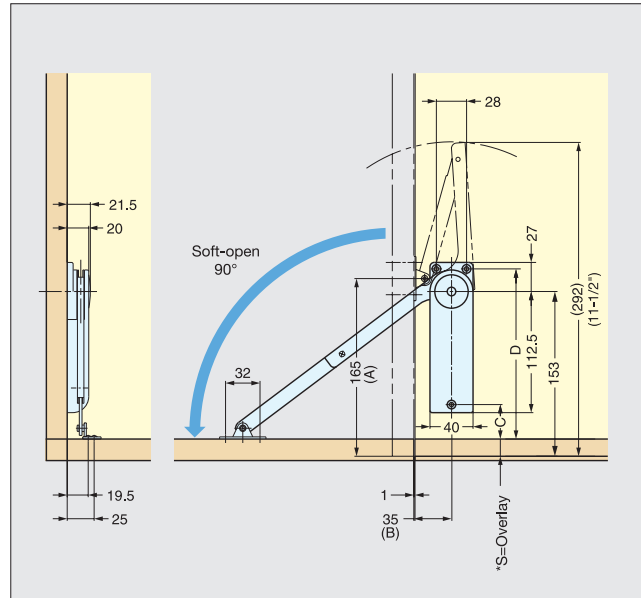

*S=Overlay coverage in case of drop hinge

Item No.		Type	Torque (kg·cm/pair)	Weight (g)	Box (pcs)	Carton (pcs)
Left	Right					
HDS-10KL	HDS-10KR	Light Duty	140~200	290	40	200
HDS-10ML	HDS-10MR	Medium Duty	200~250			
HDS-10HL	HDS-10HR	Heavy Duty	250~300			

Hinge Type	A	B	C	D
Drop Hinge	165	35	48-S	174-S
Piano/Butt Hinge	159		42	168
Material		Finish/Color		
Steel		Nickel		
Plastic		Black, White		