


HANDLE



FB

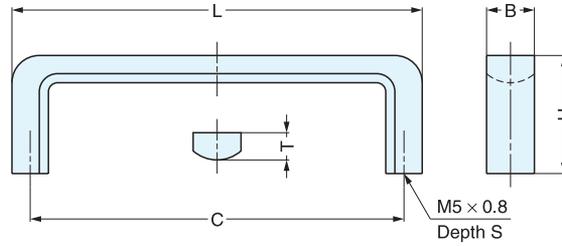

FB-110 only is RoHS compliant.

Material	Finish
304 Stainless Steel	Mirror

Item No.	L	C	H	B	T	S	Weight (g)	Box (pcs)	Carton (pcs)
FB-90	90	82 (3-7/32")	26 (1-1/32")	10.5	6	10	45	35	280
FB-110	110	102 (4-1/64")	28 (1-7/64")	12.5	7	12	60	25	200
FB-130	130	120 (4-23/32")	32 (1-17/64")	14.5	8	14	93	20	160

HANDLE




KB



KB-90/M

KB-30/S

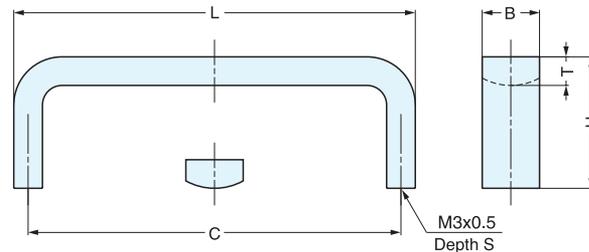

Material	Finish
303 Stainless Steel	Mirror (M) Satin (S)

Item No.	L	C	H	B	T	S	Weight (g)	Box (pcs)	Carton (pcs)	
KB-30/M	KB-30/S	30	25 (63/64")	23 (29/32")	10	5	8	18	40	400
KB-50/M	KB-50/S	50	45 (1-25/32")	22 (7/8")			10	26	30	300
KB-70/M	KB-70/S	70	65 (2-9/16")	22.5 (57/64")			10	33	20	200
KB-90/M	KB-90/S	90	85 (3-11/32")	23 (29/32")			10	40		

HANDLE




KS



Satin

Mirror

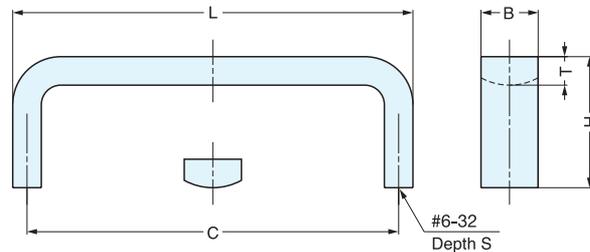

Material	Finish
304 Stainless Steel	Mirror (M) Satin (S)

Item No.	L	C	H	B	T	S	Weight (g)	Box (pcs)	Carton (pcs)
KS-430/M	KS-430/S	81	76 (3")	23 (29/32")	10	5	45	20	200
KS-435/M	KS-435/S	94	89 (3-1/2")				48		
KS-440/M	KS-440/S	106	102 (4")				54		