



FULL EXTENSION SLIDE



AR3

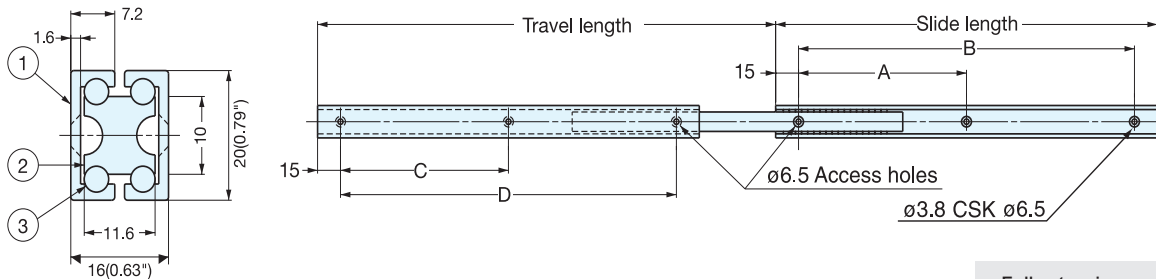

- Full extension.
- Positive stop.
- Non-handed.
- Sold by each.

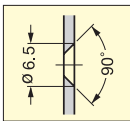

Hole Dimension (Outer Rail)

25.4 mm=1"


No.	Part	Material	Finish
①	Outer Rail	Aluminum	Anodized
②	Inner Rail		
③	Balls	Steel	-

Item No.	Slide Length	Travel Length	A	B	C	D	Load Rating (kg/pair)	Weight (g)	Box (pcs)
AR3-100	100 (3-15/16")	100 (3-15/16")	-	70	-	70	11.2 (25 lbs)	63	30
AR3-200	200 (7-7/8")	223 (8-25/32")	85	170	85	170	9.2 (20 lbs)	128	
AR3-300	300 (11-13/16")	345 (13-19/32")	135	270	135	270	7.1 (16 lbs)	194	
AR3-400	400 (15-3/4")	460 (18-7/64")	185	370	185	370	5.1 (11 lbs)	260	20
AR3-500	500 (19-11/16")	576 (22-43/64")	235	470	235	470	3.1 (7 lbs)	325	


3/4 EXTENSION SLIDE



AR2

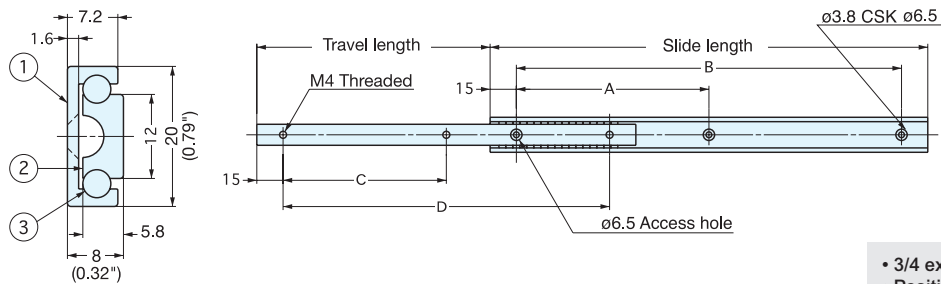

- 3/4 extension.
- Positive stop.
- Non-handed.
- Sold by each.

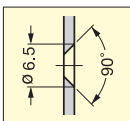

Hole Dimension (Outer Rail)

25.4 mm=1"

No.	Part	Material	Finish
①	Outer Rail	Aluminum	Anodized
②	Inner Rail		
③	Balls	Steel	-

Item No.	Slide Length	Travel Length	A	B	C	D	Load Rating (kg/pair)	Weight (g)	Box (pcs)
AR2-100	100 (3-15/16")	60 (2-23/64")	-	70	-	70	15.3 (34 lbs)	31	50
AR2-200	200 (7-7/8")	120 (4-23/32")	85	170	85	170	12.2 (27 lbs)	63	
AR2-300	300 (11-13/16")	180 (7-5/64")	135	270	135	270	10.2 (22 lbs)	76	
AR2-400	400 (15-3/4")	240 (9-29/64")	185	370	185	370	9.2 (20 lbs)	129	
AR2-500	500 (19-11/16")	300 (11-13/16")	235	470	235	470	8.2 (18 lbs)	161	