



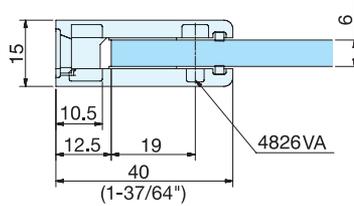

## MINI GLASS CLAMP

3001

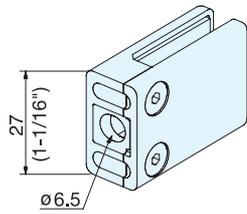



- Small glass clamp.
- Optional Parts: 4826VA (Safety Pin)
- See page 466 for load capacity.
- Tempered Glass Recommended.

Item No.	Glass Thickness (mm)	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
3001ZN1-6	6	52	20	200	Zinc Alloy	Matte Chrome
3001ZN5-6						Chrome



## MINI GLASS CLAMP

3021

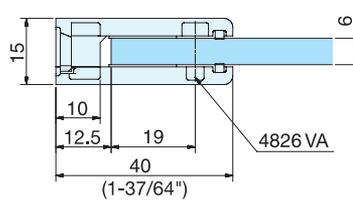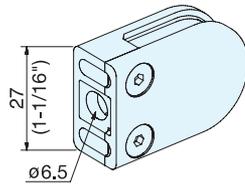

- Small type glass clamp.
- Optional Parts: 4826VA (Safety Pin)
- See page 466 for load capacity.
- Tempered Glass Recommended.


Item No.	Glass Thickness (mm)	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
3021ZN1-6	6	48	20	200	Zinc Alloy	Matte Chrome
3021ZN5-6						Chrome




## SAFETY PIN



9320VA, 4820VA, 4826VA

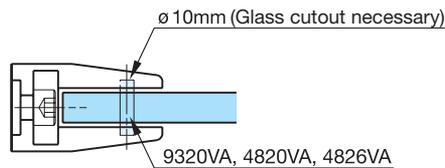

- 302 Stainless Steel Safety Pin with rubber ring.
- Use hammer to insert into clamp.

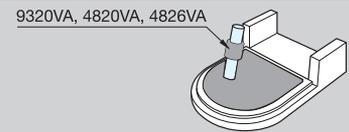


Item No.	Glass Thickness (mm)	Dimensions (mm)	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
9320VA	10	Ø6 × 20	5	20	200	302 Stainless Steel	Plain
4820VA		Ø6 × 16					
4826VA		Ø4 × 12					



## SAFETY PLATE



4849VA

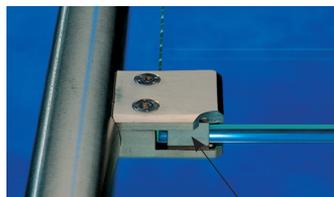

- 304 Stainless Steel Safety Plate (18 × 20 × 2 mm).

Item No.	Glass Thickness (mm)	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
4849VA	10	6	20	200	304 Stainless Steel	Plain