

BRACKET



BT, BTK, BTW

SHELF & SUPPORT HARDWARE BRACKETS



• Stainless steel BT Series (satin finish) or steel BTW and BTK Series (white or black) available.




Stainless Steel

White



Black

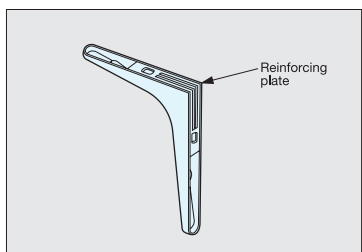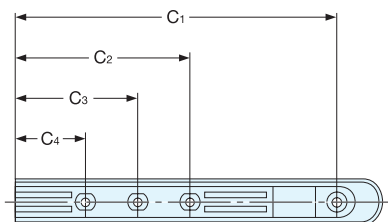

Reinforcing plate

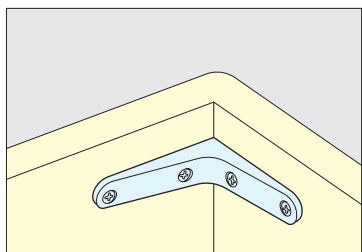

Installation

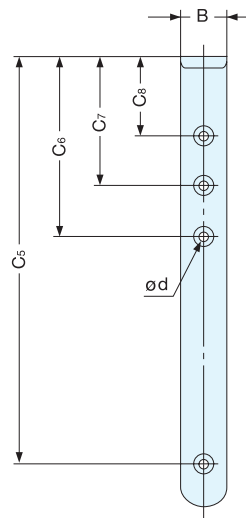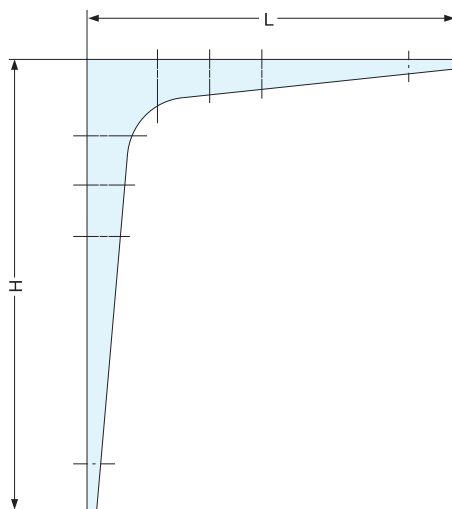

Item No.			L	H	B	C <sub>1</sub>	C <sub>2</sub>	C <sub>3</sub>	C <sub>4</sub>	C <sub>5</sub>	C <sub>6</sub>	C <sub>7</sub>	C <sub>8</sub>	d
Stainless	Steel													
BT-85	BTK-85	BTW-85	69.0 ( 2-23/32" )	86.0 ( 3-25/64" )	15 ( 19/32" )	58.0	27.0	-	-	75.0	26.0	-	-	4.0
BT-120	BTK-120	BTW-120	100.0 ( 3-15/16" )	120.0 ( 4-23/32" )		85.0	43.0	-	-	106.0	42.0	-	-	
BT-180	BTK-180	BTW-180	148.5 ( 5-27/32" )	180.5 ( 7-7/64" )		131.0	71.0	50.0	-	162.5	72.5	51.5	-	
BT-240	BTK-240	BTW-240	199.0 ( 7-27/32" )	240.0 ( 9-29/64" )	18 ( 23/32" )	176.0	91.0	59.0	-	217.0	92.0	60.0	-	5.0
BT-300	BTK-300	BTW-300	238.5 ( 9-25/64" )	301.0 ( 11-27/32" )	20 ( 25/32" )	206.5	92.5	60.5	-	269.0	95.0	63.0	-	
BT-380	BTK-380	BTW-380	318.0 ( 12-33/64" )	378.0 ( 14-7/8" )	23 ( 29/32" )	285.0	145.0	110.0	75	345.0	145.0	110.0	75	
BT-480	BTK-480	BTW-480	400.0 ( 15-3/4" )	480.0 ( 18-29/32" )	30 ( 1-3/16" )	360.0	180.0	135.0	90	440.0	180.0	135.0	90	5.5

Item No.			Holes	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)
Stainless	Steel						
BT- 85	BTK- 85	BTW- 85	4	15.0 ( 33 lbs)	40	20	240
BT-120	BTK-120	BTW-120		20.0 ( 44 lbs)	60		100
BT-180	BTK-180	BTW-180		25.0 ( 55 lbs)	110		200
BT-240	BTK-240	BTW-240	6	28.0 ( 61 lbs)	200	10	100
BT-300	BTK-300	BTW-300		35.0 ( 77 lbs)	310		40
BT-380	BTK-380	BTW-380		65.0 ( 143 lbs)	470		60
BT-480	BTK-480	BTW-480	8	82.5 ( 181 lbs)	1100	6	60

Material (BT)	Finish
304 Stainless Steel	Satin
Material (BTK/BTW)	Finish/Color
Steel	Black (BTK), White (BTW)