




FOLDING BRACKET



388



- Automatically locks when flap is in opened position.
- Press lever to release the lock.
- For panel thickness 15-35 mm (19/32"~1-3/8")
- Required Quantity:
 - Width up to 600 mm (23-5/8")...1 pc
 - Width 600~1300 mm (23-5/8"~51-3/16")...2 pcs

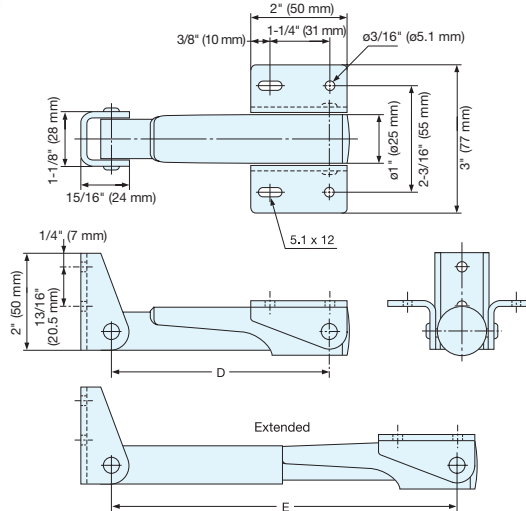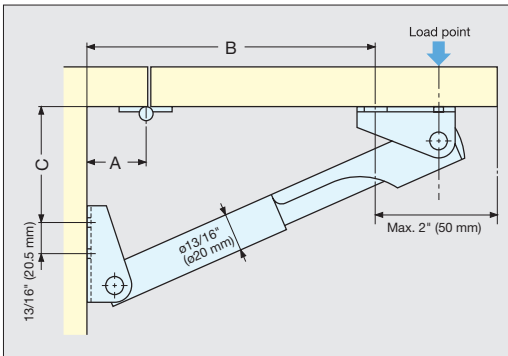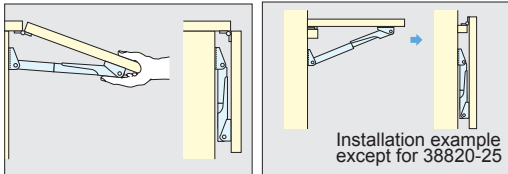

Material	Finish/Color
Aluminum	Anodized
	Black (BLK)

Item No.	A	B	C	D	E	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)
38820-25	1"~1-3/16"	6-5/16"	9/16"	4-1/2"	7-1/16"	35 (77 lbs)	149	5	50
38820-25/BLK	(25~30 mm)	(161 mm)	(15 mm)	(114 mm)	(180 mm)				
38830-25	1"~1-9/16"	9-15/16"	1-3/4"	6-5/8"	10-7/8"	55 (121 lbs)	187	5	30
38830-25/BLK	(25~39 mm)	(252 mm)	(45 mm)	(168 mm)	(275.9 mm)				
38845-25	1"~2"	15-13/16"	3-7/16"	10-3/16"	16-15/16"	60 (132 lbs)	266	5	30
38845-25/BLK	(25~50 mm)	(402 mm)	(87 mm)	(258.5 mm)	(430.8 mm)			5	50
38860-25	1"~1-9/16"	21-5/8"	5-3/8"	14-1/2"	23-1/16"	80 (176 lbs)	342	5	30
38860-25/BLK	(25~40 mm)	(549 mm)	(137 mm)	(368.5 mm)	(585.8 mm)			5	50


SPRING LOADED BRACKET




GTS-300



- Spring loaded for lift assist feature.
- Pull the knob to fold down.
- Max. depth of shelf is 450 mm (17-3/4")
- Max. width of shelf is 300 mm (11-13/16")

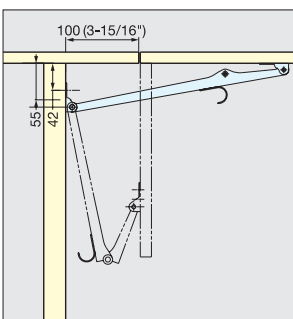

Installation

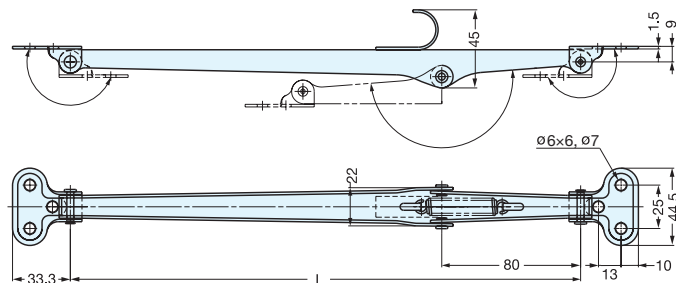

Material	Finish
304 Stainless Steel	Satin

Item No.	L	Load Capacity (kg)	Weight (g)	Box (pc)	Carton (pcs)
GTS-300	294 (11-37/64")	3 (6.6 lbs)/pc, 6 (13 lbs)/2pcs	190	12	96