

SHELF STANDARD




AP-DM, AP-DH




AP-DM1820WT

AP-DM1820

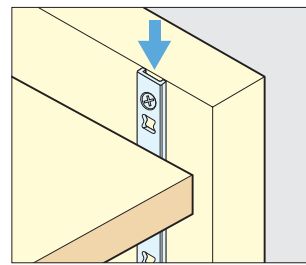

Surface Mount

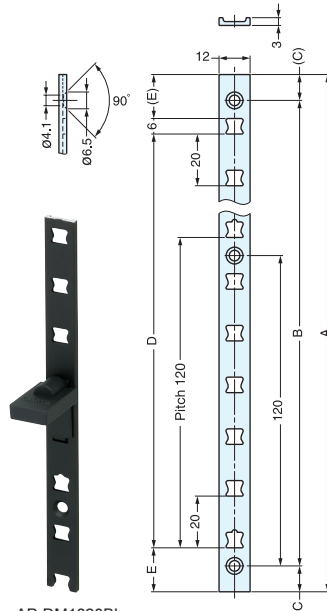


AP-DM1820BL

- Aluminum shelf standard.
- Easy to cut to desired length.
- Thin profile (3 mm, 1/8") suitable for surface mount.
- Screw hole located every 120 mm (4-23/32").
- New slot shape to prevent shelf support from falling off.
- Special screw with silver finish available. (AP-SC3-16)
- Screws and accessories sold separately.




* Install the standard with concave slot (located every 120 mm) pointing upward.

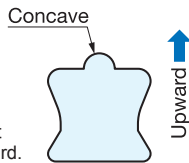


Item No.	Screw Type	Finish / Color	Material	Box (set)
AP-SC3-16	Flat-head wood 3 × 16	Yellow Zinc Chromate (Head-Silver)	Steel	1
AP-SC3-16WT		Yellow Zinc Chromate (Head-White)		
AP-SC3-16BL		Yellow Zinc Chromate (Head-Black)		
AP-SC3-30	Flat-head wood 3 × 30	Yellow Zinc Chromate (Head-Silver)		
AP-SC3-30WT		Yellow Zinc Chromate (Head-White)		
AP-SC3-30BL		Yellow Zinc Chromate (Head-Black)		




AP-DH1820

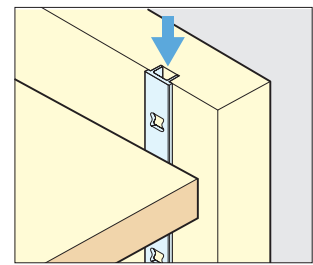


Mortise Mount

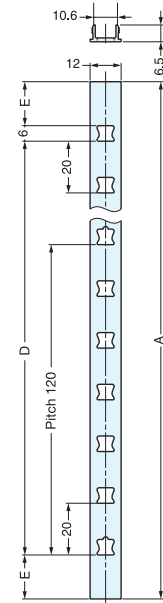

- Aluminum shelf standard.
- Easy to cut to desired length.
- Designed for press-fit mount without using screws.
- New slot shape to prevent shelf support from falling off.
- Screws and accessories sold separately.

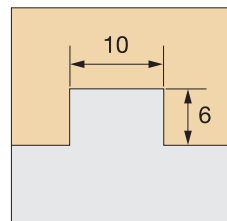

Bore Dimension
(In case of Plywood)
* Fit tightness may vary depending on the panel/wall material.
Use adhesive if loose.

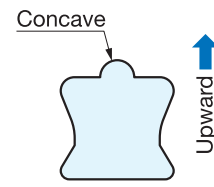

* Install the standard with concave slot (located every 120 mm) pointing upward.

Item No.	Mounting Type	A	B	C	D	E	Weight (g)	Material	Finish	Box (pcs)	
AP-DM1820	Surface Mount	1820 (71-21/32")	1800	10	1780	17	113	Aluminum	Anodized	100	
AP-DM1820WT									White		
AP-DM1820BL									Black		
AP-DM2600	Mortise Mount	2600 (102-3/8")	2520	40	2500	47	161		Anodized	60	
AP-DH1820											100
AP-DH2600											60