








## Very Low Profile Range

Perfect for mounting removable thin wall lightweight panels and facings. This clip set requires less depth compared to other Fastmount® ranges. No special installation tools are required; can be used with a two part epoxy appropriate for the material of your substrate and panel and/or screw fixed. Ideal for mounting panels where no drilling is preferred. Typical applications include wall panels, headboards and inspection panels. VL-03FR clips are made of flame retardant plastic, rated at UL94 V-0 for applications requiring fire rated materials.

VL-03/VL-03H/VL-03X/VL-03FR				
Item No.		Dimensions	Diagram Spacing Options	Description
<b>VL-03</b> (Standard)    <b>VL-03H</b> (Heavy Duty)    <b>VL-03X</b> (Extra Heavy Duty)    <b>VL-03FR</b> (Fire Rated)  	<b>Female Clip</b>		<b>Surface Mount</b>  	<b>CLIP SET</b>  For surface or recessed mounting. Can be screw or glue fixed. No special tools needed.  <b>Supplied with:</b> Stainless steel screw (VL-SS3). 1 screw included with VL-03, VL03H and VL-03X 2 screws included with VL03FR.  <b>Pull Out Force:</b> <b>VL-03:</b> 11 lbs (5kg) per clip <b>VL-03H:</b> 22 lbs (10kg) per clip <b>VL-03FR:</b> 22 lbs (10kg) per clip <b>VL-03X:</b> 55 lbs (25kg) per clip.  <b>VL-03 and VL-03H</b> Box: 100      Carton: 500  <b>VL-03FR</b> Box: 100      Carton: 1,000  <b>VL-03X</b> Box: 100      Carton: 2,000
	<b>Male Clip</b>			

### Accessories

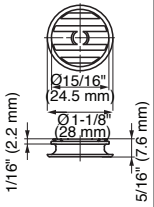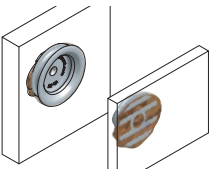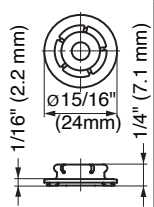

**VL-CP3 VERY LOW PROFILE CENTER POINT**  
Use to mark hole center in panel for correct clip alignment. Has stainless steel tip for marking panel or frame.  
Tip: Push fits into either side of nylon molding.

### Installation: Female & Male Clips



**GLUE**  
When fixed with adhesive two part epoxy (glue), use in accordance with manufacturer's instructions.



**VL-SS3 STAINLESS STEEL SCREW**  
Custom type 303 stainless steel screw for fixing VL-M3 into panels down to 1/4" (5.5mm) thick.

