


XL-GC SERIES (FOR SLIDING DOORS)



• Installation example: Double bypass doors.
(Refer to order quantity below)

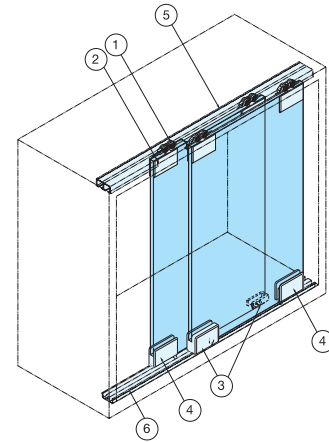

Door Width	Max. 500 mm (19-11/16")
Door Height	Max. 1200 mm (47-1/4")
Door Weight	Max. 12 kg (26.5 lbs) / Per Door
Glass Thickness	8 mm (5/16")

Part Details

Order Quantity	No.	Item No.	Part Name		Dimensions	Description
4 ea	①	57-3149-071	Upper Roller			<ul style="list-style-type: none"> ● Material Zinc Alloy (Body) Polyacetal (Roller) ● Finish/Color Yellow Zinc Chromate (Body) White (Roller)
1 set	②	XL-GC06-C	Upper Bracket		See P.605	<ul style="list-style-type: none"> ● Material Zinc Alloy ● Finish/Color Chrome <p>*4 pcs per set (for 2 glass doors)</p>
1 ea	③	XL-GC03-C	Lock		See P.605	<ul style="list-style-type: none"> ● Material Zinc Alloy ● Finish/Color Chrome <p>*24 key changes (2 keys Included)</p>
1 pair	④	XL-GC08-C	Bottom Guide Bracket		See P.605	<ul style="list-style-type: none"> ● Material Zinc Alloy ● Finish/Color Chrome <p>*1 pair (Left / Right) per set</p>
1 ea	⑤	XL-GC06-UL1200N	Upper Rail			<ul style="list-style-type: none"> ● Material Aluminum ● Finish/Color Plain <p>*Length: 1200 mm (47-1/4 ")</p>
1 ea	⑥	XL-GC03-GL 1200	Bottom Rail			<ul style="list-style-type: none"> ● Material ABS ● Finish/Color Black <p>*Length: 1200 mm (47-1/4 ")</p>