

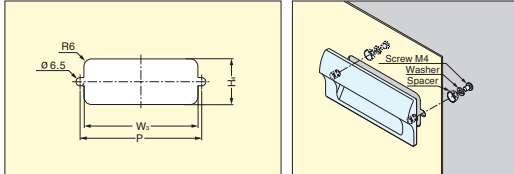


RECESSED PULL (SCREW MOUNT)

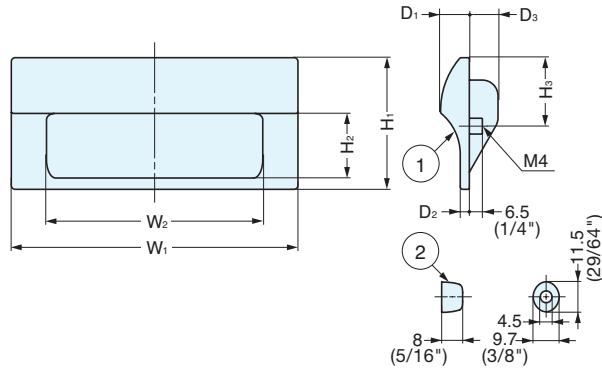

HH-JS

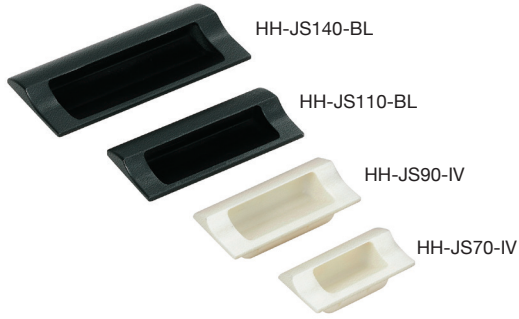

Sheetmetal Cut Out Dimensions

Installation


Part Name	Material	Finish
Handle Body	ABS + Polycarbonate	Ivory (IV)/Black (BL)

Item No.	W ₁	W ₂	H ₁	H ₂	H ₃	D ₁	D ₂	D ₃	P	W ₃	W ₄	Box (pcs)	Carton (pcs)
HH-JS70-BL	70 (2-3/4")	43 (1-11/16")	38 (1-1/2")	17.0 (43/64")	19 (3/4")	10.5	3.0	9	58 (2-9/32")	48	25	10	200
HH-JS70-IV													
HH-JS90-BL	90 (3-35/65")	63 (2-31/64")	44 (1-47/64")	21.5 (27/32")	22 (55/64")	11.0	11	96 (3-5/64")	68	31			
HH-JS90-IV													
HH-JS110-BL	110 (4-21/64")	82 (3-15/64")	50 (1-31/32")	24.4 (61/64")	26 (1-1/32")	11.5	3.5	126 (4-61/64")	90	36			
HH-JS110-IV													
HH-JS140-BL	140 (5-33/64")	109 (4-19/64")	64 (2-33/64")	34.0 (1-11/32")	33 (1-19/64")	11.5	3.5	126 (4-61/64")	116	48			
HH-JS140-IV													


RECESSED PULL (SNAP-IN MOUNT)



HH-JW

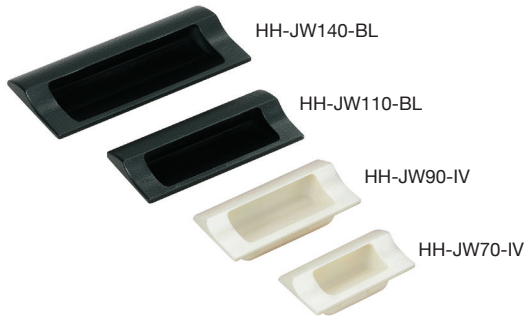


• Snap-in type recessed pull for sheet metal thickness 1/64" ~ 3/32" (0.5 ~ 2.3 mm).

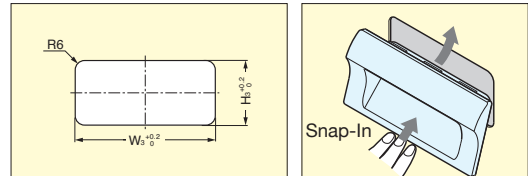

Sheetmetal Cut Out Dimensions

Installation

Part Name	Material	Finish
Handle Body	ABS + Polycarbonate	Ivory (IV)/Black (BL)

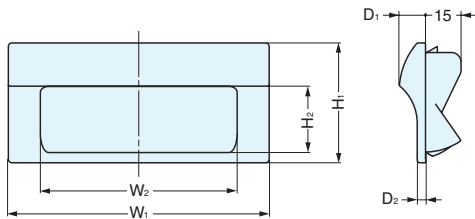

Type	W ₃	H ₃			
		Panel 0.8mm	Panel 1.0~1.2mm	Panel 1.0~1.2mm	Panel 2.3mm
HH-JW70	46	28.7	29	29.4	30.8
HH-JW90	66	34.7	35	35.4	36.8
HH-JW110	88	40.7	41	41.4	42.8
HH-JW140	114	54.7	55	55.4	56.8

Item No.	W ₁	W ₂	H ₁	H ₂	D ₁	D ₂	Box (pcs)	Carton (pcs)
HH-JW70-BL	70 (2-3/4")	43 (1-11/16")	38 (1-1/2")	18.5 (47/64")	10.5	3.0	10	200
HH-JW70-IV								
HH-JW90-BL	90 (3-35/65")	63 (2-31/64")	44 (1-47/64")	22.9 (29/32")	11.0			
HH-JW90-IV								
HH-JW110-BL	110 (4-21/64")	82 (3-15/64")	50 (1-31/32")	26.8 (1-1/16")	11.5	3.5		
HH-JW110-IV								
HH-JW140-BL	140 (5-33/64")	109 (4-19/64")	64 (2-33/64")	37.8 (1-31/64")	11.5	3.5		
HH-JW140-IV								