


PULL



SN

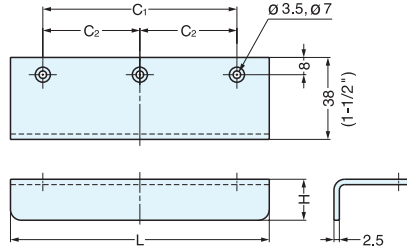

Available in 3 finishes.
Please specify finish
when ordering.



Material	Finish
304 Stainless Steel	Mirror (M) Satin (S) Black (BL)

Item No.			L	C ₁	C ₂	H	Holes	Weight (g)	Box (pcs)	Carton (pcs)
SN-50/M	SN-50/S	SN-50/BL	50 (1-31/32")	30 (1-3/16")	-	18 (11/16")	2	47	40	400
SN-70/M	SN-70/S	SN-70/BL	70 (2-3/4")	46 (1-13/16")	-			65	30	300
SN-95/M	SN-95/S	SN-95/BL	95 (3-47/64")	65 (2-9/16")	-			90	20	200
SN-120/M	SN-120/S	-	120 (4-23/32")	90 (3-35/64")	45		3	112	15	150
SN-150/M	SN-150/S	-	150 (5-29/32")	114 (4-31/64")	57			147		
SN-200/M	SN-200/S	-	200 (7-7/8")	112 (4-13/32")	56			200		
SN-300/M	SN-300/S	-	300 (11-13/16")	180 (7-3/32")	90		4	300	10	40

PULL



SND

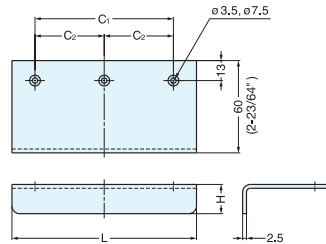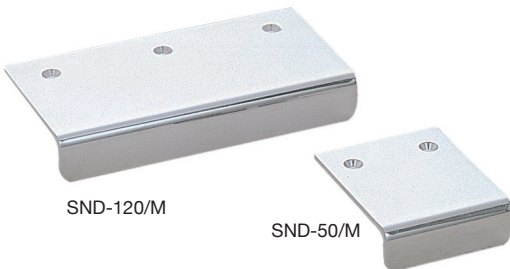



Material	Finish
304 Stainless Steel	Mirror (M)

Item No.	L	C ₁	C ₂	Hole	Weight (g)	Box (pcs)	Carton (pcs)
SND-50/M	50 (1-31/32")	30 (1-3/16")	-	2	47	40	400
SND-70/M	70 (2-3/4")	46 (1-13/16")	-		65		
SND-95/M	95 (3-47/64")	65 (2-9/16")	-		90		
SND-120/M	120 (4-23/32")	90 (3-35/64")	45	3	112	20	200
SND-150/M	150 (5-29/32")	114 (4-31/64")	57		147		


EDGE PULL



DSI-350

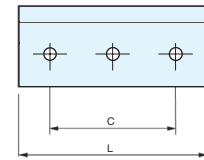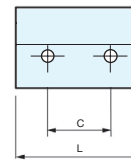

Item No.	Finish	C	L	Weight (g)	Box (pcs)	Carton (pcs)
DSI-350-16	Satin	16 (5/8")	32 (1-1/4")	22	25	250
DSI-350-16-BL	Black	16 (5/8")	32 (1-1/4")	22		
DSI-350-64	Satin	64 (2-1/2")	96 (3-25/32")	66		
DSI-350-96		96 (3-25/32")	128 (5-1/16")	88		
DSI-350-128		128 (5-1/16")	160 (6-5/16")	110		
DSI-350-160		160 (6-5/16")	192 (7-9/16")	132		
DSI-350-192	192 (7-9/16")	224 (8-13/16")	154	10	100	
DSI-350-224	224 (8-13/16")	256 (10-1/16")	176			
DSI-350-256	256 (10-1/16")	352 (13-7/8")	240			
DSI-350-352	352 (13-7/8")	544 (21-7/16")	374			

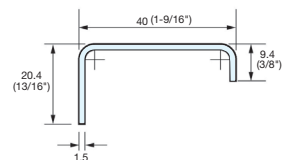

Material	Finish
304 Stainless Steel	Satin