

METAL-DETECTABLE GROMMET

MPG



MPG-28


MPG-22

MPG-16



- Made of silicone rubber for better heat and cold resistance.
- Ideal for food machine and food packaging machinery.
- Colored in standard food safety blue for simple visual verification.
- Contains metal powder, allowing for accurate metal detection.
- Operating Temperature: 14°F to 230°F (-10°C to 110°C).



The silicone rubber itself contains metal powder.

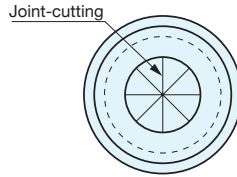

When inserting cables, please cut in joint-cutting area.

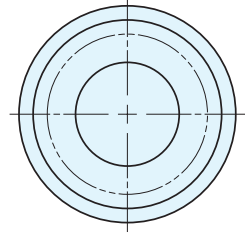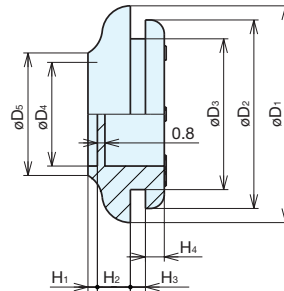

Material	Finish
Metal Detectable Silicone Rubber	Blue

Item No.	D ₁	D ₂	D ₃	D ₄	D ₅
MPG-16	29/32" (23 mm)	25/32" (20 mm)	5/8" (16 mm)	7/16" (11 mm)	33/64" (13 mm)
MPG-22	1-9/64" (29 mm)	1-1/32" (26 mm)	55/64" (22 mm)	43/64" (17 mm)	3/4" (19 mm)
MPG-28	1-29/64" (37 mm)	1-19/32" (33 mm)	1-7/64" (28 mm)	53/64" (21 mm)	15/16" (24 mm)

H ₁	H ₂	H ₃	H ₄	Weight (g)	Box (pcs)	Carton (pcs)
3/64" (1 mm)	9/64" (3.5 mm)	1/16" (1.6 mm)	5/64" (2 mm)	2	200	800
	5/32" (4 mm)		3/32" (2.5 mm)			
1/16" (1.5 mm)	13/64" (5 mm)	3/32" (2.3 mm)	1/8" (3 mm)	6	50	200