


BUTT HINGE



28000, 28500

HINGES

BUTT HINGES

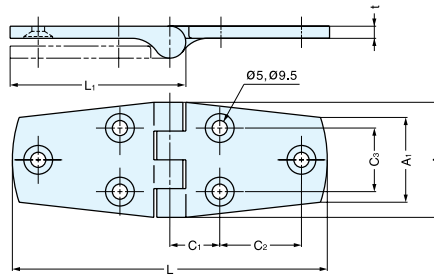

- 316 Stainless Steel construction ideal for harsh and highly corrosive environments.
- Max. Door weight: 8.8 lbs/pair (4 kg/pair)
- Max. Door size: W17-3/4" x H27-9/16" x t13/16" (W45 x H700 x t21 mm)


| Material | Finish |
|---------------------|--------|
| 316 Stainless Steel | Mirror |

| Item No. | L | L ₁ | C ₁ | C ₂ | C ₃ | A | A ₁ | t | Weight (g) | Box (pcs) | Carton (pcs) |
|----------|---------------------|-------------------|-------------------|--------------------|-------------------|-------------------|-------------------|-----------------|------------|-----------|--------------|
| 28500 | 2-15/16" (74 mm) | 1-5/8" (42 mm) | 1/2" (13 mm) | 11/16" (17 mm) | 13/16" (20 mm) | 1-1/2" (38 mm) | 1-1/8" (28 mm) | 3/16" (4 mm) | 85 | 20 | 100 |
| 28000 | 4-1/16" (104 mm) | 2-1/4" (57 mm) | 5/8" (16.5 mm) | 1-1/16" (27 mm) | 13/16" (21 mm) | | | 115 | | | |

BUTT HINGE



28100

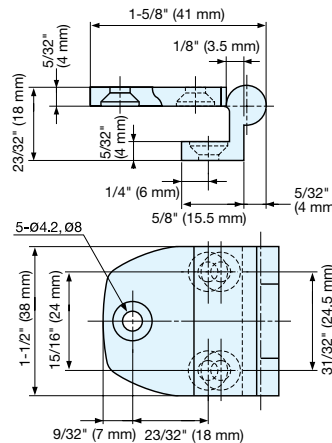

- 316 Stainless Steel construction ideal for harsh and highly corrosive environments.
- Max. Door weight: 8.8 lbs/pair (4 kg/pair)
- Max. Door size: W17-3/4" x H27-9/16" x t13/16" (W45 x H700 x t21 mm)


| Item No. | Weight (g) | Box (pcs) | Carton (pcs) |
|----------|------------|-----------|--------------|
| 28100 | 78.5 | 20 | 100 |

| Material | Finish |
|---------------------|--------|
| 316 Stainless Steel | Mirror |

BUTT HINGE



27800, 27900

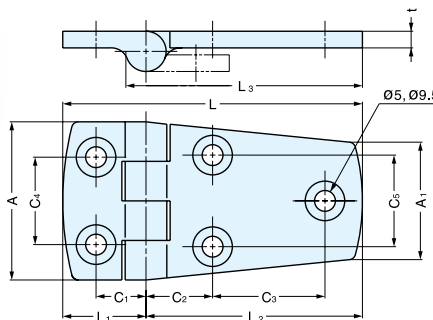

- 316 Stainless Steel construction ideal for harsh and highly corrosive environments.
- Max. Door weight: 8.8 lbs/pair (4 kg/pair)
- Max. Door size: W17-3/4" x H27-9/16" x t13/16" (W45 x H700 x t21 mm)

| Material | Finish |
|---------------------|--------|
| 316 Stainless Steel | Mirror |

| Item No. | L | L ₁ | L ₂ | L ₃ | C ₁ | C ₂ | C ₃ | C ₄ | C ₅ | A | A ₁ | t | Weight (g) | Box (pcs) | Carton (pcs) |
|----------|---------------------|--------------------|-------------------|-------------------|-----------------|-------------------|--------------------|-------------------|-------------------|-------------------|-------------------|-----------------|------------|-----------|--------------|
| 27900 | 2-1/4" (58 mm) | 13/16" (20 mm) | 1-1/2" (38 mm) | 1-5/8" (42 mm) | 1/2" (12 mm) | 1/2" (13.5 mm) | 5/8" (16.5 mm) | 13/16" (21 mm) | 13/16" (20 mm) | 1-1/2" (38 mm) | 1-1/8" (28 mm) | 3/16" (4 mm) | 70 | 20 | 100 |
| 27800 | 2-13/16" (72 mm) | 2-1/16" (52 mm) | 2-1/4" (57 mm) | 2-1/4" (57 mm) | 1/2" (12 mm) | 5/8" (16 mm) | 1-1/16" (27 mm) | 7/8" (22 mm) | 13/16" (21 mm) | 1-1/2" (38 mm) | 1-1/8" (28 mm) | 3/16" (4 mm) | 85 | | |