





GLASS SHELF SUPPORT



2884



- Load capacity (center of glass) 11 lbs (5 kg)/pair with shelf support distance max. 11-13/16" (300 mm), glass depth max. 11-13/16" (300 mm).
- Tempered Glass Recommended.

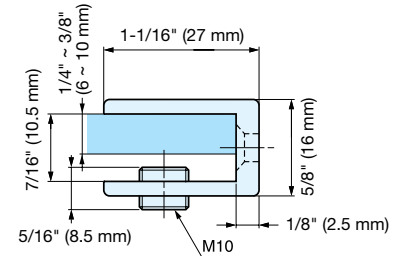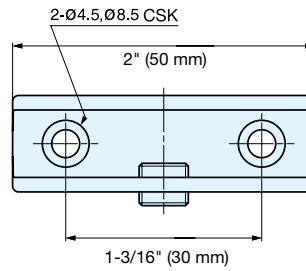

Item No.	Glass Thickness (mm)	Weight (g)	Box (pcs)	Carton (pcs)
2884ZN5	1/4" ~ 3/8"	49	20	200
2884VA2	(6 mm ~ 10 mm)			

Material	Finish
Zinc Alloy	Chrome (ZN5)
304 Stainless Steel	Satin (VA2)



GLASS SHELF SUPPORT





2880



2880ZN5

2880ZN1

- Load capacity (center of glass) 11 lbs (5 kg)/pair with shelf support distance max. 11-13/16" (300 mm), glass depth max. 11-13/16" (300 mm).
- Tempered Glass Recommended.

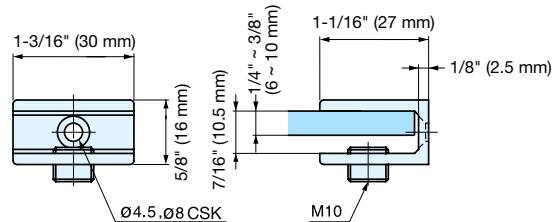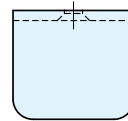

Item No.	Glass Thickness	Weight (g)	Box (pcs)	Carton (pcs)
2880ZN1	1/4" ~ 3/8"	34	20	200
2880ZN5	(6 mm ~ 10 mm)			

Material	Finish
Zinc Alloy	Matte Chrome (ZN1)
	Chrome (ZN5)
304 Stainless Steel	Satin (VA2)