




MINI GLASS CLAMP

3001

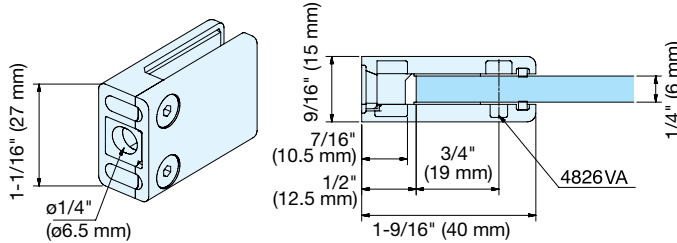


- Small glass clamp.
- Optional Parts: 4826VA (Safety Pin)
- See page 466 for load capacity.
- Tempered Glass Recommended.

Item No.	Glass Thickness	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
3001ZN1-6	1/4" (6 mm)	52	20	200	Zinc Alloy	Matte Chrome
3001ZN5-6						Chrome



MINI GLASS CLAMP

3021

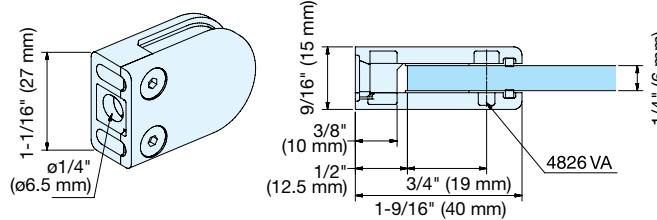

- Small type glass clamp.
- Optional Parts: 4826VA (Safety Pin)
- See page 466 for load capacity.
- Tempered Glass Recommended.


Item No.	Glass Thickness	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
3021ZN1-6	1/4" (6 mm)	48	20	200	Zinc Alloy	Matte Chrome
3021ZN5-6						Chrome




SAFETY PIN



9320VA, 4820VA, 4826VA

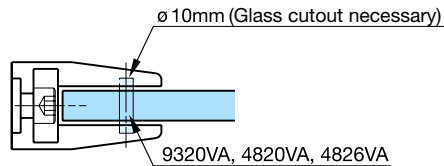

- 302 Stainless Steel Safety Pin with rubber ring.
- Use hammer to insert into clamp.

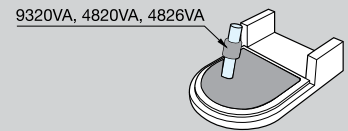

Item No.	Glass Thickness	Dimensions	Weight (g)	Box (pcs)	Carton (pcs)
9320VA	3/8" (10 mm)	Ø6 mm × 20 mm	5	20	200
4820VA		Ø6 mm × 16 mm			


Material	Finish
302 Stainless Steel	Plain



SAFETY PLATE



4849VA

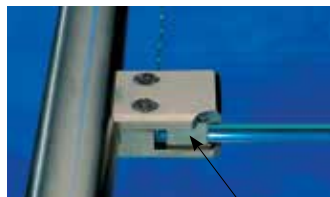

- 304 Stainless Steel Safety Plate (18 × 20 × 2 mm).

Item No.	Glass Thickness	Weight (g)	Box (pcs)	Carton (pcs)
4849VA	3/8" (10 mm)	6	20	200

Material	Finish
304 Stainless Steel	Plain