


STAINLESS STEEL LEVELING GLIDE



ADPS

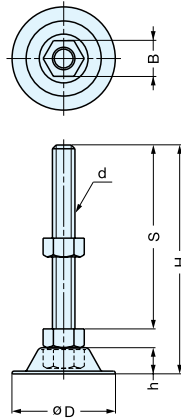

• Nut on bottom of glide allows easy installation and height adjustment with socket wrench.

Material	Finish
304 Stainless Steel	Polished


Item No.	D	H	h	S	B	d	Load Capacity	Weight (g)	Box (pcs)	Carton (pcs)
ADPS37-8-60	1-15/32" (37)	3" (76 mm)	13/32" (10.5)	2-3/8" (60)	1/2" (13)	M 8x1.25	660 lbs (300 kg)	56	200	2000
ADPS37-10-50	1-15/32" (37)	2-21/32" (67.5)	13/32" (10.5)	1-31/32" (50)	21/32" (17)	M10x1.5	660 lbs (300 kg)	78	200	2000
ADPS55-12-100	2-5/32" (55)	4-13/16" (122)	9/16" (14)	3-15/16" (100)	3/4" (19)	M12x1.75	660 lbs (300 kg)	174	100	1000
ADPS55-12-120	2-5/32" (55)	5-19/32" (142)	9/16" (14)	4-23/32" (120)	3/4" (19)	M12x1.75	660 lbs (300 kg)	187	80	800
ADPS55-12-150	2-5/32" (55)	6-25/32" (172)	9/16" (14)	5-29/32" (150)	3/4" (19)	M12x1.75	660 lbs (300 kg)	210	70	700
ADPS75-16-100	2-15/16" (75)	5-1/32" (128)	23/32" (18)	3-15/16" (100)	15/16" (24)	M16x2.0	1233 lbs (560 kg)	318	50	500
ADPS75-16-130	2-15/16" (75)	6-7/32" (158)	23/32" (18)	5-1/8" (130)	15/16" (24)	M16x2.0	1233 lbs (560 kg)	358	40	400
ADPS75-16-150	2-15/16" (75)	7" (178)	23/32" (18)	5-29/32" (150)	15/16" (24)	M16x2.0	1233 lbs (560 kg)	382	30	300
ADPS75-16-180	2-15/16" (75)	8-3/16" (208)	23/32" (18)	7-3/32" (180)	15/16" (24)	M16x2.0	1233 lbs (560 kg)	426	30	300
ADPS75-20-100	2-15/16" (75)	5-5/32" (131)	23/32" (18)	3-15/16" (100)	1-3/16" (30)	M20x2.5	1938 lbs (880 kg)	490	40	400
ADPS75-20-130	2-15/16" (75)	6-11/32" (161)	23/32" (18)	5-1/8" (130)	1-3/16" (30)	M20x2.5	1938 lbs (880 kg)	553	30	300
ADPS75-20-150	2-15/16" (75)	7-1/8" (181)	23/32" (18)	5-29/32" (150)	1-3/16" (30)	M20x2.5	1938 lbs (880 kg)	593	30	300
ADPS75-20-180	2-15/16" (75)	8-5/16" (211)	23/32" (18)	7-3/32" (180)	1-3/16" (30)	M20x2.5	1938 lbs (880 kg)	655	25	250

() units in mm

STAINLESS STEEL LEVELING GLIDE



ADCS

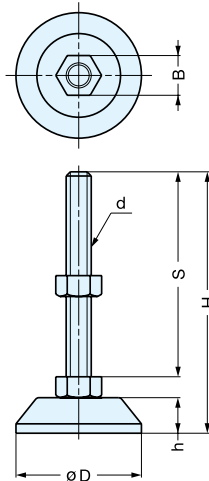

• Nut on bottom of glide allows easy installation and height adjustment with socket wrench.

Material	Finish
304 Stainless Steel	Plain

Item No.	D	H	h	S	B	d	Load Capacity	Weight (g)	Box (pcs)	Carton (pcs)
ADCS60-12-120	2-3/8" (60 mm)	5-23/32" (145)	21/32" (17)	4-23/32" (120)	3/4" (19)	M12x1.75	660 lbs (300 kg)	365	35	350
ADCS60-16-100	2-3/8" (60 mm)	5" (127)	21/32" (17)	3-15/16" (100)	15/16" (24)	M16x2.0	1233 lbs (560 kg)	440	25	250
ADCS60-16-130	2-3/8" (60 mm)	6-3/16" (157)	21/32" (17)	5-1/8" (130)	15/16" (24)	M16x2.0	1233 lbs (560 kg)	480	25	250
ADCS60-16-180	2-3/8" (60 mm)	8-5/32" (207)	21/32" (17)	7-3/32" (180)	15/16" (24)	M16x2.0	1233 lbs (560 kg)	550	20	200
ADCS60-20-100	2-3/8" (60 mm)	5-1/8" (130)	21/32" (17)	3-15/16" (100)	1-3/16" (30)	M20x2.5	1938 lbs (880 kg)	590	20	200
ADCS60-20-130	2-3/8" (60 mm)	6-5/16" (160)	21/32" (17)	5-1/8" (130)	1-3/16" (30)	M20x2.5	1938 lbs (880 kg)	650	20	200
ADCS60-20-180	2-3/8" (60 mm)	210(8-17/64")	21/32" (17)	7-3/32" (180)	1-3/16" (30)	M20x2.5	1938 lbs (880 kg)	750	15	150