




OVERLAY DOOR ANGLE HINGE

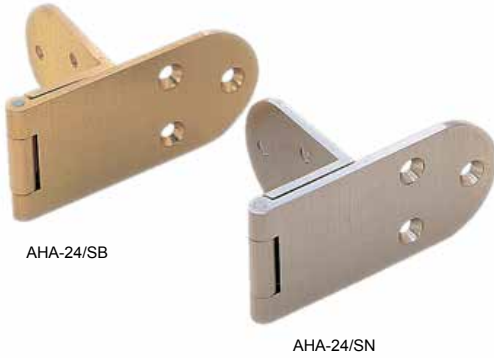

AHA-24



- Recommended Door Specifications:
 Thickness: Recess Mount- 1-1/16" (27 mm); Surface Mount- 1" (24.5 mm)
 Width: Max. 17-3/4" (450 mm)
 Height: Max. 27-9/16" (700 mm)
 Weight: Max. 5.7 lbs (2.6 kg) per pair

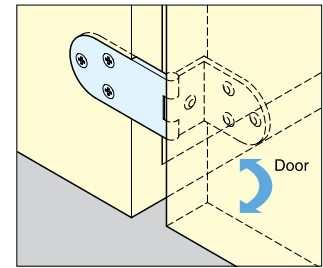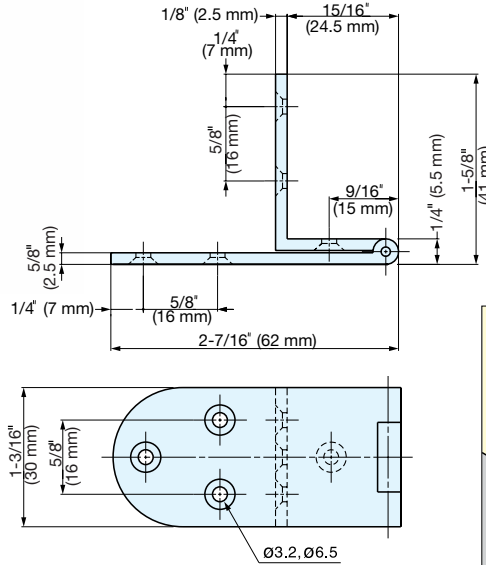


Item No.		Weight (g)	Box (pcs)	Carton (pcs)
AHA-24/SB	AHA-24/SN	70	50	200

Material	Finish
Brass	Satin Brass (SB) Satin Nickel (SN)



OVERLAY DOOR ANGLE HINGE



AHB-18

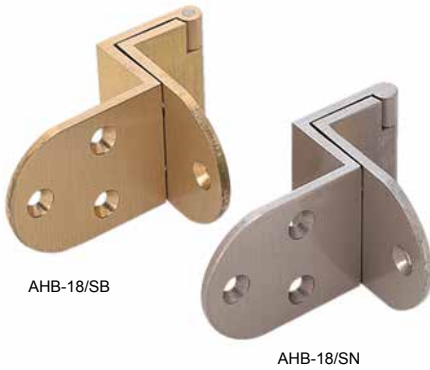

- Recommended Door Specifications:
 Thickness: Recess Mount- 13/16" (21 mm); Surface Mount- 11/16" (18 mm)
 Width: Max. 17-3/4" (450 mm)
 Height: Max. 27-9/16" (700 mm)
 Weight: Max. 5.7 lbs (2.6 kg) per pair

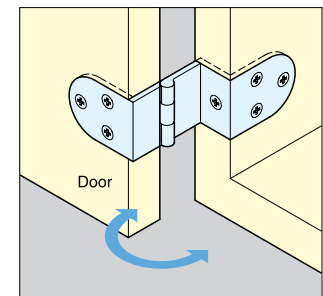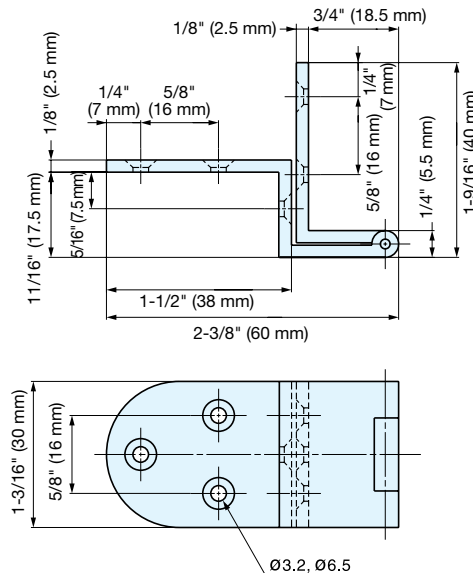

Item No.		Weight (g)	Box (pcs)	Carton (pcs)
AHB-18/SB	AHB-18/SN	76	50	200

Material	Finish
Brass	Satin Brass (SB) Satin Nickel (SN)