

VENTILATOR

APM




APM-5056/BRN




APM-5056/WHT



• Slits for ventilation cannot be seen from outside.

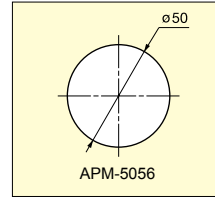

Bore Dimensions

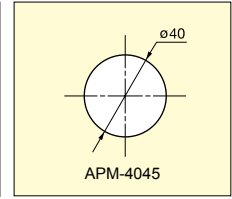

APM-4045

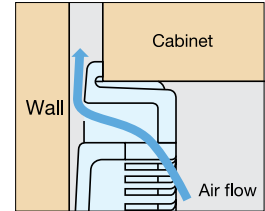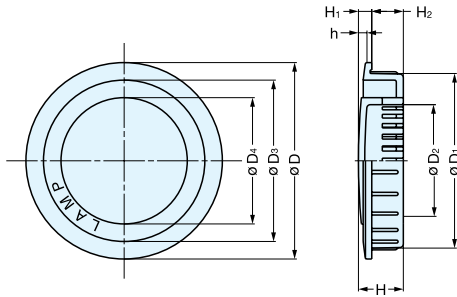

Allows air flow even if the surface of the ventilator is directly on the wall.

Material	Finish
ABS	White (WHT), Brown (BRN)

Item No.	D	D ₁	D ₂	D ₃	D ₄	H	H ₁	H ₂	h	Bore Dimension	Weight (g)	Box (pcs)	Carton (pcs)
APM-4045	1-3/4" (45 mm)	1-9/16" (39.8 mm)	1" (24.6 mm)	1-7/16" (36.2 mm)	1-1/8" (28.2 mm)	7/16" (10.3 mm)	1/8" (3.3 mm)	1/4" (7 mm)	1/16" (1.6 mm)	40	5	150	900
APM-5056	2-3/16" (56 mm)	1-15/16" (49.8 mm)	1-1/4" (32 mm)	1-13/16" (46 mm)	1-7/16" (36 mm)	1/2" (12.8 mm)	1/8" (3.8 mm)	3/8" (9 mm)	1/16" (1.8 mm)	50	9	100	600

Please specify the finish when ordering.

VENTILATOR

APB




APB-5056/WHT




APB-4045/WHT




APB-4090/WHT

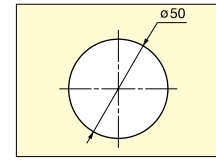


APB-5056

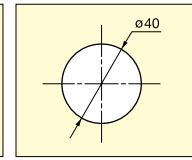

APB-4045

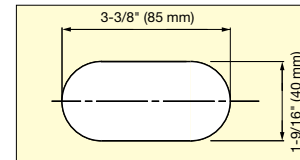


APB-4090

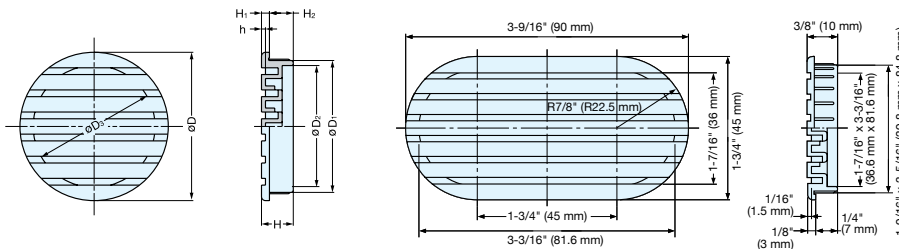

APB-4045, APB-5056

APB-4090

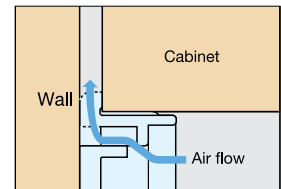

Allows air flow even if the surface of the ventilator is directly on the wall.

Material	Finish
ABS	White (WHT)

Item No.	D	D ₁	D ₂	D ₃	H	H ₁	H ₂	h	Bore Dimension	Weight (g)	Box (pcs)	Carton (pcs)
APB-4045	1-3/4" (45 mm)	1-9/16" (39.8 mm)	1-7/16" (36.6 mm)	1-7/16" (36.6 mm)	(10)	1/8"	(7)	(1.5)	40	7	150	900
APB-5056	2-3/16" (56 mm)	1-15/16" (49.8 mm)	1-13/16" (46 mm)	1-13/16" (46 mm)	(12)	(3 mm)	(9)	(1.5)	50	11	100	600
APB-4090	-	-	-	-	(10)	-	(7)	-	40 x 85	16	80	480

(.) units in mm.