 



# FULL EXTENSION SLIDE




## AR3

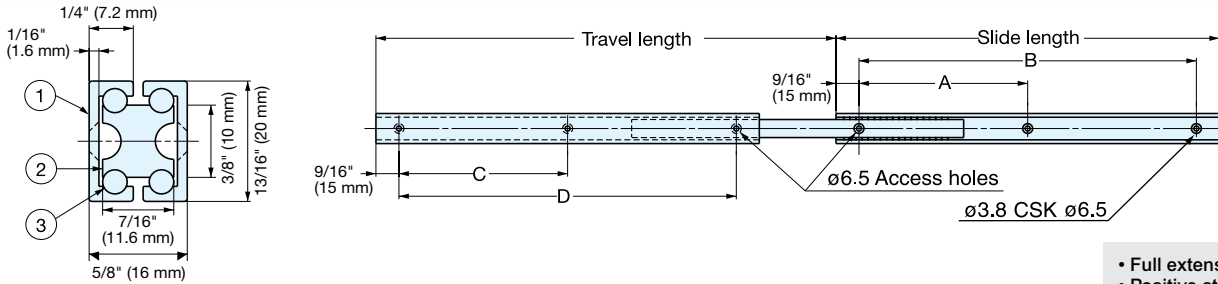

- Full extension.
- Positive stop.
- Non-handed.
- Sold by each.

25.4 mm=1"

No.	Part	Material	Finish
①	Outer Rail	Aluminum	Anodized
②	Inner Rail		
③	Balls	Steel	-

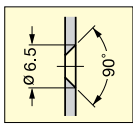


Hole Dimension (Outer Rail)


Item No.	Slide Length	Travel Length	A	B	C	D	Load Rating /pair	Weight (g)	Box (pcs)
AR3-100	3-15/16" (100 mm)	3-15/16" (100 mm)	-	(70)	-	(70)	25 lbs (11.2 kg)	63	30
AR3-200	7-7/8" (200 mm)	8-3/4" (223 mm)	3-3/8" (85 mm)	(170)	3-3/8" (85 mm)	(170)	20 lbs (9.2 kg)	128	
AR3-300	11-13/16" (300 mm)	13-9/16" (345 mm)	5-5/16" (135 mm)	(270)	5-5/16" (135 mm)	(270)	16 lbs (7.1 kg)	194	
AR3-400	15-3/4" (400 mm)	18-1/8" (460 mm)	7-1/4" (185 mm)	(370)	7-1/4" (185 mm)	(370)	11 lbs (5.1 kg)	260	
AR3-500	19-11/16" (500 mm)	22-11/16" (576 mm)	9-1/4" (235 mm)	(470)	9-1/4" (235 mm)	(470)	7 lbs (3.1 kg)	325	20

( ) units in mm.

# 3/4 EXTENSION SLIDE

 


## AR2

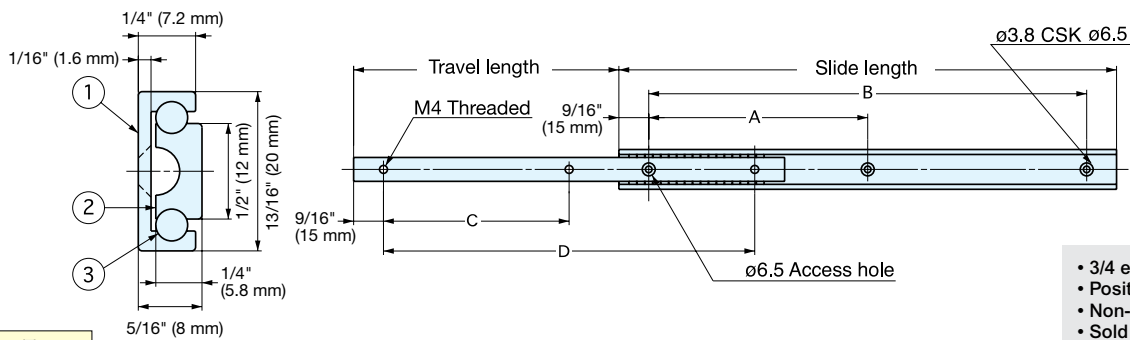

- 3/4 extension.
- Positive stop.
- Non-handed.
- Sold by each.

25.4 mm=1"

No.	Part	Material	Finish
①	Outer Rail	Aluminum	Anodized
②	Inner Rail		
③	Balls	Steel	-

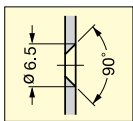

Hole Dimension (Outer Rail)

Item No.	Slide Length	Travel Length	A	B	C	D	Load Rating /pair	Weight (g)	Box (pcs)
AR2-100	3-15/16" (100 mm)	2-23/64" (60 mm)	-	70	-	70	34 lbs (15.3 kg)	31	50
AR2-200	7-7/8" (200 mm)	4-3/4" (120 mm)	3-3/8" (85 mm)	170	3-3/8" (85 mm)	170	27 lbs (12.2 kg)	63	
AR2-300	11-13/16" (300 mm)	7-1/16" (180 mm)	5-5/16" (135 mm)	270	5-5/16" (135 mm)	270	22 lbs (10.2 kg)	76	
AR2-400	15-3/4" (400 mm)	9-7/16" (240 mm)	7-1/4" (185 mm)	370	7-1/4" (185 mm)	370	20 lbs (9.2 kg)	129	
AR2-500	19-11/16" (500 mm)	11-13/16" (300 mm)	9-1/4" (235 mm)	470	9-1/4" (235 mm)	470	18 lbs (8.2 kg)	161	

( ) units in mm.