

BRACKET





BT, BTK, BTW




SHELF & SUPPORT HARDWARE BRACKETS



- Stainless steel BT Series (satin finish) or steel BTW and BTK Series (white or black) available.
- BT version is NSF Certified.

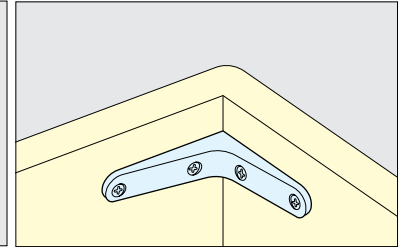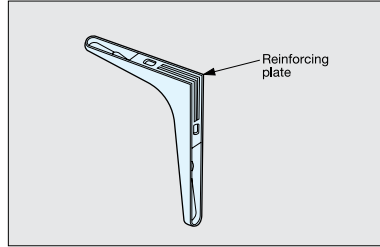

Installation

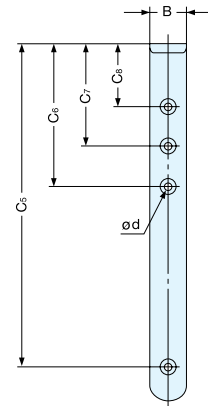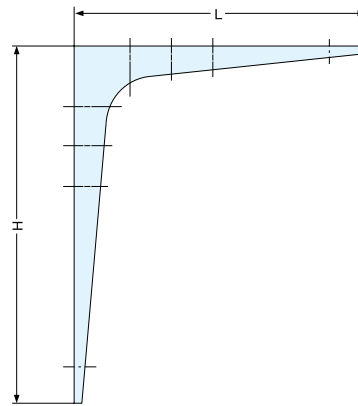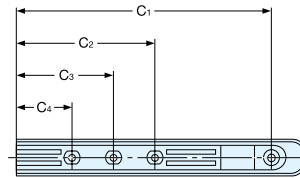

Item No.		L	H	B	C <sub>1</sub>	C <sub>2</sub>	C <sub>3</sub>	C <sub>4</sub>	C <sub>5</sub>	C <sub>6</sub>	C <sub>7</sub>	C <sub>8</sub>	d
Stainless	Steel												
BT-85*	BTK-85 BTW-85	2-3/4" (69)	3-3/8" (86)	9/16" (15)	2-1/4" (58)	1-1/16" (27)	-	-	2-15/16" (75)	1" (26)	-	-	3/16" (4)
BT-120*	BTK-120 BTW-120	3-15/16" (100)	4-3/4" (120)		3-3/8" (85)	1-11/16" (43)	-	-	4-3/16" (106)	1-5/8" (42)	-	-	
BT-180*	BTK-180 BTW-180	5-7/8" (148.5)	7-1/8" (180.5)		5-3/16" (131)	2-13/16" (71)	2" (50)	-	6-3/8" (162.5)	2-7/8" (72.5)	2" (51.5)	-	
BT-240*	BTK-240 BTW-240	7-13/16" (199)	9-7/16" (240)	11/16" (18)	6-15/16" (176)	3-9/16" (91)	2-5/16" (59)	-	8-9/16" (217)	3-5/8" (92)	2-3/8" (60)	-	3/16" (5)
BT-300*	BTK-300 BTW-300	9-3/8" (238.5)	11-7/8" (301)	13/16" (20)	8-1/8" (206.5)	3-5/8" (92.5)	2-3/8" (60.5)	-	10-9/16" (269)	3-3/4" (95)	2-1/2" (63)	-	
BT-380*	BTK-380 BTW-380	12-1/2" (318)	14-7/8" (378)	15/16" (23)	11-1/4" (285)	5-11/16" (145)	4-5/16" (110)	2-15/16" (75)	13-9/16" (345)	5-11/16" (145)	4-5/16" (110)	2-15/16" (75)	
BT-480*	BTK-480 BTW-480	15-3/4" (400)	18-7/8" (480)	1-3/16" (30)	14-3/16" (360)	7-1/16" (180)	5-5/16" (135)	3-9/16" (90)	17-5/16" (440)	7-1/16" (180)	5-5/16" (135)	3-9/16" (90)	1/4" (5.5)

( ) units in mm.  
\*NSF Certified.

Item No.			Holes	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)
Stainless	Steel						
BT-85*	BTK-85	BTW-85	4	33 lbs (15 kg)	40	20	240
BT-120*	BTK-120	BTW-120		44 lbs (20 kg)	60		100
BT-180*	BTK-180	BTW-180		55 lbs (25 kg)	110		200
BT-240*	BTK-240	BTW-240	6	61 lbs (28 kg)	200	10	100
BT-300*	BTK-300	BTW-300		77 lbs (35 kg)	310		40
BT-380*	BTK-380	BTW-380		143 lbs (65 kg)	470		60
BT-480*	BTK-480	BTW-480	8	181 lbs (82.5 kg)	1100	6	60

\*NSF Certified.

Material (BT)	Finish
304 Stainless Steel	Satin
Material (BTK/BTW)	Finish/Color
Steel	Black (BTK), White (BTW)