



# BRACKET

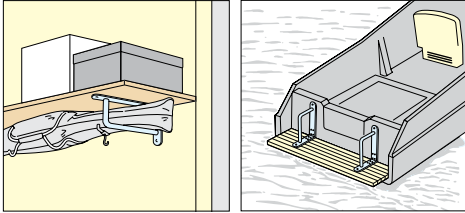

BY

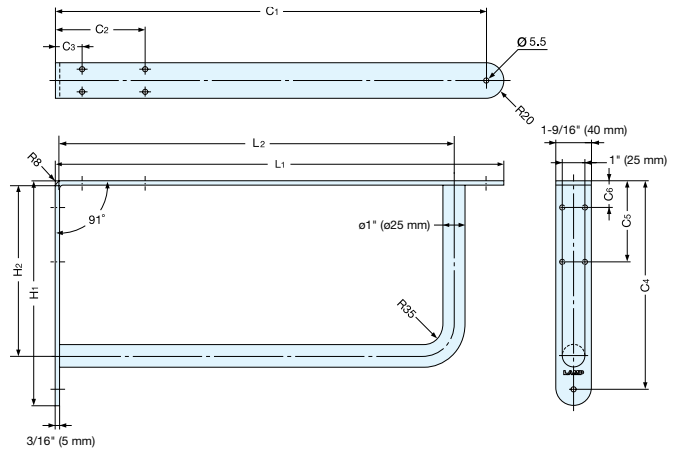

Installation

Material	Finish
304 Stainless Steel	Mirror




Item No.	L <sub>1</sub>	L <sub>2</sub>	H <sub>1</sub>	H <sub>2</sub>	C <sub>1</sub>	C <sub>2</sub>	C <sub>3</sub>	C <sub>4</sub>	C <sub>5</sub>	C <sub>6</sub>	Holes	Screw
BY-300	11-13/16" (300 mm)	9-7/16" (240 mm)	5-15/16" (150 mm)	3-9/16" (90 mm)	11" (280 mm)	3-15/16" (100 mm)		5-1/8" (130 mm)	-		8	5 × 25, 5 × 16
BY-400	15-3/4" (400 mm)	13-3/8" (340 mm)	7-7/8" (200 mm)	5-1/2" (140 mm)	14-15/16" (380 mm)	4-3/4" (120 mm)	1-3/16" (30 mm)	7-1/16" (180 mm)	3-9/16" (90 mm)	1-3/16" (30 mm)	10	
BY-500	19-11/16" (500 mm)	17-5/16" (440 mm)	9-13/16" (250 mm)	7-1/2" (190 mm)	18-7/8" (480 mm)	6-5/16" (160 mm)		9-1/16" (230 mm)				

Item No.	Load Capacity/ pc	Weight (g)	Box (pcs)	Carton (pcs)
BY-300	110 lbs (50 kg)	1100	2	6
BY-400		1400		
BY-500		1800		

# FORK BRACKET



BU-200

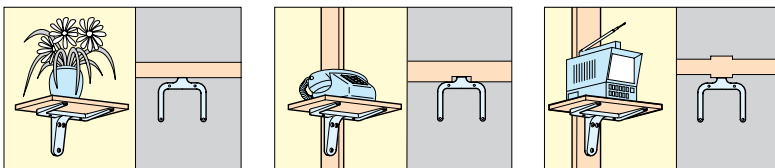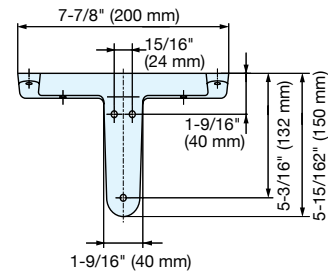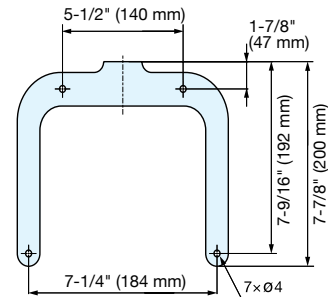

Sample Installation

Material	Finish
Aluminum	Ivory/Black

Item No.	Load Capacity	Weight (g)	Box (pcs)	Carton (pcs)
BU200-I	66 lbs (30 kg)	280	10	100
BU200-B				