




KNUCKLE CATCH

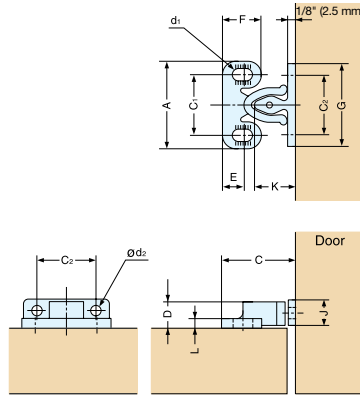

D-CATCH

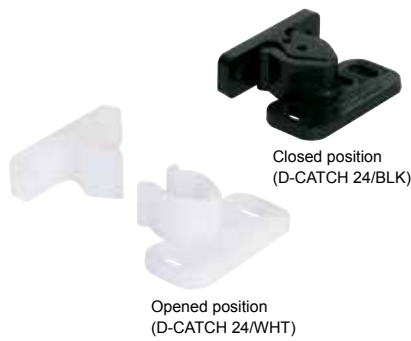

- Grabs and holds doors tightly.

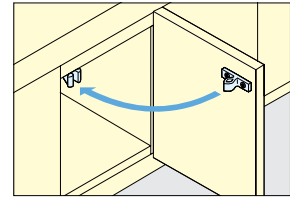

Installation

* Please specify color when ordering.


Part Name	Material	Color
Catch	Polyacetal	Natural White(WHT) Black (BLK)
Strike	Polyamide	

Item No.	Push in Force	Pulling Force	A	C ₁	C	D	E	F	G	C ₂	J	K	L	d ₁	d ₂	Weight (g)	Box (pcs)	Carton (pcs)
D-CATCH 24/WHT	6.8 lbs (3.1 kg)	5.9 lbs (2.7 kg)	15/16" (24)	11/16" (17)	7/8" (21.5)	5/16" (7.5)	1/4" (7)	1/2" (12)	7/8" (22)	5/8" (15.5)	5/16" (7.5)	1/2" (12.5)	1/16" (2)	2.5×5.5	1/8" (2.5)	1.5	100	2000


KNUCKLE CATCH



K-CATCH

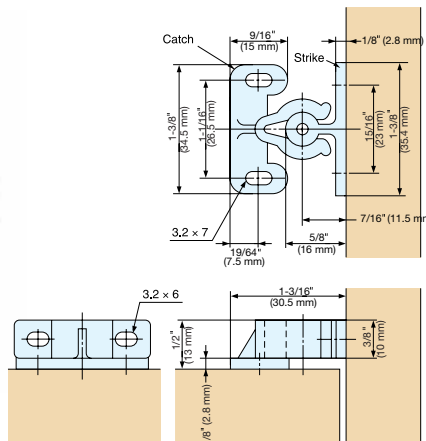

- Grabs and holds doors tightly.

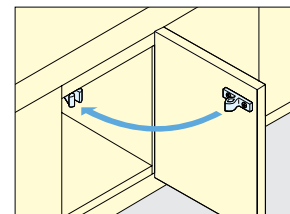

Installation



Part Name	Material	Color
Catch	Polyacetal	White
Strike	Polyamide	

Item No.	Push in Force	Pulling Force	Weight (g)	Box (pcs)	Carton (pcs)
K-CATCH/WHT-T	12.5 lbs (5.7 kg)	15.6 lbs (7.1 kg)	4.5	100	1000

SNAP-IN KNUCKLE CATCH



JCU-F

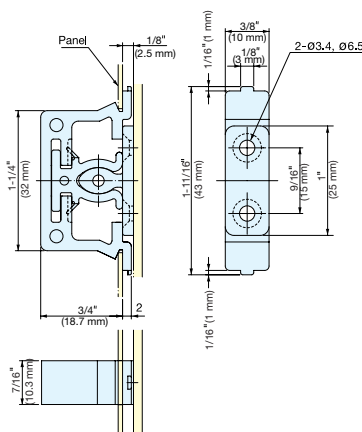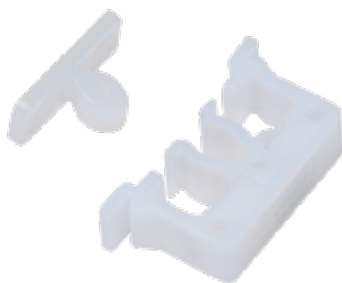

- Grabs and holds doors tightly.
- Snap-in type body for easy installation.
- Designed for sheet metal or plastic panel applications.
- Internal catch body slides 1/16" (1.5 mm) for better alignment.

Part Name	Material	Color
Catch	Polyacetal	White
Strike	Polyamide	

Panel Thickness	Cut Out Dimensions
0.8 mm	32.3 × 10.1
1.0 mm	32.9 × 10.1
1.2 mm	33.8 × 10.1

Item No.	Push in Force	Pulling Force	Weight (g)	Box (pcs)	Carton (pcs)
JCU-F	4.4 lbs (2 kg)	4.4 lbs (2 kg)	5.2	40	800