



# HANDLE

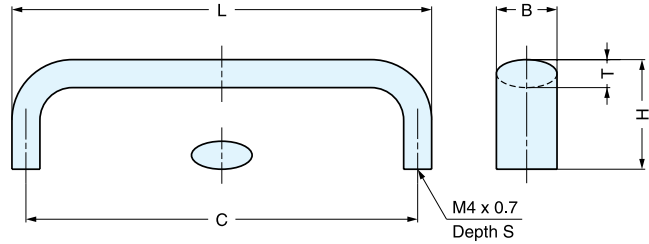

Material	Finish
303 Stainless Steel	Mirror (M) Satin (S)

Item No.	L	C	H	B	T	S	Weight (g)	Box (pcs)	Carton (pcs)	
DL-70/M	DL-70/S	2-3/4" (70 mm)	2-1/2" (64 mm)	15/16" (23 mm)	1/2" (13 mm)	1/4" (6 mm)	3/8" (10 mm)	44	20	200
DL-90/M	DL-90/S	3-9/16" (90 mm)	3-5/16" (84 mm)	55						
DL-110/M	DL-110/S	4-5/16" (110 mm)	4-1/16" (104 mm)	65						
DL-130/M	DL-130/S	5-1/8" (130 mm)	4-7/8" (124 mm)	75						
DL-150/M	DL-150/S	5-15/16" (150 mm)	5-11/16" (144 mm)	1" (25 mm)			86	15	150	



# HANDLE

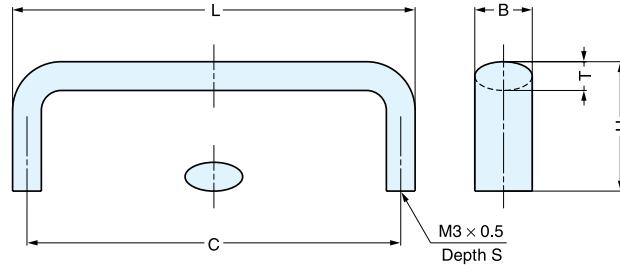

Material	Finish
303 Stainless Steel	Mirror (M) Satin (S)

Item No.	L	C	H	B	T	S	Weight (g)	Box (pcs)	Carton (pcs)
DS-30/M	DS-30/S	1-3/16" (30 mm)	1" (25 mm)	15/16" (23 mm)	3/8" (10 mm)	3/16" (5 mm)	15	40	400
DS-50/M	DS-50/S	2" (50 mm)	1-3/4" (45 mm)	7/8" (22 mm)			22		
DS-70/M	DS-70/S	2-3/4" (70 mm)	2-9/16" (65 mm)	7/8" (22.5 mm)			28		
DS-90/M	DS-90/S	3-9/16" (90 mm)	3-3/8" (85 mm)	15/16" (23 mm)			35		

# HANDLE

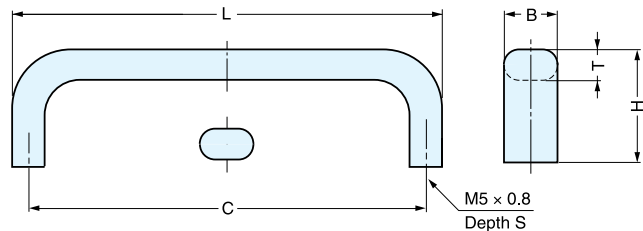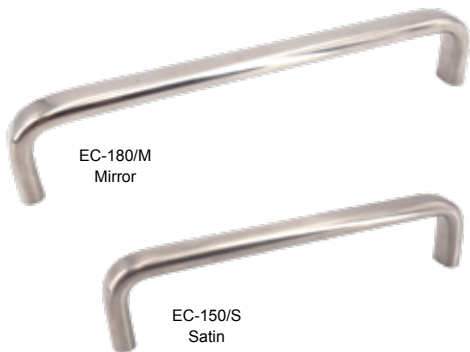

Material	Finish
303 Stainless Steel	Mirror (M) Satin (S)

Item No.	L	C	H	B	T	S	Weight (g)	Box (pcs)	Carton (pcs)
EC-100/M	EC-100/S	3-15/16" (100 mm)	3-5/8" (92 mm)	1-1/4" (32 mm)	9/16" (14 mm)	5/16" (8 mm)	102	15	150
EC-120/M	EC-120/S	4-3/4" (120 mm)	4-7/16" (112 mm)	1-5/16" (34 mm)			120		
EC-150/M	EC-150/S	5-15/16" (150 mm)	5-9/16" (142 mm)	1-7/16" (36 mm)			148		
EC-180/M	EC-180/S	7-1/16" (180 mm)	6-3/4" (172 mm)	1-7/16" (37 mm)			174		