


DOOR HANDLE

STAINLESS
304
STEEL

DSI-3310

HANDLES

DOOR HANDLES

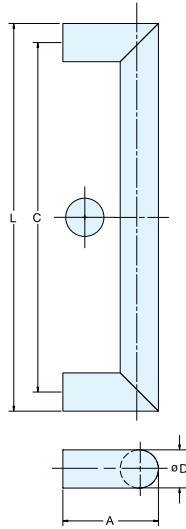

- For use with DSI mounting kits (sold separately, See P.10).
- Please specify Interior/Exterior type when ordering:
 - Posts for Exterior handles are threaded to accept screws.
 - Posts for Interior handles have set screws for DSI mounting kits.
- Similar style to DIH series cabinet handles. (P.36)

Material	Finish
304 Stainless Steel	Satin


Item No.		D	L	C	A	Weight		Box (pcs)	Carton (pcs)
Interior	Exterior					Interior	Exterior		
DSI-3310-15-15I	DSI-3310-15-15E	9/16" (15)	6-1/2" (165)	5-15/16" (150)	2-3/16" (55)	0.7 lbs (0.32 kg)	0.7 lbs (0.32 kg)	1	10
DSI-3310-15-20I	DSI-3310-15-20E		8-7/16" (215)	7-7/8" (200)		0.9 lbs (0.39 kg)	0.9 lbs (0.40 kg)		
DSI-3310-15-30I	DSI-3310-15-30E		12-3/8" (315)	11-13/16" (300)		1.1 lbs (0.52 kg)	1.2 lbs (0.54 kg)		
DSI-3310-20-20I	DSI-3310-20-20E	13/16" (20)	8-11/16" (220)	7-7/8" (200)	2-9/16" (65)	0.4 lbs (0.16 kg)	0.4 lbs (0.18 kg)		
DSI-3310-20-25I	DSI-3310-20-25E		10-5/8" (270)	9-13/16" (250)		0.4 lbs (0.18 kg)	0.4 lbs (0.20 kg)		
DSI-3310-20-30I	DSI-3310-20-30E		12-5/8" (320)	11-13/16" (300)		0.4 lbs (0.20 kg)	0.5 lbs (0.23 kg)		
DSI-3310-30-25I	DSI-3310-30-25E	1-3/16" (30)	11" (280)	9-13/16" (250)	3-9/16" (90)	1.1 lbs (0.48 kg)	1.1 lbs (0.48 kg)		
DSI-3310-30-30I	DSI-3310-30-30E		13" (330)	11-13/16" (300)		1.1 lbs (0.52 kg)	1.1 lbs (0.52 kg)		
DSI-3310-30-35I	DSI-3310-30-35E		14-15/16" (380)	13-3/4" (350)		1.3 lbs (0.59 kg)	1.3 lbs (0.57 kg)		
DSI-3310-30-60I	DSI-3310-30-60E		24-13/16" (630)	23-5/8" (600)		2.1 lbs (0.95 kg)	2.1 lbs (0.95 kg)		

(units in mm)

DOOR HANDLE

STAINLESS
304
STEEL

DSI-3330

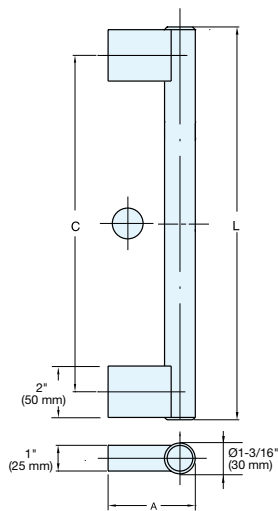

- For use with DSI mounting kits (sold separately, See P.10).
- Please specify Interior/Exterior type when ordering:
 - Posts for Exterior handles are threaded to accept screws.
 - Posts for Interior handles have set screws for DSI mounting kits.
- Similar style to 16 and 27 series cabinet handles. (P.36)

Material	Finish
304 Stainless Steel	Satin

Item No.		L	C	A	Weight		Box (pcs)	Carton (pcs)
Interior	Exterior				Interior	Exterior		
DSI-3330-30-30I	DSI-3330-30-30E	13-3/4" (350)	11-13/16" (300)	3-9/16" (90)	3.3 lbs (1.49 kg)	3.5 lbs (1.57 kg)	1	10
DSI-3330-30-50I	DSI-3330-30-50E	21-5/8" (550)	19-11/16" (500)		3.7 lbs (1.70 kg)	3.7 lbs (1.70 kg)		

(units in mm)

