

EDGE PULL




DSI-350




Satin

Black

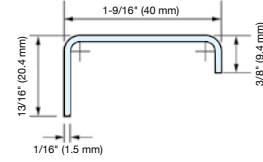

Item No.	Finish	C	L	Weight (g)	Box (pcs)	Carton (pcs)
DSI-350-16	Satin	5/8" (16 mm)	1-1/4" (32 mm)	22	25	250
DSI-350-16-BL	Black	5/8" (16 mm)	1-1/4" (32 mm)	22		
DSI-350-64	Satin	2-1/2" (64 mm)	3-3/4" (96 mm)	66		
DSI-350-96	Satin	3-3/4" (96 mm)	5-1/16" (128 mm)	88		
DSI-350-128	Satin	5-1/16" (128 mm)	6-5/16" (160 mm)	110	10	100
DSI-350-160	Satin	6-5/16" (160 mm)	7-9/16" (192 mm)	132		
DSI-350-192	Satin	7-9/16" (192 mm)	8-13/16" (224 mm)	154		
DSI-350-224	Satin	8-13/16" (224 mm)	10-1/16" (256 mm)	176		
DSI-350-256	Satin	12-5/8" (320 mm)	13-7/8" (352 mm)	240		
DSI-350-352	Satin	20-3/16" (512 mm)	21-7/16" (544 mm)	374		

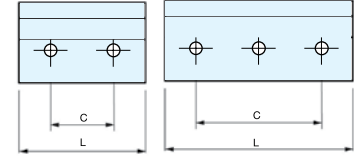

Material	Finish
304 Stainless Steel	Satin, Black (BL)


EDGE PULL



DSI-360




- Back mounted cabinet pull.
- Rounded front pull, available in various lengths.

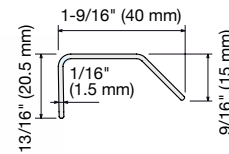

For Models:
16,64,96,128

 For Models:
160, 192



Item No.	L	C	Weight (g)	Box (pcs)	Carton (pcs)
DSI-360-16	1-1/4" (32 mm)	5/8" (16 mm)	24	25	200
DSI-360-64	3-3/4" (96 mm)	2-1/2" (64 mm)	68		150
DSI-360-96	5-1/16" (128 mm)	3-3/4" (96 mm)	90		100
DSI-360-128	6-5/16" (160 mm)	5-1/16" (128 mm)	120	10	60
DSI-360-160	7-9/16" (192 mm)	6-5/16" (160 mm)	144	10	40
DSI-360-192	8-13/16" (224 mm)	7-9/16" (192 mm)	156		

Material	Finish
304 Stainless Steel	Satin


EDGE PULL



DSI-370




- Back mounted cabinet pull.
- Rectangle front pull, available in various lengths.

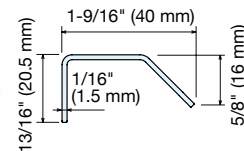

For Models:
16,64,96,128

 For Models:
160, 192



Item No.	L	C	Weight (g)	Box (pcs)	Carton (pcs)
DSI-370-16	1-1/4" (32 mm)	5/8" (16 mm)	24	25	200
DSI-370-64	3-3/4" (96 mm)	2-1/2" (64 mm)	68		150
DSI-370-96	5-1/16" (128 mm)	3-3/4" (96 mm)	90		100
DSI-370-128	6-5/16" (160 mm)	5-1/16" (128 mm)	120	10	60
DSI-370-160	7-9/16" (192 mm)	6-5/16" (160 mm)	144	10	40
DSI-370-192	8-13/16" (224 mm)	7-9/16" (192 mm)	156		

Material	Finish
304 Stainless Steel	Satin