


# SLIDING DOOR HANDLE

**STAINLESS  
304  
STEEL**


## DSI-4253

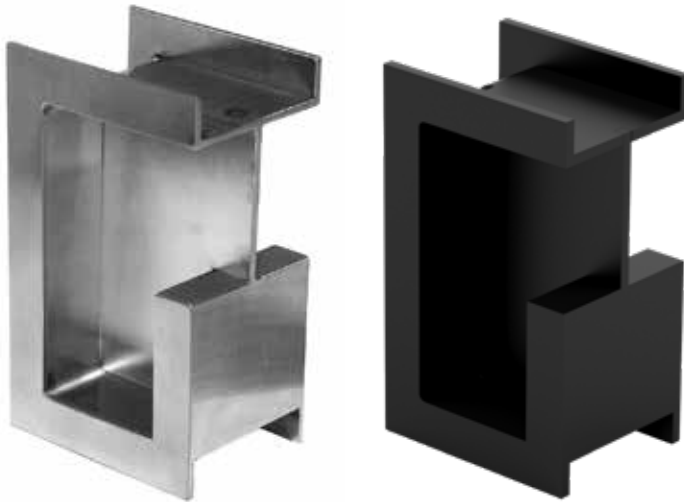

Satin

Black

- Contemporary handle design that can be accessed from door front, back, or edge.
- Requires adhesive for installation (Such as 2-part epoxy, not supplied.)

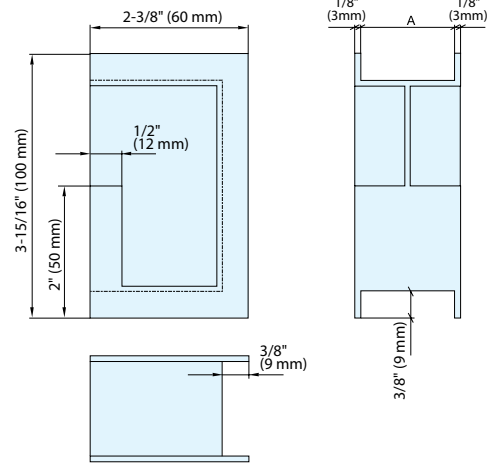

Item No.	Finish	A	Weight (g)	Box (pcs)	Carton (pcs)
DSI-4253-35	Satin	1-3/8" (35 mm)	495	1	10
DSI-4253-35-BL	Black	1-3/8" (35 mm)	495		
DSI-4253-38	Satin	1-1/2" (38 mm)	505		
DSI-4253-40	Satin	1-9/16" (40 mm)	515		
DSI-4253-43	Satin	1-11/16" (43 mm)	530		
DSI-4253-45	Satin	1-3/4" (44.5 mm)	545		
DSI-4253-45-BL	Black	1-3/4" (44.5 mm)	545		

Material	Finish
304 Stainless Steel	Satin, Black (BL)


# SLIDING DOOR HANDLE

**STAINLESS  
304  
STEEL**

## DSI-4254



- Contemporary handle design that can be accessed from door front, back, or edge.
- Requires adhesive for installation (Such as 2-part epoxy, not supplied.)

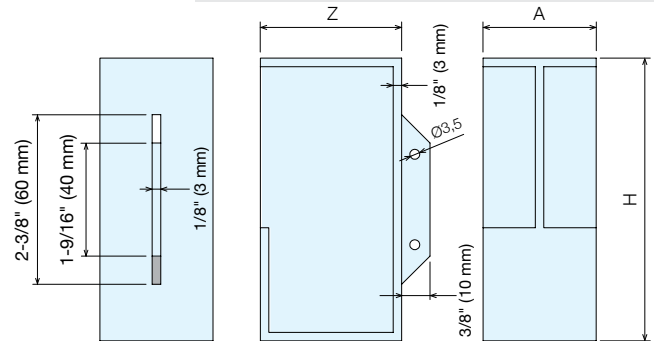

Item No.	A	H	Z	Weight (g)	Box (pcs)	Carton (pcs)
DSI-4254-100-35	1-3/8" (35 mm)	3-15/16" (100 mm)	2" (50 mm)	293	1	10
DSI-4254-100-35-BL						
DSI-4254-100-45	1-3/4" (45 mm)	3-15/16" (100 mm)	2" (50 mm)	345		
DSI-4254-100-45-BL						
DSI-4254-200-35	1-3/8" (35 mm)	7-7/8" (200 mm)	3-3/8" (85 mm)	746		
DSI-4254-200-45	1-3/4" (45 mm)	7-7/8" (200 mm)	3-3/8" (85 mm)	822		
DSI-4254-300-35	1-3/8" (35 mm)	11-13/16" (300 mm)	3-3/8" (85 mm)	1110		
DSI-4254-300-45	1-3/4" (45 mm)	11-13/16" (300 mm)	3-3/8" (85 mm)	1231		
DSI-4254-300-45-BL						
DSI-4254-500-35	1-3/8" (35 mm)	19-11/16" (500 mm)	3-3/8" (85 mm)	1795		
DSI-4254-500-45	1-3/4" (45 mm)	19-11/16" (500 mm)	3-3/8" (85 mm)	2019		

Material	Finish
304 Stainless Steel	Satin Matte Black (BL)