



LINEAR BALL BEARING GUIDE



ESR-9

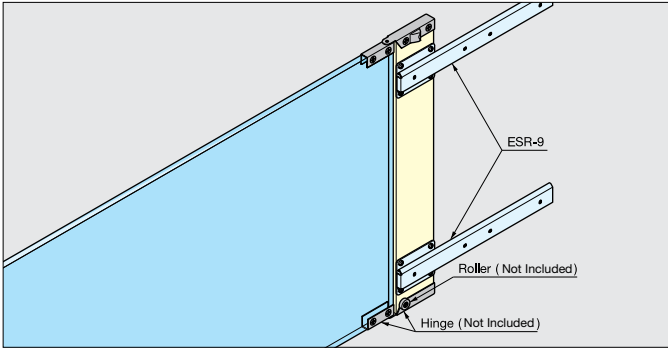

- Non-handed.
- Mounting plate attached.
- Sold by each.
- Mount with M4 or #8 Binding, Pan, or Truss head screws.

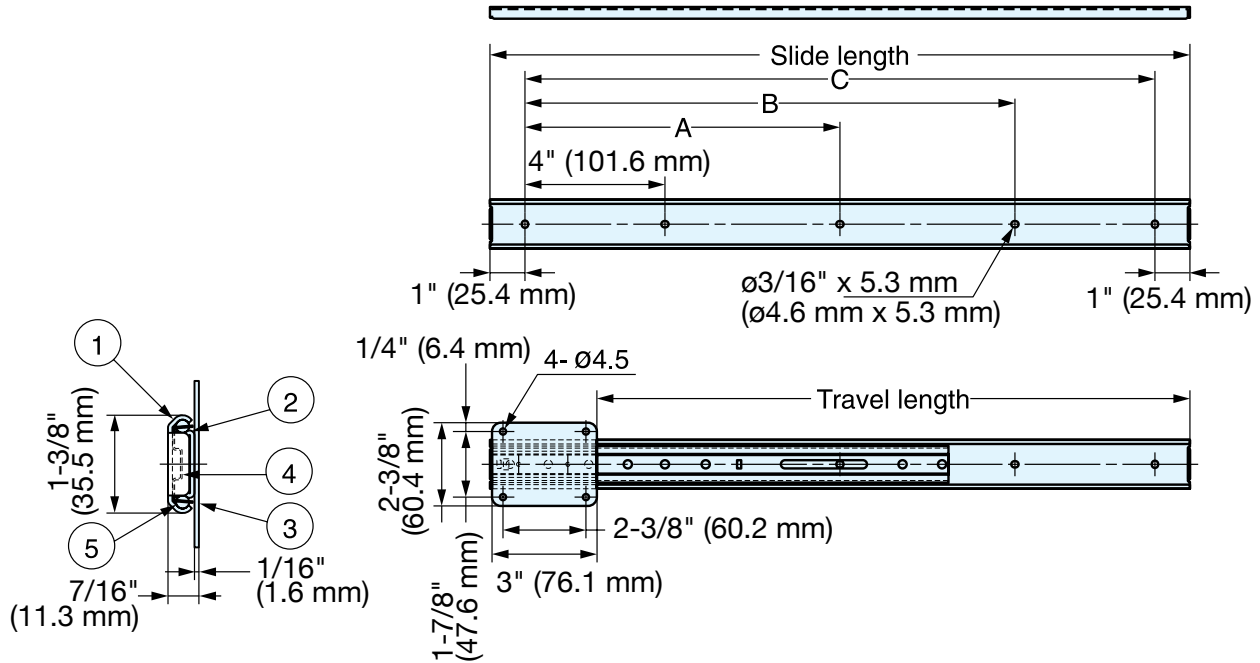

25.4 mm=1"

No.	Part	Material
①	Outer Rail	304 Stainless Steel
②	Inner Rail	
③	Mounting Plate	
④	Retainer	
⑤	Balls	

Item No.	Slide Length	Travel Length	A	B	C	# of Holes Outer Rail	Load Rating /pair	Weight (g)	Box (pcs)
ESR-9-12	12" (304.8 mm)	8-7/8" (225 mm)	-	6" (152.4 mm)	10" (254 mm)	4	11 lbs (5 kg)	280	20
ESR-9-14	14" (355.6 mm)	10-7/8" (276 mm)		8" (203.2 mm)	12" (304.8 mm)				
ESR-9-16	16" (406.4 mm)	12-7/8" (327 mm)		10" (254 mm)	14" (355.6 mm)				
ESR-9-18	18" (457.2 mm)	14-7/8" (378 mm)	8" (203.2 mm)	12" (304.8 mm)	16" (406.4 mm)	5		373	
ESR-9-20	20" (508 mm)	16-7/8" (428 mm)	9" (228.6 mm)	14" (355.6 mm)	18" (457.2 mm)			404	
ESR-9-22	22" (558.8 mm)	18-7/8" (479 mm)	10" (254 mm)	16" (406.4 mm)	20" (508 mm)			441	
ESR-9-24	24" (609.6 mm)	20-7/8" (530 mm)	11" (279.4 mm)	18" (457.2 mm)	22" (558.8 mm)	5		472	
ESR-9-26	26" (660.4 mm)	22-7/8" (581 mm)	12" (304.8 mm)	20" (508 mm)	24" (609.6 mm)			503	
ESR-9-28	28" (711.2 mm)	24-7/8" (632 mm)	13" (330.2 mm)	22" (558.8 mm)	26" (660.4 mm)			536	

() units in mm.