


KNOB



EY-338

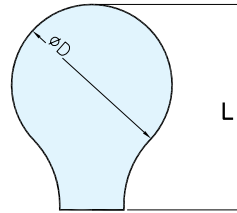


| Item No. | D | L | Weight (g) | Box (pcs) | Carton (pcs) |
|-----------|----------------|----------------|------------|-----------|--------------|
| EY-338/20 | 13/16" (20 mm) | 1" (26 mm) | 40 | 25 | 250 |
| EY-338/25 | 1" (25 mm) | 1-1/4" (32 mm) | 75 | | |

| Material | Finish |
|---------------------|--------|
| 304 Stainless Steel | Satin |

KNOB



EY-339


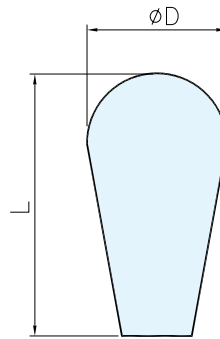


| Item No. | D | L | Weight (g) | Box (pcs) | Carton (pcs) |
|-----------|----------------|------------------|------------|-----------|--------------|
| EY-339/20 | 13/16" (20 mm) | 1-1/2" (37.5 mm) | 125 | 25 | 250 |
| EY-339/25 | 1" (25 mm) | 1-5/8" (41.5 mm) | 226 | | |

| Material | Finish |
|---------------------|--------|
| 304 Stainless Steel | Satin |

KNOB

TS

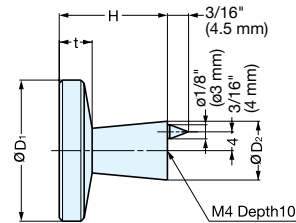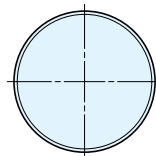

| Material | Finish |
|----------|--------------|
| Brass | Satin Nickel |

| Item No. | D ₁ | D ₂ | H | t | Weight (g) | Box (pcs) | Carton (pcs) |
|----------|-----------------|-----------------|----------------|----------------|------------|-----------|--------------|
| TS-25 | 1" (25 mm) | 9/16" (14.5 mm) | 15/16" (23 mm) | 1/4" (6.7 mm) | 36 | 50 | 200 |
| TS-30 | 1-3/16" (30 mm) | | | | 47 | | |
| TS-36 | 1-7/16" (36 mm) | 9/16" (15 mm) | 15/16" (24 mm) | 5/16" (7.5 mm) | 70 | 30 | 120 |