


# HANDLE



**FB**

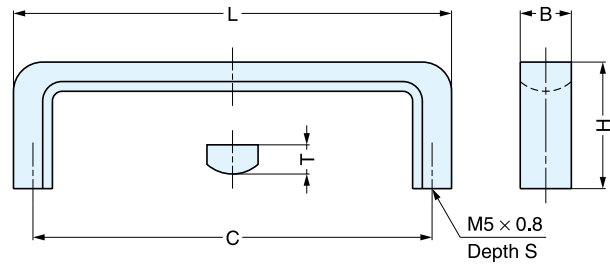


Material	Finish
304 Stainless Steel	Mirror

Item No.	L	C	H	B	T	S	Weight (g)	Box (pcs)	Carton (pcs)
FB-90	3-9/16" (90 mm)	3-1/4" (82 mm)	1" (26 mm)	7/16" (10.5 mm)	1/4" (6 mm)	3/8" (10 mm)	45	35	280
FB-110	4-5/16" (110 mm)	4" (102 mm)	1-1/8" (28 mm)	1/2" (12.5 mm)	1/4" (7 mm)	1/2" (12 mm)	60	25	200
FB-130	5-1/8" (130 mm)	4-3/4" (120 mm)	1-1/4" (32 mm)	9/16" (14.5 mm)	5/16" (8 mm)	9/16" (14 mm)	93	20	160

# HANDLE



**KB**

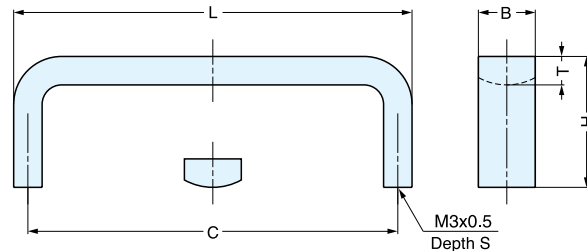


Material	Finish
303 Stainless Steel	Mirror (M) Satin (S)

Item No.	L	C	H	B	T	S	Weight (g)	Box (pcs)	Carton (pcs)	
KB-30/M	KB-30/S	1-3/16" (30 mm)	1" (25 mm)	15/16" (23 mm)	3/8" (10 mm)	3/16" (5 mm)	5/16" (8 mm)	18	40	400
KB-50/M	KB-50/S	2" (50 mm)	1-3/4" (45 mm)	7/8" (22 mm)			26	30	300	
KB-70/M	KB-70/S	2-3/4" (70 mm)	2-9/16" (65 mm)	7/8" (22.5 mm)			33	20	200	
KB-90/M	KB-90/S	3-9/16" (90 mm)	3-3/8" (85 mm)	15/16" (23 mm)			40			

# HANDLE



**KS**

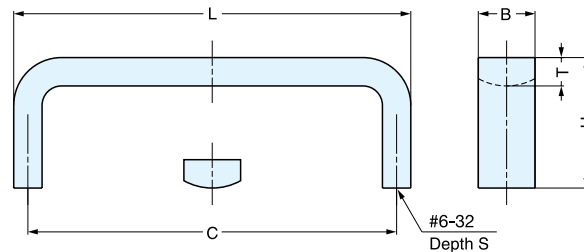

Material	Finish
304 Stainless Steel	Mirror (M) Satin (S)

Item No.	L	C	H	B	T	S	Weight (g)	Box (pcs)	Carton (pcs)	
KS-430/M	KS-430/S	3-3/16" (81 mm)	3" (76 mm)	15/16" (23 mm)	3/8" (10 mm)	3/16" (5 mm)	3/8" (9 mm)	45	20	200
KS-435/M	KS-435/S	3-11/16" (94 mm)	3-1/2" (89 mm)					48		
KS-440/M	KS-440/S	4-3/16" (106 mm)	4" (102 mm)					54		