



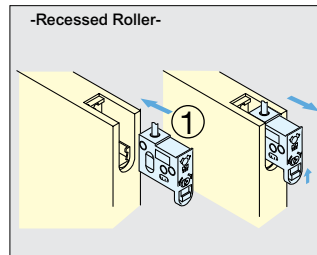


- Thin profile allows flexible design on various application
- Soft-Close Type available by selecting each roller type
- Various parts available for many applications
- \*Designed for interior use, not exterior.

Type	FD30			
	Standard Sliding		One-way Soft Close	Two-way Soft Close
Roller	Recessed	Side Mount	Recessed	Recessed
Door Weight	Max. 66 lbs (30 kg)			
Door Thickness (Min.)	1"(24 mm)	1-1/8"(28 mm)	1"(24 mm)	
Door Width	Max. 39-3/8" (1000 mm)		20"-39-3/8" (510~1000 mm)	23-1/4"-39-3/8" (590~1000 mm)
Door Height	Max.94-1/2" (2400 mm)			

### ■ Door Installation







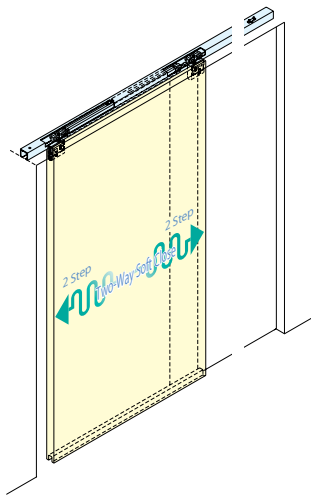


① Snap-in

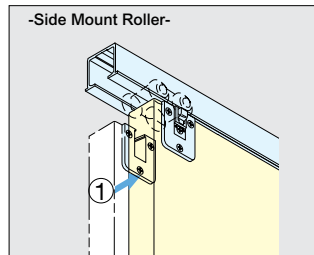





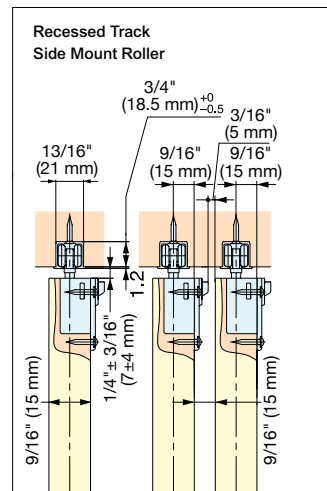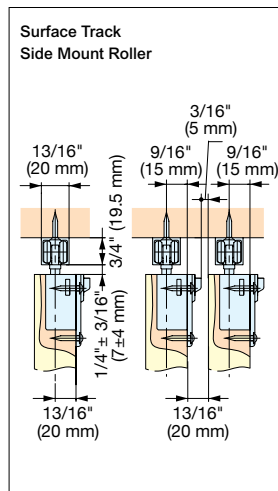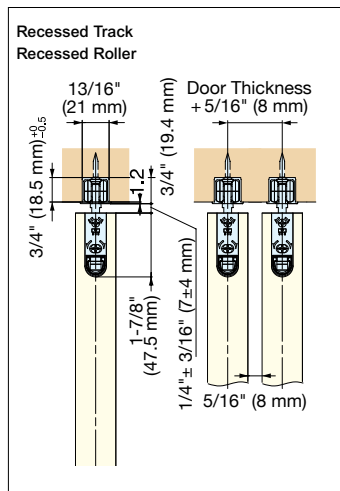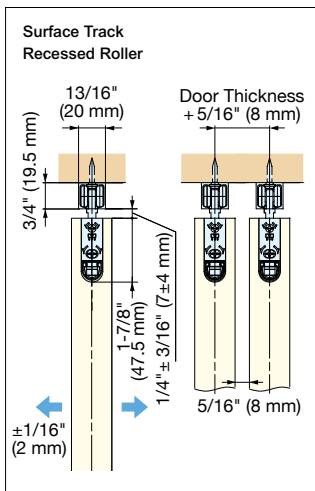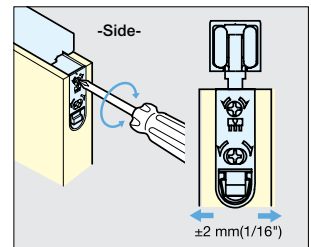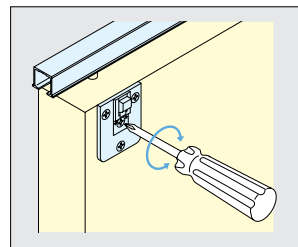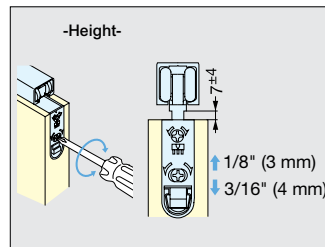

① Snap-in

 
 
 
 
 
### ■ Adjustment (With Phillips Screwdriver)





Parts Set (per door)		Necessary Parts	
		Please refer to "Qty [a] ~ [d]" for parts included in each set.	
Item No.	Description	Roller	Function
[a]	FD30-DHCP	Recessed	Two Way Soft-Close
[b]	FD30-HCP	Recessed	One Way Soft-Close
[c]	FD30-HHP	Recessed	Standard Sliding
[d]	FD30-HUP	Side-Mount	Standard Sliding

Parts Included

No.	Qty				Part Name	Description
	[a]	[b]	[c]	[d]		
1	1 pc	-	-	-	Recessed-Roller Soft-Closer (Two-Way)  FD30-WRH-DSC	<ul style="list-style-type: none"> <li>Material Zinc Alloy/Polyacetal</li> <li>Finish Yellow Zinc Chromate /Light Brown</li> </ul>
2	-	1 pc	-	-	Recessed-Roller Soft-Closer (One-Way)  FD30-WRH-SC	<ul style="list-style-type: none"> <li>Material Zinc Alloy/Polyacetal</li> <li>Finish Yellow Zinc Chromate /Light Brown</li> </ul>
3	1 pc	1 pc	2 pcs	-	Recessed-Roller Standard Sliding  FD30-WRH	<ul style="list-style-type: none"> <li>Material Zinc Alloy/Polyacetal</li> <li>Finish Yellow Zinc Chromate /Light Brown</li> </ul>
4	-	-	-	2 pcs	Side-Mount Roller Standard Sliding  FD30-WRU	<ul style="list-style-type: none"> <li>Material Steel/Polyacetal</li> <li>Finish Yellow Zinc Chromate /Brown</li> </ul>
5	1 pc	1 pc	1 pc	1 pc	Floor Guide  FD30-HBG	<ul style="list-style-type: none"> <li>Material Steel/Polyamide</li> <li>Finish Yellow Zinc Chromate /Light Brown</li> </ul>
6	-	1 pc	2 pcs	2 pcs	End Stopper  FD30-HTST-DB	<ul style="list-style-type: none"> <li>Material Steel/Polyacetal</li> <li>Finish Yellow Zinc Chromate /Brown</li> </ul>

Optional Parts			
	Part Name	Description	
7	Door Stopper  FD30-HTKY	<ul style="list-style-type: none"> <li>Material Zinc Alloy/Rubber</li> <li>Finish/Grey</li> </ul>	
8	Stopper Block  FD30-HSB	<ul style="list-style-type: none"> <li>Material/Polyacetal</li> <li>Finish/Dark Brown</li> </ul>	
9	Cover Cap  FD30-WRH-CP	<ul style="list-style-type: none"> <li>Material Polypropylene</li> <li>Finish: Light Brown *Dark Brown/White</li> </ul>	
10	Bottom Guide (For By-pass Door)  FD30-HGW	<ul style="list-style-type: none"> <li>Material/Polyamide</li> <li>Finish/Light Brown</li> </ul>	
11	Door Guide Track  FD30-HBRT1500SIL	<ul style="list-style-type: none"> <li>Material/Aluminum</li> <li>Finish Anodized Silver</li> </ul>	

Upper Tracks

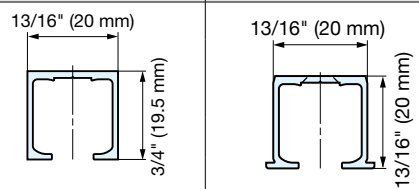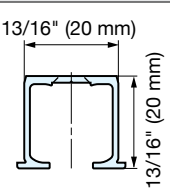	Length	Item No.		Dimension, Material / Finish	
		Surface Mount	Recessed Mount	Surface	Recessed
Standard	71-5/8" (1820 mm)	FD30-TRM1820SIL	FD30-TRH1820SIL		
	107-1/2" (2730 mm)	FD30-TRM2730SIL	FD30-TRH2730SIL		
	143-5/16" (3640 mm)	FD30-TRM3640SIL	FD30-TRH3640SIL		
Soft-closing	71-5/8" (1820 mm)	FD30-TRM1820SCSIL	FD30-TRH1820SCSIL		
	107-1/2" (2730 mm)	FD30-TRM2730SCSIL	FD30-TRH2730SCSIL		
	143-5/16" (3640 mm)	FD30-TRM3640SCSIL	FD30-TRH3640SCSIL		
				Aluminum / Anodized Silver	