



INSET GLASS DOOR LIFT-OFF HINGE




GH-36/NCR

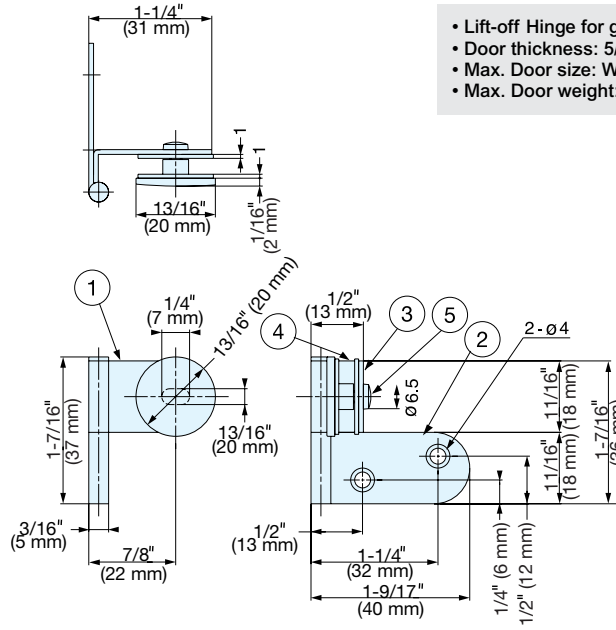

- Lift-off Hinge for glass/acrylic doors.
- Door thickness: 5/32"~1/4" (4~6 mm)
- Max. Door size: W17-3/4" × H27-9/16" (W450 × H700)
- Max. Door weight: 8.8 lbs/pair (4 kg/pair)

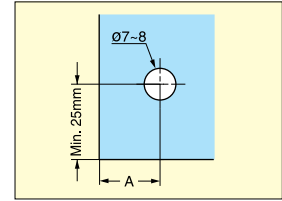

Cut Out Dimension

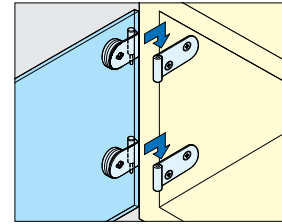

Installation

Glass Thickness	A
3/16" (4 mm)	3/4" (19 mm)
3/16" (5 mm)	23/32" (18 mm)
1/4" (6 mm)	21/32" (17 mm)

No.	Part Name	Material	Finish
①	Body	Steel	Chrome
②			
③	Plate	Brass	
④	Washer	PVC	Clear
⑤	Screw	Steel	Nickel

Item No.		Weight (g)	Box (pcs)	Carton (pcs)
GH-36/NCRL	GH-36/NCRR	24.5	100	400


CONCEALED HINGE



T-90-200



- Concealed hinge for either inset or overlay installation.

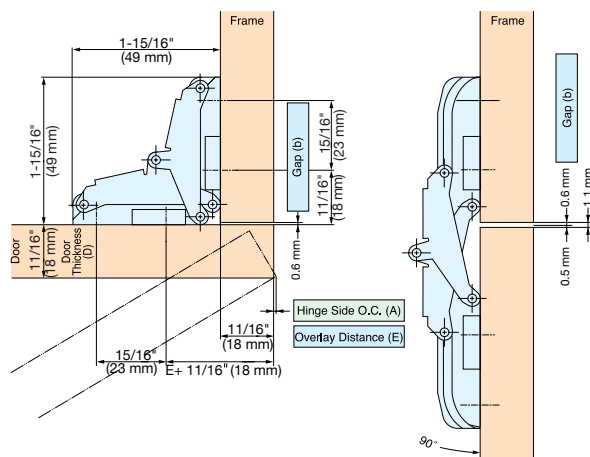

■ Door Thickness (D) and Gap (b) Table 1.

Door thickness (D)	9/16" (15)	5/8" (16)	11/16" (17)	11/16" (18)
Gap (b)	0.2 mm	0.3 mm	0.5 mm	0.6 mm

■ Hinge side opening clearance chart Table 2.

Door thickness (D)	Overlay distance (E)			
	9/16" (15)	5/8" (16)	11/16" (17)	11/16" (18)
9/16" (15)	1.1 mm	0.5 mm	-	-
5/8" (16)	2.0 mm	1.4 mm	0.8 mm	0.2 mm
11/16" (17)	2.9 mm	2.3 mm	1.7 mm	1.1 mm
11/16" (18)	3.8 mm	3.2 mm	2.6 mm	2.0 mm

Hinge side O.C. (A)

Item No.	Weight (g)	Box (pcs)
T-90-200	45	200

Part Name	Material	Finish
Arm	Polyamide	Ivory
Body	Steel	Chrome