


OVERLAY GLASS DOOR HINGE (W/ CATCH)





GH-456C

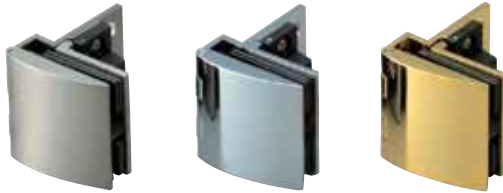


GH-456C/SN
Satin Nickel

GH-456C/CR
Chrome


GH-456C/GA
Gold

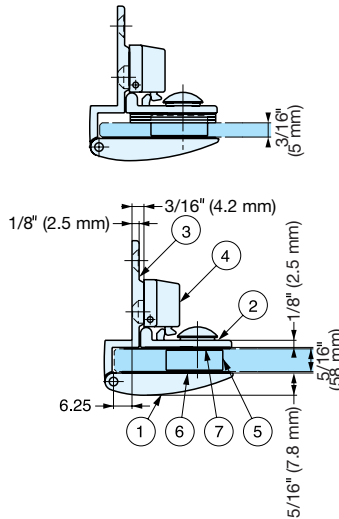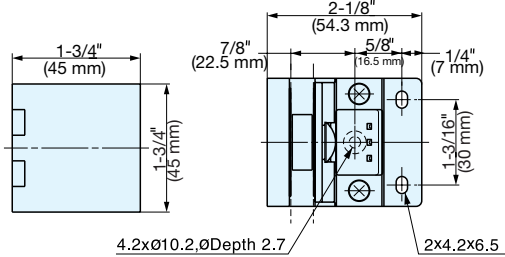

- Glass hinge with catch.
- For overlay use.
- Suitable for showcases
- Mounting position adjustable:
Vertically $\pm 1/32''$ (1 mm)
Horizontally $\pm 1/16''$ (1.2 mm)

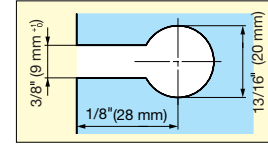

Cut Out Dimensions for 5/16" (8 mm) Glass

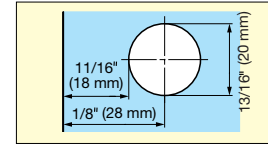

Cut Out Dimensions for 3/16", 1/4" (5,6 mm) Glass

Item No.	Applicable Door Thickness	Applicable Glass Door Size /Pair
GH-456C/SN	3/16" ~ 5/16" (5~8 mm)	W:23-5/8" (600 mm)
GH-456C/CR	3/16" (5 mm): Use with 3 spacers 1/4" (6 mm): Use with 2 spacers	H:47" (1200 mm)
GH-456C/GA	5/16" (8 mm): Spacer not required	Maximum 33 lbs (15 kg)

Item No.	Weight (g)	Box (pcs)	Carton (pcs)
GH-456C/SN	216	10	40
GH-456C/CR			
GH-456C/GA			

No.	Part Name	Material	Finish		
			SN	CR	GA
①	Face Plate	Brass	Satin Nickel	Chrome	Gold
②	Fixing Plate				
③	Mounting Plate				
④	Catch	PBT, POM	Black		
⑤	Glass Adjustment Block	Polyamide			
⑥	Pad A	PVC			
⑦	Pad B				
⑧	Spacer	Polypropylene			

OVERLAY GLASS DOOR HINGE (W/O CATCH)





GH-456N




GH-456N/SN
Satin Nickel

GH-456N/CR
Chrome


GH-456N/GA
Gold

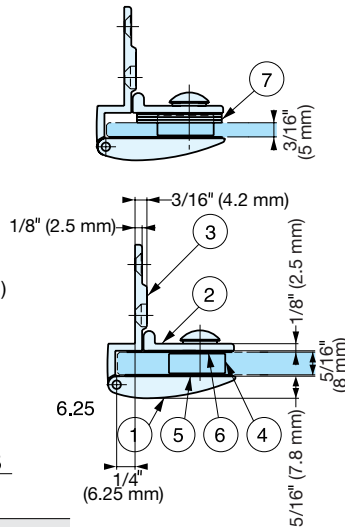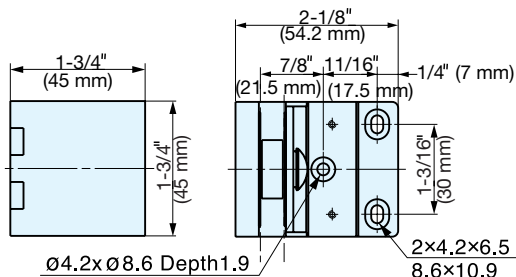

- For overlay use.
- Suitable for showcases
- Mounting position adjustable:
Vertically $\pm 1/32''$ (1 mm)
Horizontally $\pm 1/16''$ (1.2 mm)

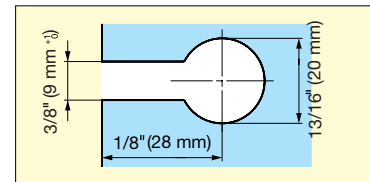

Cut Out Dimensions for 5/16" (8 mm) Glass

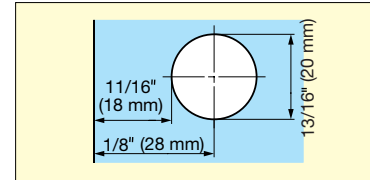

Cut Out Dimensions for 3/16", 1/4" (5,6 mm) Glass

Item No.	Applicable Door Thickness	Applicable Glass Door Size /Pair
GH-456N/SN	3/16" ~ 5/16" (5~8 mm)	W:23-5/8" (600 mm)
GH-456N/CR	3/16" (5 mm): Use with 3 spacers 1/4" (6 mm): Use with 2 spacers	H:47" (1200 mm)
GH-456N/GA	5/16" (8 mm): Spacer not required	Maximum 33 lbs (15 kg)

Item No.	Weight (g)	Box (pcs)	Carton (pcs)
GH-456N/SN	210	10	40
GH-456N/CR			
GH-456N/GA			

No.	Part Name	Material	Finish		
			SN	CR	GA
①	Face Plate	Brass	Satin Nickel	Chrome	Gold
②	Fixing Plate				
③	Mounting Plate				
④	Glass Adjustment Block	Polyamide	Black		
⑤	Pad	Rubber			
⑥	Spacer	Polypropylene			