

CONCEALED HINGE



HES-3038BK


- Door weight: Max. 99 lbs (45 kg)/3 pcs
- Door thickness: Min. 1-7/16" (36 mm)
- Suitable door size: H78-3/4" x W35-7/16" (H2000 mm x W900 mm)
- Successfully passed 200,000 open/close private cycle tests.




HES-3038BK/PB




HES-3038BK/SC

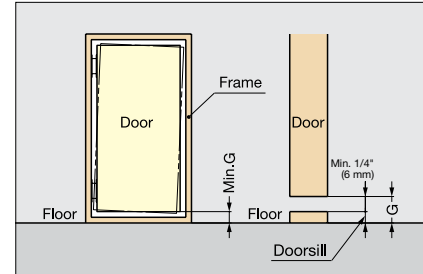

To determine the door and frame dimension, (G) must be taken into account.
G = Min. 1/6" (6 mm) + doorsill

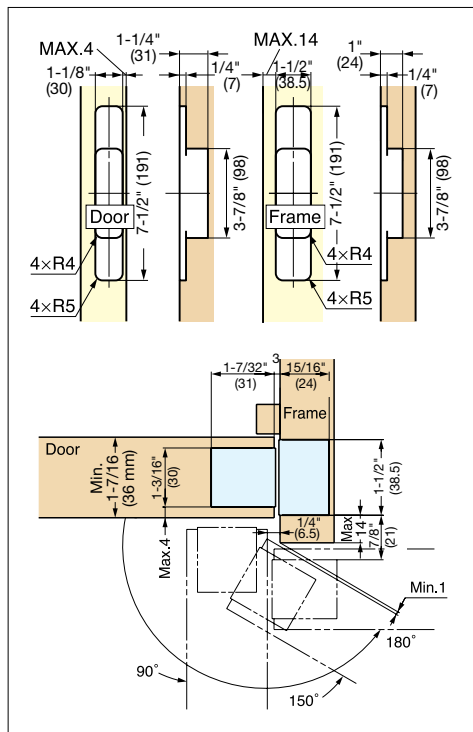

Bore Dimensions

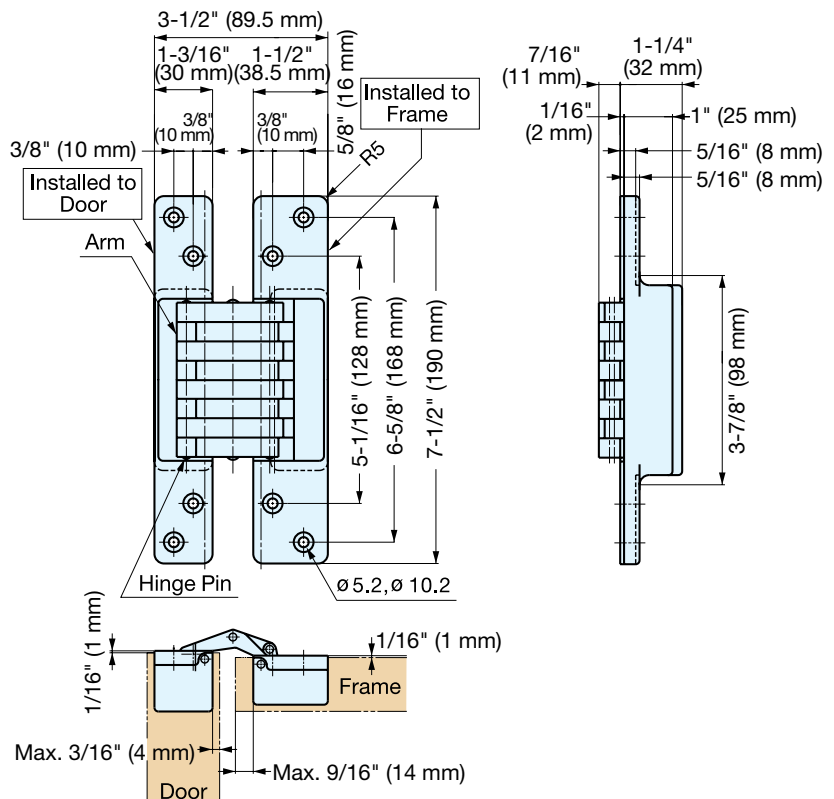

Item No.	Weight (g)	Box (pcs)	Carton (pcs)
HES-3038BK/PB	1360	2	20
HES-3038BK/SC			

Material	Finish/Color
Brass	Polished Brass (PB) Satin Chrome (SC)