

# 3-WAY ADJUSTABLE CONCEALED HINGE



# HES3D-120

HINGES



HES3D-120DC  
Dull Chrome




HES3D-120DN  
Dull Nickel

HES3D-120BL  
Black

- 3-WAY adjustment function allows vertical, horizontal, and depth adjustment after hinge installed.
  - Easy installation and adjustment.
  - Successfully passed 300,000 open/close private cycle tests.
  - Supplied with steel flat head screw.
  - Covers hide all screw heads for clean appearance.
  - Max. Door weight: 66 lbs (30 kg)/2 pcs, 88 lbs (40 kg)/3 pcs
  - Min. Door Thickness: 1-1/8" (29 mm)
  - Max. Door Size: H 94-1/2" x W 35-7/16" (H 2400 mm x W 900 mm)
  - Bracket for sheet metal available.
- HES3D-120BKT-D: Door  
HES3D-120BKT-F: Frame



3-WAY ADJUSTABLE CONCEALED HINGES

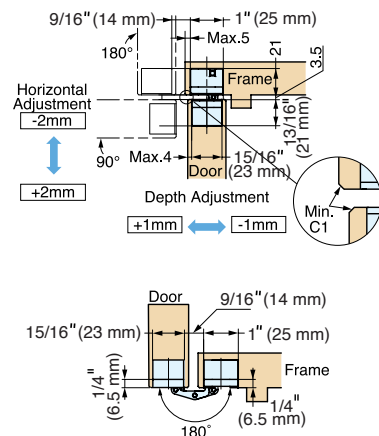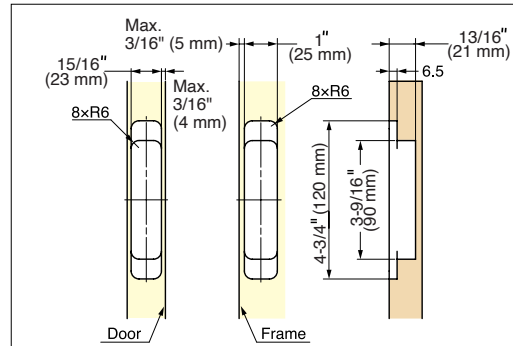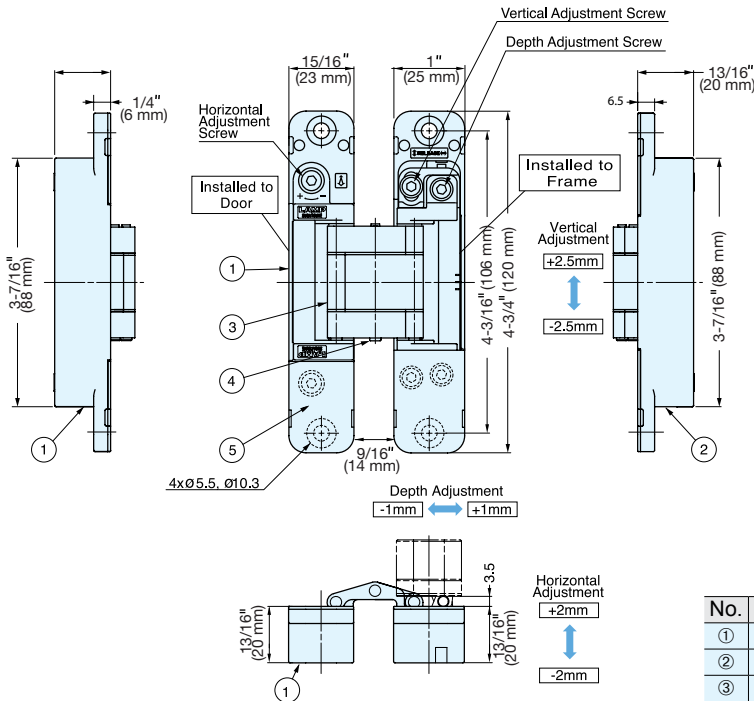

Bore Dimensions

Item No.	Finish/Color	Weight (g)	Box (pcs)	Carton (pcs)
HES3D-120DC	Dull Chrome	380	2	24
HES3D-120DN	Dull Nickel			
HES3D-120BL	Black			

No.	Part Name	Material	Finish/Color
①	Body	Zinc Alloy	Dull Chrome (DC)
②	Base Frame		Dull Nickel (DN)
③	Arm		Black (BL)
④	Pin	304 Stainless Steel	-
⑤	Cover	ABS	Dull Chrome (DC) Dull Nickel (DN) Black (BL)