

3-WAY ADJUSTABLE CONCEALED HINGE



HES3D-V135LGR-2





HES3D-V135LGR-2

- 3-WAY adjustment function allows vertical, horizontal, and depth adjustment after hinge installed.
- Easy installation and adjustment.
- Successfully passed 300,000 open/close private cycle tests.
- Supplied with steel button head screw.
- Door weight: Max. 88 lbs (40 kg)/2 pcs, 122 lbs (55 kg)/3 pcs
- Door Thickness: Min. 1-3/16" (30 mm)
- Max. Door Size: H 94-1/2" x W 35-7/16" (H 2400 mm x W 900 mm)


Item No.	Finish/Color		
HES3D-V135LGR-2	Light Gray		

Item No.	Weight (g)	Box (pcs)	Carton (pcs)
HES3D-V135LGR-2	400	2	24

No.	Part Name	Material	Finish/Color
①	Body	Steel	Nickel
②	Base Frame	Polyacetal	Light Grey
③	Arm	Aluminum	Anodized
④	Pin	Steel	Nickel
⑤	Cover	Polyacetal	Light Grey
⑥	Block	Zinc Alloy	Nickel

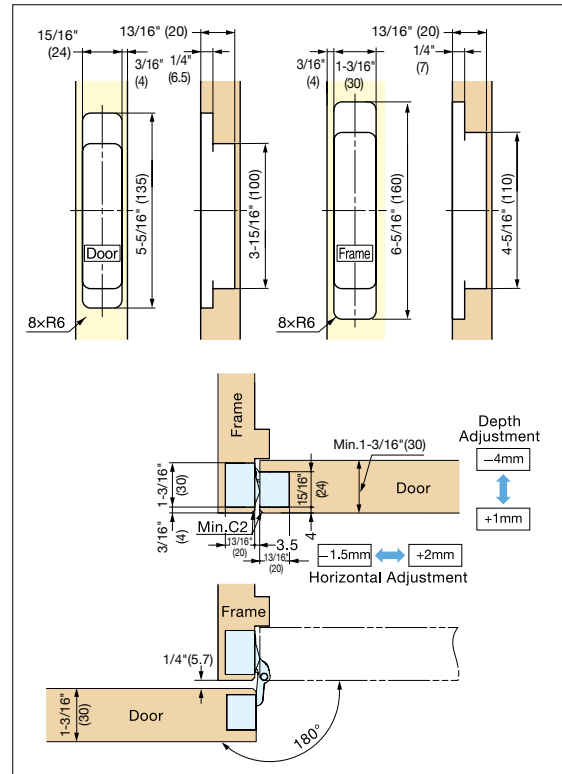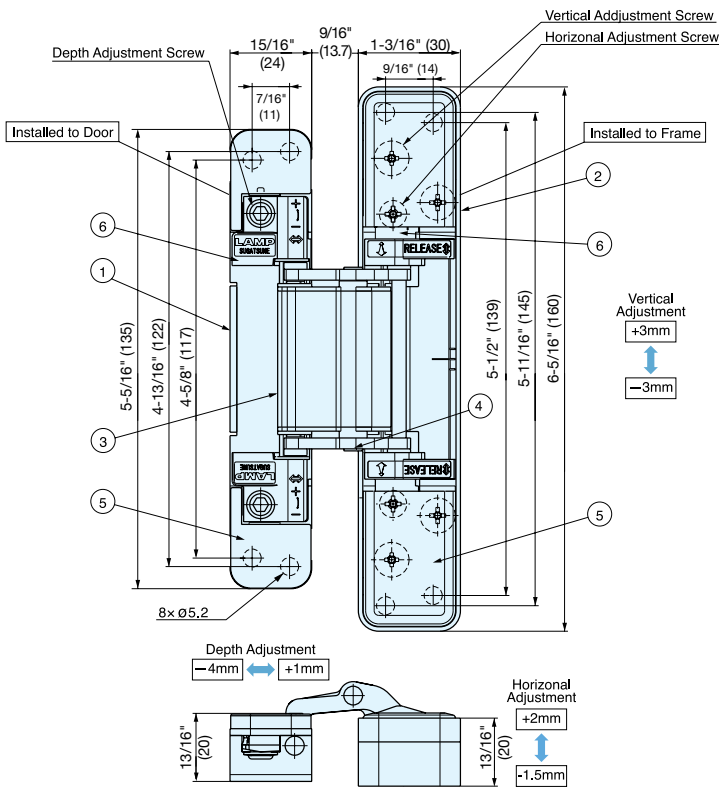

Bore Dimensions

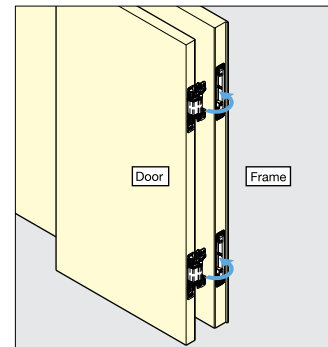

Installation